




**T&B Catalog Number:** 2921NM  
**UPC Number:** 78621079741  
**Description:** 1/2" Ranger; Liquidtight Cord Connector-Straight. Body material-Weather stabilized nylon; Bushing-Rubber. Cord range-.310-.560  
**Status:** Active

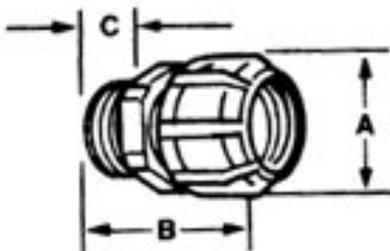

### Features

Extended range with superior strain relief.  
 Reduced overall size, fits into tighter spaces.  
 Gland nut designed to restrict cable bending.

### Application

Provide a means for passing a cord cable into an enclosure through a bulkhead; Form a mechanical grip and water and/or oil-resistant seal for cord; Form a non-slip connection or termination for flexible cord and cable.

### General

**Material** Nylon  
**Cord and Cable Types** S, SO, SV, ST, STD, SJ, SJO, SJT, SJTO, SVD

### Dimension Information

**Hub Size (inches)** 1/2  
**Dimension A (inches)** 1 7/32  
**Dimension B (inches)** 2 1/8  
**Dimension C (inches)** 5/8  
**Cord Range (inches)** .310-.560  
**Throat Diameter (inches)** 0.55

### Packaging

**T&B Inner Pack** 25  
**Package in Units** 100  
**T&B Sold in UOM** Each  
**T&B Weight Per UOM** 5.2 lbs. per 100

### Application Support

**T&B Instruction Sheets** ta00927-tb2  
**Product Overview** Available on Website  
**Specifications** Available on Website  
**Liquidtight Flexible Cord and Cable Connectors-Application and Features** Available on Website  
**Portable Cord Selection Table** Available on Website

### Notes

**\*\*Note** Suitable for Ordinary, Wet or Dry locations.

### Certifications

**RoHS Compliance** No

### Certifications

File Nbr:  
 E 13938

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
 8155 T&B Blvd.  
 Memphis, TN 38125

T&B Technical Support  
 MS 3B-50  
 8155 T&B Blvd.

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289

