 

 
 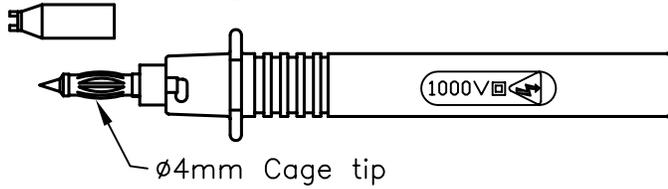



ALL RIGHTS RESERVED. NO PORTION OF THIS PUBLICATION, WHETHER IN WHOLE OR IN PART CAN BE REPRODUCED WITHOUT THE EXPRESS WRITTEN CONSENT OF SPC TECHNOLOGY.

REVISIONS			DOC. NO. SPC-F004 * Effective: 12/21/98 * DCP No: 680					
DCP #	REV	DESCRIPTION	DRAWN	DATE	CHECKD	DATE	APPRVD	DATE
615	A	RELEASED	JWM	6/23/00	JC	8/11/00	DJC	8/23/00
1355	B	Length was 60	JWM	3/9/04	JC	3/9/04	JC	3/9/04




Spring Tip Mini-Probes - w/IC Caps (1 amp)

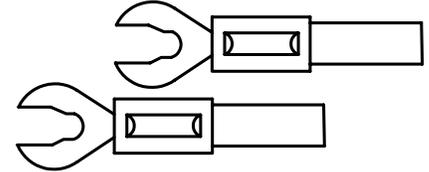


Spade Lug Adapters (36 Amps)

**Probe Bodies w/ Replacement Tips & IC Caps**

- 1000V CAT III
- 36 Amps
- Reinforced or Double Insulation
- 1 Red, 1 Black



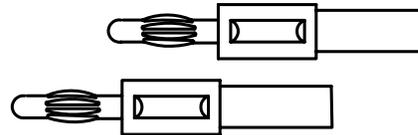


4mm Banana Plug Adapters (10 Amps)

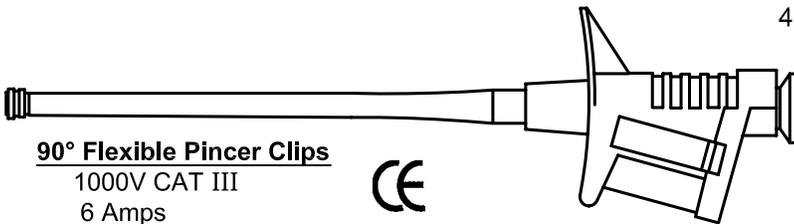


**90° Flexible Pincer Clips**

- 1000V CAT III
- 6 Amps
- Reinforced or Double Insulation
- 1 Red, 1 Black

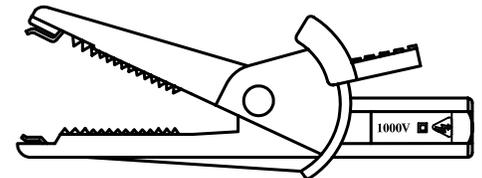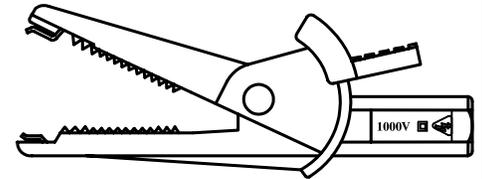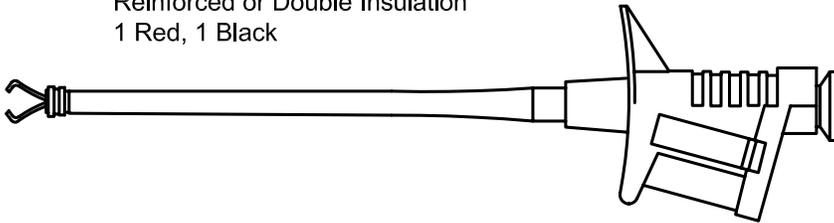

**Insulated Alligator Clips**

 - 1000V CAT III
- 20 Amps
- Reinforced or Double Insulation
- 1 Red, 1 Black



**Leads, Straight to Right-Angle Sheath Plugs**

- 1000V CAT III
- 12 Amps
- Reinforced or Double Insulation
- 1 Red, 1 Black
- Leads: PVC



Packaged in Clear Poly Bag

SPC-F004.DWG

DISCLAIMER:  
ALL STATEMENTS AND TECHNICAL INFORMATION CONTAINED HEREIN ARE BASED UPON INFORMATION AND/OR TESTS WE BELIEVE TO BE ACCURATE AND RELIABLE. SINCE CONDITIONS OF USE ARE BEYOND OUR CONTROL, THE USER SHALL DETERMINE THE SUITABILITY OF THE PRODUCT FOR THE INTENDED USE AND ASSUME ALL RISK AND LIABILITY WHATSOEVER IN CONNECTION THEREWITH.



UNLESS OTHERWISE SPECIFIED, DIMENSIONS ARE FOR REFERENCE PURPOSES ONLY.	DRAWN BY:	DATE:	DRAWING TITLE:				
	Jeff McVicker	6/23/00	Deluxe DMM Probe Kit				
	CHECKED BY:	DATE:	SIZE	DWG. NO.	ELECTRONIC FILE	REV	
	JOHN COLE	8/11/00	A	76-082	16F7741.dwg	B	
APPROVED BY:	DATE:	SCALE: NTS		U.O.M.: INCHES [cm]		SHEET: 1 OF 1	
Daniel Carey	8/23/00						