


All rights Reserved . No Portion of this publication, whether in whole or in part can be reproduced without the express written consent of SPC Technology.


Revisions:			DOC. No.		* Effective: 12/21/98		* DCP No. 680	
DCP: #	REV	Description:	Drawn	Date	Checked	Date	Approved	Date
XXX	A	RELEASED	Geetha	20-11-08	Suresh	20-11-08	JN	12/12/08

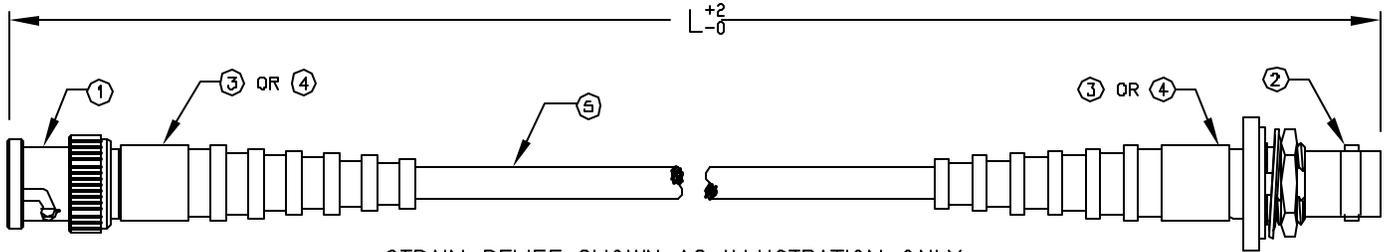

STRAIN RELIEF SHOWN AS ILLUSTRATION ONLY

ITEM	DESCRIPTION	MATERIAL	FINISH
5	CABLE	-	-
4	TUBING	**HEAT SHRINK	BLACK
3	STRAIN RELIEF	POLYVINYL CHLORIDE	BLACK
2	BNC F CRIMP BULK	BRASS	NICKEL
1	BNC MALE CRIMP	BRASS	NICKEL

\*\*DUAL WALL POLYOLEFIN

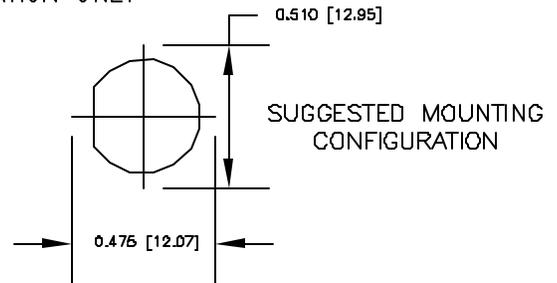

SUGGESTED MOUNTING CONFIGURATION

Manufacturer Part Number	Product Description	Length	Cable Type	Strain Relief
SPC26545	BNC Male to BNC Female Bulkhead, RG-58C/U Cable, 12 inch Length, Cr/Cr	12	RG-58C/U	Yes
SPC26548	BNC Male to BNC Female Bulkhead, RG-58C/U Cable, 36 inch Length, Cr/Cr	36	RG-58C/U	Yes
SPC26551	BNC Male to BNC Female Bulkhead, RG-58C/U Cable, 60 inch Length, Cr/Cr	60	RG-58C/U	Yes
SPC26553	BNC Male to BNC Female Bulkhead, RG-58C/U Cable, 72 inch Length, Cr/Cr	72	RG-58C/U	Yes
SPC26555	BNC MALE TO BNC FEM BLKHD; RG-174A/U; 12"; CR/CR	12	RG-174A/U	No
SPC26556	BNC MALE TO BNC FEM BLKHD; RG-174A/U; 24"; CR/CR	24	RG-174A/U	No
SPC26557	BNC MALE TO BNC FEM BLKHD; RG-174A/U; 36"; CR/CR	36	RG-174A/U	No
SPC26558	BNC MALE TO BNC FEM BLKHD; RG-174A/U; 48"; CR/CR	48	RG-174A/U	No
SPC26559	BNC MALE TO BNC FEM BLKHD; RG-174A/U; 60"; CR/CR	60	RG-174A/U	No
SPC26560	BNC MALE TO BNC FEM BLKHD; RG-174A/U; 72"; CR/CR	72	RG-174A/U	No
SPC26562	BNC MALE TO BNC FEM BLKHD; RG-316/U; 24"; CR/CR	24	RG-316/U	No
SPC26564	BNC MALE TO BNC FEM BLKHD; RG-316/U; 36"; CR/CR	36	RG-316/U	No
SPC26566	BNC MALE TO BNC FEM BLKHD; RG-316/U; 48"; CR/CR	48	RG-316/U	No
SPC26568	BNC MALE TO BNC FEM BLKHD; RG-316/U; 60"; CR/CR	60	RG-316/U	No
SPC26570	BNC MALE TO BNC FEM BLKHD; RG-316/U; 72"; CR/CR	72	RG-316/U	No
SPC26573	BNC Male to BNC Female Bulkhead, RG-59B/U Cable, 24 inch Length, Cr/Cr	24	RG-59B/U	No
SPC26576	BNC Male to BNC Female Bulkhead, RG-59B/U Cable, 48 inch Length, Cr/Cr	48	RG-59B/U	No
SPC26578	BNC Male to BNC Female Bulkhead, RG-59B/U Cable, 60 inch Length, Cr/Cr	60	RG-59B/U	No
SPC26580	BNC Male to BNC Female Bulkhead, RG-59B/U Cable, 72 inch Length, Cr/Cr	72	RG-59B/U	No
SPC26582	BNC MALE TO BNC FEM BLKHD; RG-188A/U; 12"; CR/CR	12	RG-188A/U	No

**Disclaimer:**

All statements and technical information contained herein are based upon information and/or tests we believe to be accurate and reliable. Since conditions of use are beyond our control, the user shall determine the suitability of the product for the intended use and assume all risk and liability whatsoever in connection therewith.



**SPC TECHNOLOGY**

Drawing Title:

**BNC MALE CRIMP TO BNC FEMALE CRIMP BULKHEAD**

Unless otherwise specified, Dimensions are for references purposes only.

Drawn By:

Geetha

Date:

20-11-08

Checked By:

Suresh

Date:

20-11-08

Approved By:

Jason Nash

Date:

12/12/08

Size: A

Dwg. No

TA-978

Electronic File

TA-978.dwg

Rev A

Scale: NTS

U.O.M.: Inches (mm)

Sheet: 1 of 2

All rights Reserved . No Portion of this publication, whether in whole or in part can be reproduced without the express written consent of SPC Technology.

Revisions:			DOC. No.		* Effective: 12/21/98		* DCP No. 680	
DCP: #	REV	Description:	Drawn	Date	Checked	Date	Approved	Date
XXX	A	RELEASED	Geetha	20-11-08	Suresh	20-11-08	JN	12/12/08

Manufacturer Part Number	Product Description	Length	Cable Type	Strain Relief
SPC26583	BNC MALE TO BNC FEM BLKHD; RG-188A/U; 24"; CR/CR	24	RG-188A/U	No
SPC26584	BNC MALE TO BNC FEM BLKHD; RG-188A/U; 36"; CR/CR	36	RG-188A/U	No
SPC26585	BNC MALE TO BNC FEM BLKHD; RG-188A/U; 48"; CR/CR	48	RG-188A/U	No
SPC26586	BNC MALE TO BNC FEM BLKHD; RG-188A/U; 60"; CR/CR	60	RG-188A/U	No
SPC26587	BNC MALE TO BNC FEM BLKHD; RG-188A/U; 72"; CR/CR	72	RG-188A/U	No
SPC26777	BNC MALE TO BNC FEM BLKHD; RG-142B/U; 12"; CR/CR	12	RG-142B/U	No
SPC26778	BNC MALE TO BNC FEM BLKHD; RG-142B/U; 24"; CR/CR	24	RG-142B/U	No
SPC26779	BNC MALE TO BNC FEM BLKHD; RG-142B/U; 36"; CR/CR	36	RG-142B/U	No
SPC26780	BNC MALE TO BNC FEM BLKHD; RG-142B/U; 48"; CR/CR	48	RG-142B/U	No
SPC26781	BNC MALE TO BNC FEM BLKHD; RG-142B/U; 60"; CR/CR	60	RG-142B/U	No
SPC26782	BNC MALE TO BNC FEM BLKHD; RG-142B/U; 72"; CR/CR	72	RG-142B/U	No
SPC26783	BNC MALE TO BNC FEM BLKHD; RG-223/U; 12"; CR/CR	12	RG-223/U	No
SPC26784	BNC MALE TO BNC FEM BLKHD; RG-223/U; 24"; CR/CR	24	RG-223/U	No
SPC26785	BNC MALE TO BNC FEM BLKHD; RG-223/U; 36"; CR/CR	36	RG-223/U	No
SPC26786	BNC MALE TO BNC FEM BLKHD; RG-223/U; 48"; CR/CR	48	RG-223/U	No
SPC26787	BNC MALE TO BNC FEM BLKHD; RG-223/U; 60"; CR/CR	60	RG-223/U	No
SPC26788	BNC MALE TO BNC FEM BLKHD; RG-223/U; 72"; CR/CR	72	RG-223/U	No
SPC26789	BNC MALE TO BNC FEM BLKHD; RG-400/U; 12"; CR/CR	12	RG-400/U	No
SPC26790	BNC MALE TO BNC FEM BLKHD; RG-400/U; 24"; CR/CR	24	RG-400/U	No
SPC26791	BNC MALE TO BNC FEM BLKHD; RG-400/U; 36"; CR/CR	36	RG-400/U	No
SPC26792	BNC MALE TO BNC FEM BLKHD; RG-400/U; 48"; CR/CR	48	RG-400/U	No
SPC26793	BNC MALE TO BNC FEM BLKHD; RG-400/U; 60"; CR/CR	60	RG-400/U	No
SPC26794	BNC MALE TO BNC FEM BLKHD; RG-400/U; 72"; CR/CR	72	RG-400/U	No
SPC26796	BNC Male to BNC Female Bulkhead, RG-55B/U Cable, 24 inch Length, Cr/Cr	24	RG-55B/U	No
SPC26798	BNC Male to BNC Female Bulkhead, RG-55B/U Cable, 36 inch Length, Cr/Cr	36	RG-55B/U	No
SPC26802	BNC Male to BNC Female Bulkhead, RG-55B/U Cable, 72 inch Length, Cr/Cr	72	RG-55B/U	No
SPC26804	BNC MALE TO BNC FEM BLKHD; LMR-195; 12"; CR/CR	12	LMR-195	No
SPC26805	BNC MALE TO BNC FEM BLKHD; LMR-195; 24"; CR/CR	24	LMR-195	No
SPC26806	BNC MALE TO BNC FEM BLKHD; LMR-195; 36"; CR/CR	36	LMR-195	No
SPC26807	BNC MALE TO BNC FEM BLKHD; LMR-195; 48"; CR/CR	48	LMR-195	No
SPC26808	BNC MALE TO BNC FEM BLKHD; LMR-195; 60"; CR/CR	60	LMR-195	No
SPC26809	BNC MALE TO BNC FEM BLKHD; LMR-195; 72"; CR/CR	72	LMR-195	No
SPC26810	BNC MALE TO BNC FEM BLKHD; LMR-100; 12"; CR/CR	12	LMR-100	No
SPC26811	BNC MALE TO BNC FEM BLKHD; LMR-100; 24"; CR/CR	24	LMR-100	No
SPC26812	BNC MALE TO BNC FEM BLKHD; LMR-100; 36"; CR/CR	36	LMR-100	No
SPC26813	BNC MALE TO BNC FEM BLKHD; LMR-100; 48"; CR/CR	48	LMR-100	No
SPC26814	BNC MALE TO BNC FEM BLKHD; LMR-100; 60"; CR/CR	60	LMR-100	No
SPC26815	BNC MALE TO BNC FEM BLKHD; LMR-100; 72"; CR/CR	72	LMR-100	No
SPC26816	BNC MALE TO BNC FEM BLKHD; RG-316/U DS; 12"; CR/CR	12	RG-316/U	No
SPC26817	BNC MALE TO BNC FEM BLKHD; RG-316/U DS; 24"; CR/CR	24	RG-316/U	No
SPC26818	BNC MALE TO BNC FEM BLKHD; RG-316/U DS; 36"; CR/CR	36	RG-316/U	No
SPC26819	BNC MALE TO BNC FEM BLKHD; RG-316/U DS; 48"; CR/CR	48	RG-316/U	No
SPC26820	BNC MALE TO BNC FEM BLKHD; RG-316/U DS; 60"; CR/CR	60	RG-316/U	No
SPC26821	BNC MALE TO BNC FEM BLKHD; RG-316/U DS; 72"; CR/CR	72	RG-316/U	No
SPC26822	BNC Male to BNC Female Bulkhead, RG-58A/U Cable, 12 inch Length, Cr/Cr	12	RG-58A/U	Yes
SPC26827	BNC Male to BNC Female Bulkhead, RG-58A/U Cable, 60 inch Length, Cr/Cr	60	RG-58A/U	Yes

**Disclaimer:**

All statements and technical information contained herein are based upon information and/or tests we believe to be accurate and reliable. Since conditions of use are beyond our control, the user shall determine the suitability of the product for the intended use and assume all risk and liability whatsoever in connection therewith.



**SPC TECHNOLOGY**

Drawing Title:

**BNC MALE CRIMP TO BNC FEMALE CRIMP BULKHEAD**

Size: A

Dwg. No

**TA-978**

Electronic File

**TA-978.dwg**

Rev A

Scale: NTS

U.O.M.: Inches (mm)

Sheet: 2 of 2

Unless otherwise specified, Dimensions are for references purposes only.

Drawn By:

Geetha

Date:

20-11-08

Checked By:

Suresh

Date:

20-11-08

Approved By:

Jason Nash

Date:

12/12/08