

**SPECIFICATIONS:**

- Material Thickness: .003" (.0762mm) nominal, +/- 10%
- Surface Resistance:
  - Outer Layer: <10E11 ohms per ANSI/ESD S11.11
  - Inner Layer: <10E11 ohms per ANSI/ESD S11.11
- Static Shielding: < 50 nJ per ANSI/ESD S11.31
- Light Transmission: >40% per ASTM 1003

**PACKAGING:**

- Bags are packed in Multicomp packaging


Item #	Multicomp #	Size (W x L)	Approval
CMG-10833	MC35821	2" x 3"	
CMG-10834	MC35822	3" x 5"	
CMG-10835	MC35823	4" x 6"	
CMG-10836	MC35824	5" x 8"	
CMG-10837	MC35825	6" x 8"	
CMG-10838	MC35826	6" x 10"	
CMG-10839	MC35827	8" x 10"	
CMG-10840	MC35828	8" x 12"	
CMG-10841	MC35829	10" x 12"	
CMG-10842	MC35830	10" x 14"	

Side Seam is 3/8" (+/- .10")  
 Tolerance L: +/- 0.250" / Tolerance W: +/- 0.250"

**multicomp**  
 SPC Type No.: MCXXXXX  
 Desc.: STATIC SHIELDING BAG, METAL-IN  
 RoHS COMPLIANT  
 Qty & UOM: QTY Pack  
 Tracking Info: RPXXXXXXXXX  
 Made in USA.

Multicomp packaging label

**RoHS Compliance Statement**  
 None of the following materials are intentionally added in manufacturing this product: lead, mercury, cadmium, hexavalent chromium, polybrominated biphenyls (PBB) or polybrominated diphenyl ethers (PBDE) as outlined in the Directive 2002/95/EC Article 4.1

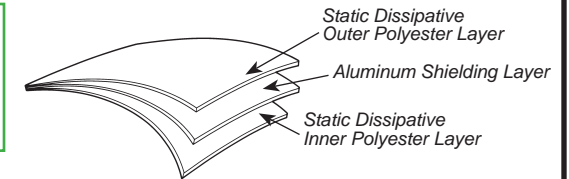

Special manufactured items are not returnable for credit **MADE IN AMERICA**

**BAGS, ESD SHIELDING, METAL IN, TRANSPARENT, PACKAGED IN MULTICOMP PACKAGING**

**CMG**

3651 WALNUT AVE., CHINO, CA 91710  
 PHONE (909) 627-9634 FAX (909) 363-7322  
 WEBSITE: www.CMG-Sales.com

**DRAWING NUMBER**  
 CMG-10833

**DATE**  
 September 2010