


REVISIONS				DOC. NO. SPC-F004 * Effective: 7/8/02 * DCP No: 1398				
DCP #	REV	DESCRIPTION	DRAWN	DATE	CHECKD	DATE	APPRVD	DATE
1575	A	RELEASED	JWM	8/7/03	HO	9/11/03	DJC	9/11/03

Specifications

- Base: GX-23
- Watts: 13
- Approx. Initial Lumens: 825
- Approx. Mean Lumens: 710
- Color Temperature: 2700°K
- Average Life: 10,000
- Color Rendering Index: 82

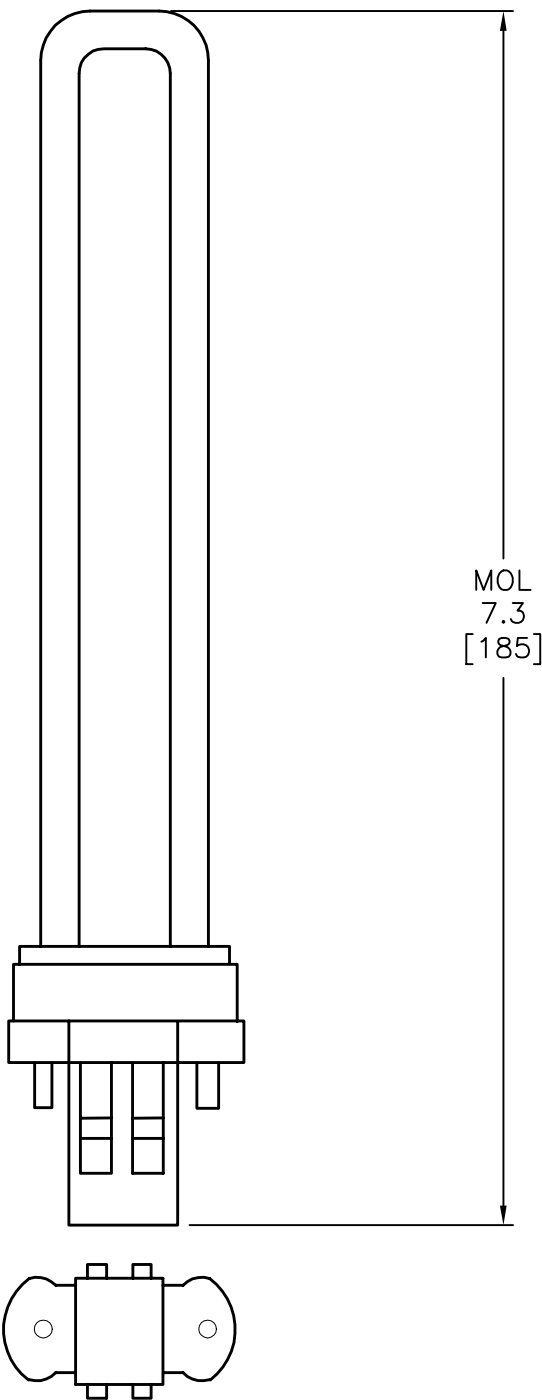

SPC-F004.DWG

TOLERANCES: UNLESS OTHERWISE SPECIFIED, DIMENSIONS ARE FOR REFERENCE PURPOSES ONLY.	DRAWN BY: Jeff McVicker	DATE: 8/7/03	DRAWING TITLE: Compact Fluorescent, Duo-Tube Lamp, 2 Pin Base			
	CHECKED BY: Hisham Odish	DATE: 9/11/03	SIZE A	DWG. NO. DT13/27	ELECTRONIC FILE 31C8491.dwg	REV A
	APPROVED BY: Daniel Carey	DATE: 9/11/03	SCALE: NTS		U.O.M.: INCHES [mm]	SHEET: 1 OF 1
	ALL RIGHTS RESERVED. NO PORTION OF THIS PUBLICATION, WHETHER IN WHOLE OR IN PART CAN BE REPRODUCED WITHOUT THE EXPRESS WRITTEN CONSENT OF SPC TECHNOLOGY. DISCLAIMER: ALL STATEMENTS AND TECHNICAL INFORMATION CONTAINED HEREIN ARE BASED UPON INFORMATION AND/OR TESTS WE BELIEVE TO BE ACCURATE AND RELIABLE. SINCE CONDITIONS OF USE ARE BEYOND OUR CONTROL, THE USER SHALL DETERMINE THE SUITABILITY OF THE PRODUCT FOR THE INTENDED USE AND ASSUME ALL RISK AND LIABILITY WHATSOEVER IN CONNECTION THEREWITH.					