

L-com's USB Cable Portfolio, a Solution for every Application


L-com offers the most extensive offering of off the shelf USB cable assemblies to address myriad applications. Our USB cable options include PVC, LSZH, USB 2.0 and USB 3.0, armored, waterproof, panel mount, angled and more.

Panel Mount USB Cables


ECF504-12AAL



UPMB5-M

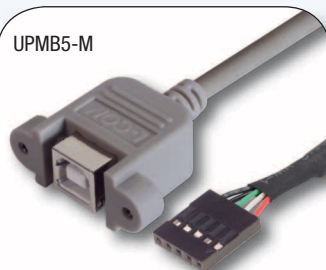

UPMAA-30-M

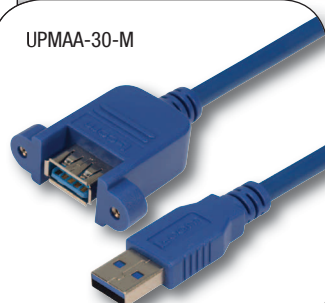


Panel Mount USB Cables


- USB 2.0 and USB 3.0 options
- Allows USB cables to be passed through panels or enclosures
- Flying lead and 5-pin housing versions available
- All variations of male/female and Type A/B connectors offered

USB 3.0 Cables


CAU3AB-M

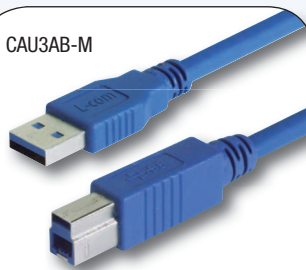

CAVISU3AMICB

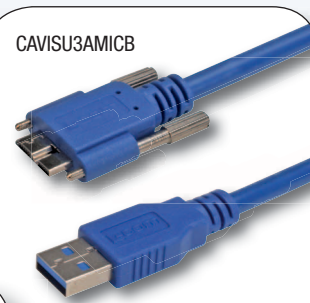

CAVISU3AA

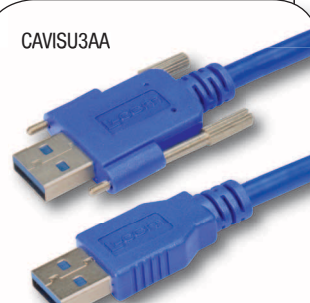

USB 3.0 Cables

- 30 micro inch gold plated contacts provide reliable connections
- Thumbscrew options for USB3 Vision applications
- USB 3.0 Type A, B, Micro B and panel mount versions available
- Low Smoke Zero Halogen (LSZH) available

Specialty USB Cable Assemblies

Coiled



COILMB5EXT-2M




COILUAB

Latching




CAUZALAL-M

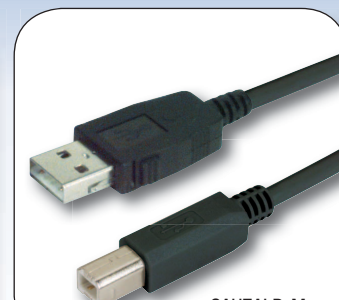


CAUZALB-M

LSZH

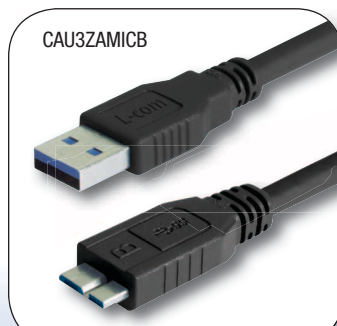

CAU3ZAMICB

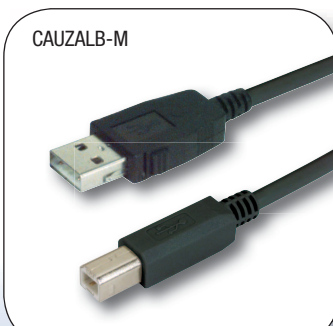

CAUZALB-M

Waterproof IP67



WPUSBAXSH



WPUSBAX

L-com's USB Cable Portfolio, a Solution for every Application

In addition to thousands of in stock off the shelf USB cable assemblies, L-com can custom manufacture USB cables to your specific requirements. As a leader in the connectivity industry L-com provides the widest selection and highest quality USB cables found anywhere.

Deluxe USB Cables


ECUSBAA



ECUSBAX



ECUSBAB-M

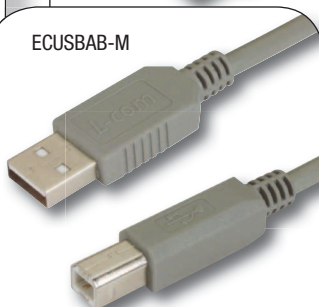


Deluxe USB Cables

- Industry standard USB cable
- USB 2.0 Compliant 26 AWG power leads
- Foil plus braid shield provides maximum protection against EMI/RFI
- Available in 0.3, 0.5, 0.75, 1, 2, 3, 4 & 5 meter lengths

Premium USB Cables


CSMUAB

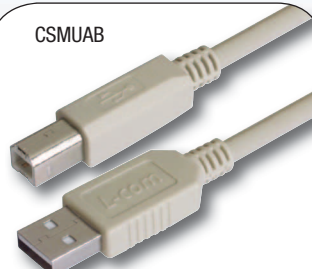

CSMUAX-M



CSMUAA

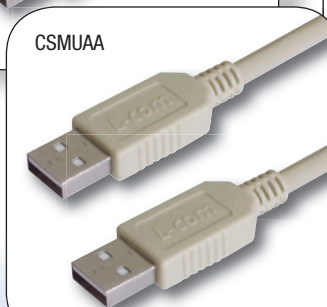

Premium USB Cables

- 20 AWG power conductors support maximum power transfer
- Foil plus braid shield provides maximum protection against EMI/RFI
- Transfer rates up to 480Mbps meets USB 2.0 requirements
- Molded backshells provide durability and increased strength at cable entry point


45 & 90 Degree USB Cables

L-com Sales Contact

45 & 90 Degree USB Cables

- Six off the shelf 45 degree cable/connector choices
- Left, right, up and down 90 degree connector options
- 30 microinch gold plated contacts provide reliable connections
- USB 2.0 compliant 26 AWG power leads
- Available in lengths ranging from 0.3 to 5 meters
- USB Type A, B, Micro B and Mini B options


CAA-45LB

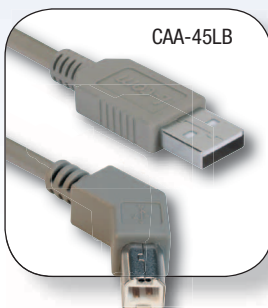


CA45LA-45LB




CA45RA-B

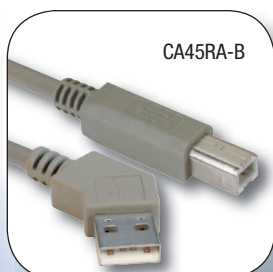

CA90UA-90UB

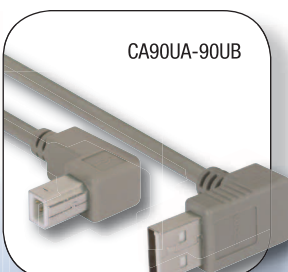

CAA-90UB

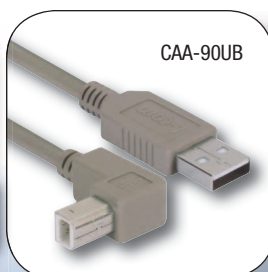

CAA-90RMB5-M

