

MAXIMIZE PRODUCTIVITY WITH RELIABLE
POWER SOLUTIONS FROM



element14



DURACELL®

ALKALINE BATTERIES


DURACELL® COPPERTOP® ALKALINE BATTERIES

WITH DURALOCK POWER PRESERVE™ TECHNOLOGY

- CopperTop® batteries are engineered to deliver just the right level of power for most electronic needs.
- Duracell Batteries are engineered for intermittent use, so the battery is not expelling energy when the device is off, providing longer life and increases your productivity.
- Less maintenance = less downtime in your facility, increasing your efficiency throughout your facility and cuts your costs.
- Available in bulk packs or smaller retail packs.
- CopperTop® batteries contain no added mercury and are rated for reliable operation in extremes from -4°F to 129°F.
- Individually date-coded and up to 10-year guarantee in storage.
- Contain no added mercury.




MN1500BKD

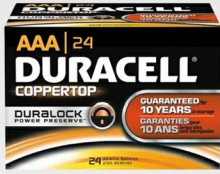

MN2400BKD



MN1400

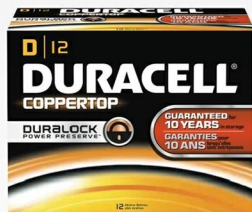

MN1300



MN1604BKD

Description	AA	AAA	D	C	9V
Pack Size	24	24	12	12	12
Duracell Part #	65W8049	65W8056	65W8043	65W8046	6W8052

For more information, call 800-463-9275,
contact your sales rep, or go online to www.newark.com

