

Cables & Connectivity Products



1111 W. 35th Street, Chicago, IL 60609
www.tripplite.com

Tripp Lite offers the most convenient, cost-effective solutions for connecting and controlling computers, electronic equipment and peripherals in any environment: corporate, education, retail, small/home office, IT lab, government, data center and more.

USB/FireWire® Solutions

Take advantage of the latest in USB and FireWire technology with high-speed data transfer rates up to 800 Mbps.

USB Cables	pp. 3
USB Hubs & Adapters	pp. 3–4
USB Sharing Switches & Hard Drive Enclosures	pp. 4
FireWire 800 Cables	pp. 4
FireWire Cables	pp. 5

Computer Solutions

Include superior molded construction and superior conductivity for all your computer connectivity needs.

Printer Cables	pp. 5
Modem/Null Modem Cables & Coupler	pp. 5
Ribbon & Internal Cables	pp. 5
Serial ATA (SATA) Cables	pp. 6
Keyboard/Mouse Cables	pp. 6
Automatic Switches	pp. 6
Straight-Through/Switch Cables	pp. 6
Miscellaneous Computer Adapters and Gender Changers	pp. 7
AC Power Cords	pp. 7–9

VGA Display Solutions

A wide array of cables and adapters available for connecting, splitting or extending a VGA signal over long distances.

VGA Display Cables	pp. 9–10
VGA Extension Cables	pp. 10
VGA Adapters	pp. 10
VGA Gender Changers	pp. 11
VGA Switches & Splitters	pp. 11
VGA Over Cat5 (UTP) Extenders	pp. 11
Easy Pull Base Cables (Type A)	pp. 12
Easy Pull VGA Connector Kits (Type A)	pp. 12
Easy Pull VGA All-in-One Kits	pp. 12

DVI Display Solutions

Provide high video resolutions and bandwidth rates for optimal video signals when connecting a DVI source to a display.

DVI Display Cables	pp. 13
DVI Adapters	pp. 13–14
DVI Splitters	pp. 14
DVI Signal Boosters	pp. 14
DVI Over Cat5 (UTP) Extenders	pp. 14
Easy Pull Base Cables (Type B)	pp. 15
Easy Pull DVI Connector Kits (Type B)	pp. 15
Easy Pull DVI All-in-One Kits	pp. 15

HDMI Display Solutions

Use reliable HDMI cables and extenders to connect an HDMI source to an HDTV display for crisp audio and video.

High-Speed HDMI Cables	pp. 15–16
HDMI Gender Changers	pp. 16
HDMI Splitters	pp. 16
HDMI Switches	pp. 16
HDMI Over Cat5 (UTP) Extenders	pp. 17

Continued on Page 2



Contact Us Today!

To Place Order: **773.869.1797** For Fax Orders: **773.869.1329**

For Technical Assistance: **773.869.1234** For Return Information: **773.869.1103**

For General Office:
773.869.1111

Audio/Video Solutions

Premium Audio/Video cables and extenders provide high-quality signal transfer to all points of digital signage applications.

Composite Video Cables (Yellow RCA Connector)	pp. 17
Component Video Cables (Red/Green/Blue RCA Connectors)	pp. 17
S-Video Cables	pp. 17
RG59 Coaxial Cables ("F" Type Connector)	pp. 18
Stereo Audio Cables (Red/White RCA Connectors)	pp. 18
Mini-Stereo Audio Cables	pp. 18
Digital Coax Audio Cables	pp. 18
Toslink Digital Optical Audio Cables	pp. 18
Audio Adapters and Cable Ties	pp. 18
Component Video and S-Video Splitters & Extenders	pp. 18

DisplayPort Cables & Adapters

With multiple lengths to choose from, and an array of adapters, DisplayPort cables convert signals across other standards, like HDMI and DVI.

DisplayPort Cables	pp. 19
DisplayPort Adapters & Gender Changers	pp. 19

Category 6/5e Network Solutions

Keep your network on the cutting edge by meeting the most current industry standards and providing fast data transfer.

Cat6 Shielded (STP) Patch Cables	pp. 19
Cat6 Snagless (UTP) Patch Cables	pp. 19–21
Cat6 Snagless (UTP) 24Awg, Solid Conductor Patch Cables	pp. 21
Cat6 (UTP) Patch Cables	pp. 21
Cat6 Snagless (UTP) Cross-Over Cables	pp. 21
Cat6a (Augmented Cat6) Snagless 10Gb Certified	pp. 21
Cat5/5e Retractable Patch Cable	pp. 22
Cat5e Shielded (STP) Patch Cables	pp. 22
Cat5e Snagless Patch Cables	pp. 22–23
Cat5e Patch Cables	pp. 23–24
Cat5e Outdoor-Rated Snagless Patch Cables	pp. 24
Cat5e Cross-Over Patch Cables	pp. 24
T1 Patch Cables	pp. 24
Cat5e Bulk Cables, Connectors & In-Line Couplers	pp. 25
Cat5e Patch Panels	pp. 25
Cat6 Bulk Cables & In-Line Coupler	pp. 25
Cat6 Patch Panels	pp. 25
Patch Panel Brackets	pp. 26
CX4 Cables	pp. 26

Fiber Optic Solutions

Provide nearly unlimited bandwidth at high speeds over long distances with a full line of fiber optic cables.

62.5/125 Multimode Fiber Optic Patch Cables	pp. 26–28
50/125 Multimode Fiber Optic Patch Cables	pp. 28–29
8.3/125 Singlemode Fiber Optic Patch Cables	pp. 29–30
Mode Conditioning Fiber Optic Patch Cables	pp. 30
10Gbps 50/125 Multimode Aqua Fiber Optic Patch Cables	pp. 30–31
40/100 Gbps 50/125 Multimedia Aqua OM4 Fiber Optic Patch Cables	pp. 31
Couplers	pp. 31
Media Converters	pp. 32
Adapters	pp. 32
Patch Panels	pp. 32

SCSI/SAS/Fibre Channel Solutions


Offer the latest SCSI/SAS cabling with cross-generational solutions to link all your system's SCSI/SAS devices.

SCSI Adapters	pp. 32
SCSI Terminators	pp. 32
SCSI Ribbon Cables	pp. 33
SCSI External Cables	pp. 33
SAS (Serial Attached SCSI) Cables	pp. 33

KVM Switch Solutions

Save time, money and space by controlling multiple computers from a single keyboard/monitor/mouse console.

KVM Switches	pp. 34–35
KVM Cable Kits	pp. 35
KVM Accessories	pp. 36

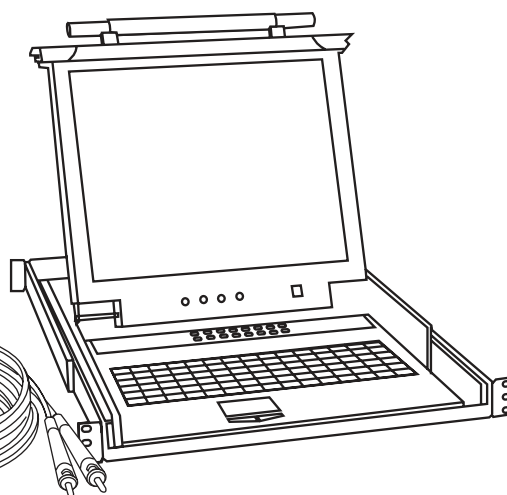

USB/FireWire® Solutions

A USB (Universal Serial Bus) port provides a universal connector to link digital cameras, printers and other peripherals to a computer. The USB's universal connector eliminates the need to add a costly and confusing array of adapters to your system. The significantly faster data transfer rates of FireWire and USB 2.0 make them perfect for multimedia applications.

USB Cables

- All Tripp Lite USB cables include superior foil shielding for reliable, error-free data communications
- Gold-plated contacts provide superior conductivity for low- and high-speed devices (1.5 to 480 Mbps)
- USB 2.0 hubs link multiple USB devices to one computer

Item #	Description	Length	Connector	Connector
U004-010-R	USB A/A Gold Extension Cable (Retail Package)	10 ft.	USB A (Male) A	USB A (Female) C
U005-10I	USB Right Angle Gold Extension Cable	10 in.	USB A (Male) A	USB A (Female) C
U021-003	USB 2.0 Certified A/B Device Cable	3 ft.	USB A (Male) A	USB B (Male) B
U022-006	USB 2.0 Certified Gold A/B Device Cable	6 ft.	USB A (Male) A	USB B (Male) B
U022-006-R	USB 2.0 Certified Gold A/B Device Cable (Retail Package)	6 ft.	USB A (Male) A	USB B (Male) B
U022-010	USB 2.0 Certified Gold A/B Device Cable	10 ft.	USB A (Male) A	USB B (Male) B
U022-010-R	USB 2.0 Certified Gold A/B Device Cable (Retail Package)	10 ft.	USB A (Male) A	USB B (Male) B
U022-015	USB 2.0 Certified Gold A/B Device Cable	15 ft.	USB A (Male) A	USB B (Male) B
U023-006	USB 2.0 Gold A/B Device Cable with Ferrite Chokes	6 ft.	USB A (Male) A	USB B (Male) B
U024-006	USB 2.0 Gold A/A Extension Cable	6 ft.	USB A (Male) A	USB A (Female) C
U024-010	USB 2.0 Gold A/A Extension Cable	10 ft.	USB A (Male) A	USB A (Female) C
U026-016	USB 2.0 Certified Active Extension Cable	16 ft.	USB A (Male) A	USB A (Female) C
U026-20M	USB 2.0 Certified Active Extension Cable	65 ft.	USB A (Male) A	USB A (Female) C
U028-006	USB 2.0 A to 4-Pin Mini-B Cable	6 ft.	USB A (Male) A	USB Mini-B 4-Pin (Male) D
U029-006	USB 2.0 A to 4-Pin Mini-B Cable	6 ft.	USB A (Male) A	USB Round Mini-B 4-Pin (Male) F
U030-003	USB 2.0 A to 5-Pin Mini-B Cable	3 ft.	USB A (Male) A	USB Mini-B 5-Pin (Male) E
U030-006	USB 2.0 A to 5-Pin Mini-B Cable	6 ft.	USB A (Male) A	USB Mini-B 5-Pin (Male) E
U032-004-R	USB 2.0 Retractable A/B Device Cable (Retail Package)	4 ft.	USB A (Male) A	USB B (Male) B
U042-036	USB 2.0 Extra-Long High-Speed Active Device Cable	36 ft.	USB A (Male) A	USB B (Male) B
U050-003	Micro-USB 2.0 Device Cable	3 ft.	USB A (Male) A	Micro-USB (Male) H
U050-006	Micro-USB 2.0 Device Cable	6 ft.	USB A (Male) A	Micro-USB (Male) H
U050-010	Micro-USB 2.0 Device Cable	10 ft.	USB A (Male) A	Micro-USB (Male) H
U322-003	USB 3.0 A/B Device Cable	3 ft.	USB 3.0 A (Male) G	USB 3.0 B (Male) I
U322-006	USB 3.0 A/B Device Cable	6 ft.	USB 3.0 A (Male) G	USB 3.0 B (Male) I
U322-010	USB 3.0 A/B Device Cable	10 ft.	USB 3.0 A (Male) G	USB 3.0 B (Male) I
U322-015	USB 3.0 A/B Device Cable	15 ft.	USB 3.0 A (Male) G	USB 3.0 B (Male) I
U324-006	USB 3.0 A/A Extension Cable	6 ft.	USB 3.0 A (Male) G	USB 3.0 A (Female) J
U324-010	USB 3.0 A/A Extension Cable	10 ft.	USB 3.0 A (Male) G	USB 3.0 A (Female) J
U326-003	USB 3.0 A/Micro-B Device Cable	3 ft.	USB 3.0 A (Male) G	USB 3.0 Micro-B (Male) K
U326-006	USB 3.0 A/Micro-B Device Cable	6 ft.	USB 3.0 A (Male) G	USB 3.0 Micro-B (Male) K
U326-010	USB 3.0 A/Micro-B Device Cable	10 ft.	USB 3.0 A (Male) G	USB 3.0 Micro-B (Male) K

USB Hubs & Adapters

- USB hubs link multiple USB devices to one computers
- Adapters link USB and non-USB computers and peripherals

Item #	Description	Length	Connector	Connector
B015-000	USB to PS/2 Adapter	—	USB A (Male) A	(x2) Mini DIN-6 (Female) M
B202-150	USB 1.1 Over Cat5 Extender Kit	—	USB A (Male) A RJ45 (Female) L	USB A (Female) C RJ45 (Female) L
B203-101	USB 2.0 Over Cat5 Extender Kit	—	USB A (Female) C RJ45 (Female) L	USB A (Female) C RJ45 (Female) L
U007-40M	USB 1.1 Over Cat5 Extender Kit	—	USB A (Male) A RJ45 (Female) L	USB A (Female) C RJ45 (Female) L
U206-006-R	USB to IEEE Gold Parallel Printer Adapter Cable	6 ft.	USB A (Male) A	Centronics 36 (Male) N
U207-006	USB to IEEE Parallel Printer Adapter Cable	6 ft.	USB A (Male) A	DB25 (Male) O
U209-000-R	USB Serial Adapter	17 in.	USB A (Male) A	DB9 (Male) P
U219-000-R	USB PS/2 Adapter	—	USB A (Male) A	(x2) Mini DIN-6 (Female) M

A USB A
(Male)



 
B USB B
(Male)



C USB A
(Female)



D USB Mini-B 4-Pin
(Male)




E USB Mini-B 5-Pin
(Male)



F USB Round
Mini-B 4-Pin (Male)



 G USB 3.0 A
(Male)




H Micro-USB
(Male)



I USB 3.0 B
(Male)



 J USB 3.0 A
(Female)



K USB 3.0 Micro-B
(Male)



 
L RJ45
(Female)



M Mini DIN-6
(Female)



N Centronics 36
(Male)



O DB25
(Male)



P DB9
(Male)



USB/FireWire Solutions (continued)

USB Hubs & Adapters (continued)

Item #	Description	Length	Connector	Connector
U222-004-R	USB 2.0 Hub, 4 Port	—	(x4) USB A (Female) A	USB A (Male) B
U222-007-R	USB 2.0 Hub, 7 Port	—	(x7) USB A (Female) A	USB B (Female) C
U222-010-R	USB 2.0 Hub, 10 Port	—	(x10) USB A (Female) A	USB Mini-B 5-Pin (Female) D
U224-1R4-R	USB Over Cat5 Extender Hub, 3 Local, 1 Remote Port	—	USB A (Male) B (x3) USB A (Female) A RJ45 (Female) E	RJ45 (Female) E USB A (Female) A
U224-4R4-R	USB 1.1 Over Cat5 Extender Hub, 4 Remote Ports	—	USB A (Male) B RJ45 (Female) E	RJ45 (Female) E (x4) USB A (Female) A
U225-004-R	USB 2.0 Hub, 4-Port	—	USB Mini-B 5-Pin (Female) D	(x4) USB A (Female) A
U227-FT3-R	USB 2.0 Hub with File Transfer Capability, 3-Port	—	USB A (Male) B	USB Mini-B 5-Pin (Female) D (x3) USB A (Female) A
U233-006-PP-R	USB 2.0 PC/PC Easy File Transfer Cable	6 ft.	USB A (Male) B	USB A (Male) B
U233-006-MP-R	USB 2.0 PC/MAC Easy File Transfer Cable	6 ft.	USB A (Male) B	USB A (Male) B
U236-000-R	USB 2.0 to Ethernet Adapter	—	USB A (Male) B	RJ45 (Female) E
U238-000	USB 2.0 to SATA/IDE Adapter	1 ft.	USB A (Male) B	7-Pin SATA (Female) F 40-Pin IDE (Female) G
U239-UE1	USB 2.0 eSATA SATA Hard Drive Quick Doc	—	USB A (Male) B	22-PIN SATA + Power (Female) H
U244-001-R	USB 2.0 to DVI-I/VGA Adapter	—	USB Mini-B 5-Pin (Female) D	DVI-I (Female) I
U244-001-HDMI-R	USB 2.0 to HDMI Adapter	—	USB Mini-B 5-Pin (Female) D	HDMI (Female) J
U244-001-VGA-R	USB 2.0 to VGA Adapter	—	USB Mini-B 5-Pin (Female) D	HD15 (Female) K
U338-000-R	USB 3.0 Super Speed to SATA Adapter Cable	—	USB 3.0 A (Male) L	22-PIN SATA + Power (Female) H
U360-004-R	USB 3.0 Super Speed Hub	—	USB 3.0 B (Female) M	(x4) USB 3.0 A (Female) N
USA-19HS	Keyspan by Tripp Lite USB Serial Adapter	3 ft.	DB9 (Male) O	USB A (Male) B
USA-28XG	Keyspan by Tripp Lite USB Twin Serial Adapter for Mac	—	Mini DIN-8 (Female) P	USB A (Male) B
USA-49WG	Keyspan by Tripp Lite USB Serial Adapter, 4-Port	—	USB A (Female) A	(x4) DB9 (Male) O

USB Sharing Switches & Hard Drive Enclosures

- USB sharing switch allows up to four computers to share one printer
- Hard drive enclosure allows you to access data while traveling

Item #	Description	Ports	Connector	Connector
U215-004-R	USB Peripheral Sharing Switch	4	USB B (Female) C	USB A (Female) A
U230-204-R	USB 2.0 2-to-4 Share Switch with File Transfer	4	(x2) USB B (Female) C	(x4) USB A (Female) A
U256-025	USB 2.0 2.5in IDE External Hard Drive Enclosure	-	USB Mini-B 5-Pin (Female) D	44-Pin IDE (Female) G
U256-035	USB 2.0 3.5in IDE External Hard Drive Enclosure	-	USB B (Female) C	40-Pin IDE (Female) G 4-Pin Molex (Female) B
U257-025	USB 2.0 2.5in SATA External Hard Drive Enclosure	-	USB A (Male) B	22-PIN SATA + Power (Female) H
U258-035	USB 2.0 eSATA 3.5in SATA External Hard Drive Enclosure	-	USB B (Female) C 7-Pin eSATA (Female) F	22-PIN SATA + Power (Female) H
U357-025-R	USB 3.0 Super Speed 2.5" SATA External Hard Drive Enclosure	—	USB 3.0 Micro-B (Female) S	22-PIN SATA + Power (Female) H

FireWire 800 Cables

- Twice the speed of original FireWire—data transfers up to 800 Mbps
- Backward-compatible to original FireWire components

Item #	Description	Length	Connector	Connector
F015-006	IEEE 1394b FireWire 800 Gold Hi-Speed Cable	6 ft.	9-Pin (Male) T	9-Pin (Male) T
F015-010	IEEE 1394b FireWire 800 Gold Hi-Speed Cable	10 ft.	9-Pin (Male) T	9-Pin (Male) T
F017-006	IEEE 1394b FireWire 800 Gold Hi-Speed Cable	6 ft.	9-Pin (Male) T	6-Pin (Male) U
F017-010	IEEE 1394b FireWire 800 Gold Hi-Speed Cable	10 ft.	9-Pin (Male) T	6-Pin (Male) U
F019-006	IEEE 1394b FireWire 800 Gold Hi-Speed Cable	6 ft.	9-Pin (Male) T	4-Pin (Male) V
F019-010	IEEE 1394b FireWire 800 Gold Hi-Speed Cable	10 ft.	9-Pin (Male) T	4-Pin (Male) V

A USB A (Female)



B USB A (Male)



C USB B (Female)



D USB Mini-B 5-Pin (Female)



E RJ45 (Female)



 
F 7-Pin SATA (Female)



G 40-Pin IDE (Female)



H 22-PIN SATA + Power (Female)



I DVI-I (Female)



 
J HDMI (Female)



K HD15 (Female)



L USB 3.0 A (Male)



M USB 3.0 B (Female)



N USB 3.0 A (Female)



O DB9 (Male)



 
P Mini DIN-8 (Female)



Q 44-Pin IDE (Female)



R 4-Pin Molex (Female)



S USB 3.0 Micro-B (Female)



T 9-Pin (Male)



U 6-Pin (Male)



V 4-Pin (Male)



USB/FireWire Solutions (continued)

FireWire Cables

- Premium quadruple-shielded cables with tinned copper braid and aluminum mylar foil on each twisted pair as well as on the cable as a whole—data transfers up to 400 Mbps

Item #	Description	Length	Connector	Connector
F005-006	IEEE 1394 FireWire Gold Cable	6 ft.	6-Pin (Male) A	6-Pin (Male) A
F005-015	IEEE 1394 FireWire Gold Cable	15 ft.	6-Pin (Male) A	6-Pin (Male) A
F007-003	IEEE 1394 FireWire Gold Cable	3 ft.	6-Pin (Male) A	4-Pin (Male) B
F007-006	IEEE 1394 FireWire Gold Cable	6 ft.	6-Pin (Male) A	4-Pin (Male) B
F007-015	IEEE 1394 FireWire Gold Cable	15 ft.	6-Pin (Male) A	4-Pin (Male) B
F009-006	IEEE 1394 FireWire Gold Cable	6 ft.	4-Pin (Male) B	4-Pin (Male) B

Computer Solutions

Maximize the functionality of your desktop or notebook computer and peripherals with an assortment of cables, adapters and more, featuring the latest high-speed data-transfer technology.

Printer Cables

- Superior molded cables with integral strain relief and foil shielding for maximum EMI/RFI protection

Item #	Description	Length	Connector	Connector
P602-010	Bi-Directional Parallel Printer Cable	10 ft.	DB25 (Male) C	Centronics 36 (Male) D
P606-003	IEEE 1284 Gold Parallel Printer A/B Cable	3 ft.	DB25 (Male) C	Centronics 36 (Male) D
P606-006	IEEE 1284 Gold Parallel Printer A/B Cable	6 ft.	DB25 (Male) C	Centronics 36 (Male) D
P606-010	IEEE 1284 Gold Parallel Printer A/B Cable	10 ft.	DB25 (Male) C	Centronics 36 (Male) D
P606-015	IEEE 1284 Gold Parallel Printer A/B Cable	15 ft.	DB25 (Male) C	Centronics 36 (Male) D
P608-006	IEEE 1284 Gold Parallel Printer A/C Cable	6 ft.	DB25 (Male) C	Mini Centronics 36 (Male) E

Modem/Null Modem Cables & Coupler

- Superior molded cables with foil shielding for maximum EMI/RFI protection
- In-line coupler inexpensively extends two telephone cords

Item #	Description	Length	Connector	Connector
P402-006-R	Serial Modem Gold Cable (Retail Package)	6 ft.	DB25 (Female) F	DB25 (Male) C
P404-006	AT Serial Modem Gold Cable	6 ft.	DB9 (Female) G	DB25 (Male) C
P410-007-SR	Fax/Modem Silver Flat Patch Cable	7 ft.	RJ11 (Male) H	RJ11 (Male) H
P420-001	RJ11 In-Line Coupler	—	RJ11 (Female) I	RJ11 (Female) I
P450-000	Null Modem Adapter Kit - 2-Pack	—	RJ45 (Female) J	DB9 (Female) G
P450-006	Null Modem Gold Cable	6 ft.	DB9 (Female) G	DB9 (Female) G
P450-010	Null Modem Gold Cable	10 ft.	DB9 (Female) G	DB9 (Female) G
P454-006	Null Modem Gold Cable	6 ft.	DB9 (Male) K	DB9 (Female) G
P456-006	Null Modem Gold Cable	6 ft.	DB9 (Female) G	DB25 (Male) C

Ribbon & Internal Cables

- An assortment of high-quality ribbon cables, power cables and CD-ROM cable assemblies

Item #	Description	Length	Connector	Connector
P906-18I	UATA/UDMA EIDE 2-Drive Ribbon Cable	18 in.	—	(x3) 40-Pin IDE (Female) L
P906-18I-BP	UATA/UDMA EIDE 2-Drive Ribbon Cable (Bulk Pack)	18 in.	—	(x3) 40-Pin IDE (Female) L
P906-24I	UATA/UDMA EIDE 2-Drive Ribbon Cable	24 in.	—	(x3) 40-Pin IDE (Female) L
P906-26I	UATA/UDMA EIDE 2-Drive Ribbon Cable	26 in.	—	(x3) 40-Pin IDE (Female) L
P920-006	Power Y Splitter 5.25" Cable	6 in.	4-Pin (Male) B	(x2) 4-Pin Molex (Female) M
P930-26I	Universal CD-ROM Audio Cable Assembly	26 in.	—	—

A 6-Pin
(Male)



I RJ11
(Female)



 
B 4-Pin
(Male)



J RJ45
(Female)




C DB25
(Male)



K DB9
(Male)



 
D Centronics 36
(Male)



L 40-Pin IDE
(Female)



 E Mini Centronics
36 (Male)



M 4-Pin Molex
(Female)



F DB25
(Female)



G DB9
(Female)



H RJ11
(Male)



Serial ATA (SATA) Cables

- Signal cables connect any high-speed Serial ATA device to a Serial ATA controller
- Support much higher data transfer rates (up to 1.5 Gbps)
- Design helps improve internal air flow

Item #	Description	Length	Connector	Connector
P936-000	Serial ATA (SATA) Converter	—	40-Pin IDE (Female) A 4-Pin (Male) B	7-Pin SATA (Female) C
P940-08I	Serial ATA (SATA) Signal Cable	8 in.	7-Pin SATA (Male) D	7-Pin SATA (Male) D
P940-19I	Serial ATA (SATA) Signal Cable	19 in.	7-Pin SATA (Male) D	7-Pin SATA (Male) D
P940-39I	Serial ATA (SATA) Signal Cable	39 in.	7-Pin SATA (Male) D	7-Pin SATA (Male) D
P941-19I	Serial ATA (SATA) Signal Cable	19 in.	7-Pin SATA (Male) D	7-Pin SATA Right-Angle Up (M) E
P942-19I	Serial ATA (SATA) Signal Cable	19 in.	7-Pin SATA (Male) D	7-Pin SATA Right-Angle Down (M) F
P943-19I	Serial ATA (SATA) Signal Cable	19 in.	7-Pin SATA Right-Angle Up (M) E	7-Pin SATA Right-Angle Down (M) F
P944-06I	Serial ATA (SATA) Power Cable	6 in.	15-Pin SATA Power G	4-Pin (Male) B
P945-06I	Serial ATA (SATA) Power Adapter/Extension Cable	6 in.	15-Pin SATA Power G	(x2) 4-Pin (Male) B
P946-12I	Serial ATA (SATA) Dual Power Adapter Cable	12 in.	4-Pin (Male) B	(x2) 15-Pin SATA Power G
P950-18I	Serial ATA (eSATA) II Signal Cable	18 in.	7-Pin eSATA (Male) H	7-Pin eSATA (Male) H
P950-36I	Serial ATA (eSATA) II Signal Cable	36 in.	7-Pin eSATA (Male) H	7-Pin eSATA (Male) H
P950-02M	Serial ATA (eSATA) II Signal Cable	6 ft.	7-Pin eSATA (Male) H	7-Pin eSATA (Male) H
P952-002	SATA to eSATA Transition Cable w/Bracket	2 ft.	7-Pin SATA (Male) D	7-Pin eSATA (Female) I
P952-003	SATA to eSATA Transition Cable	3 ft.	7-Pin eSATA (Male) H	7-Pin SATA (Male) D
P952-18I	SATA to eSATA Transition Cable	18 in.	7-Pin eSATA (Male) H	7-Pin SATA (Male) D

Keyboard/Mouse Cables

- AT and PS/2 keyboard cables connect keyboards and mice to a computer

Item #	Description	Length	Connector	Connector
P222-006	PS/2 Keyboard/Mouse Extension Cable	6 ft.	Mini DIN-6 (Male) J	Mini DIN-6 (Female) K
P222-010	PS/2 Keyboard/Mouse Extension Cable	10 ft.	Mini DIN-6 (Male) J	Mini DIN-6 (Female) K
P222-015	PS/2 Keyboard/Mouse Extension Cable	15 ft.	Mini DIN-6 (Male) J	Mini DIN-6 (Female) K
P222-025	PS/2 Keyboard/Mouse Extension Cable	25 ft.	Mini DIN-6 (Male) J	Mini DIN-6 (Female) K
P222-050	PS/2 Keyboard/Mouse Extension Cable	50 ft.	Mini DIN-6 (Male) J	Mini DIN-6 (Female) K
P230-001	PS/2 Keyboard/Mouse Y Splitter Cable	1 ft.	Mini DIN-6 (Male) J	(x2) Mini DIN-6 (Female) K

Automatic Switches

- Automatic, hands-free switching
- No external power source required
- Reversible design allows multiple computers to share one printer or one computer to use multiple printers

Item #	Description	Ports	Connector
B170-002-R	IEEE Reversible 2 Position Gold Autoswitch (Retail Package)	2	(x3) DB25 (Female) L

Straight-Through/Switch Cables

- Connect a computer to either a manual or automatic switchbox
- Feature a superior molded design to ensure durability
- Gold-plated connectors and contacts offer superior conductivity

Item #	Description	Length	Connector	Connector
P710-006	IEEE 1284 Straight-Through Gold Cable	6 ft.	DB25 (Male) M	DB25 (Male) M

A 40-Pin IDE (Female)



B 4-Pin (Male)



C 7-Pin SATA (Female)



D 7-Pin SATA (Male)



 
E 7-Pin SATA Right-Angle Up (M)



F 7-Pin SATA Right-Angle Down (M)



G 15-Pin SATA Power



H 7-Pin eSATA (Male)



I 7-Pin eSATA (Female)



J Mini DIN-6 (Male)



 
K Mini DIN-6 (Female)



L DB25 (Female)



M DB25 (Male)



Miscellaneous Computer Adapters and Gender Changers

- AT, PS/2, Serial, Null Modem adapters convert a variety of connections and are an inexpensive alternative to buying new cables
- Gold gender changers allow you to connect male/female cables

Item #	Description	Length	Connector	Connector
P100-000-R	AT Serial Gold Adapter (Retail Package)	—	DB9 (Female) A	DB25 (Male) B
P106-000	AT to PS/2 Keyboard Adapter	—	DIN-5 (Female) C	Mini DIN-6 (Male) D
P108-000	PS/2 to AT Keyboard Adapter	—	DIN-5 (Male) E	Mini DIN-6 (Female) F
P108-000-R	PS/2 to AT Keyboard Adapter (Retail Package)	—	DIN-5 (Male) E	Mini DIN-6 (Female) F
P110-000-R	PS/2 to Serial Combo Mouse (Retail Package)	—	Mini DIN-6 (Male) D	DB9 (Male) G
P112-000	PS/2 to Serial Combo Mouse	—	Mini DIN-6 (Female) F	DB9 (Female) A
P150-000	DB9 Male-to-Female Gender Changer	—	DB9 (Female) A	DB9 (Female) A
P152-000	DB9 Female-to-Male Gender Changer	—	DB9 (Male) G	DB9 (Male) G
P154-000	DB25 Male-to-Female Gender Changer	—	DB25 (Female) H	DB25 (Female) H
P156-000	DB25 Female-to-Male Gender Changer	—	DB25 (Male) B	DB25 (Male) B

AC Power Cords

- Deliver AC power to a variety of electronic equipment

C5 Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P013-006	C5 to 5-15P Power Cord, 120V, 2.5A	6 ft.	C5 I	5-15P J
P014-06N	C5 to C14 Power Adapter Cord, 100-250V, 2.5A	6 in.	C5 I	C14 K
P014-006	C5 to C14 Power Adapter Cord, 100-250V, 2.5A	6 ft.	C5 I	C14 K

C7 Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P012-006	C7 to 1-15P Power Cord (Non-Polarized), 120V, 10A	6 ft.	C7 L	1-15P M


C13 Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P030-002-5	5-Pack of C13 to 5-15P Power Cords, 120V, 10A	2 ft.	C13 N	5-15P J
P007-002	C13 to 5-15P Heavy Duty Power Cord, 120V, 15A	2 ft.	C13 N	5-15P J
P006-003	C13 to 5-15P Power Cord, 120V, 10A	3 ft.	C13 N	5-15P J
P006-004	C13 to 5-15P Power Cord, 120V, 10A	4 ft.	C13 N	5-15P J
P006-004-GN	C13 to 5-15P Power Cord with Green Connectors, 120V, 10A	4 ft.	C13 N	5-15P J
P006-004-RD	C13 to 5-15P Power Cord with Red Connectors, 120V, 10A	4 ft.	C13 N	5-15P J
P006-004-YW	C13 to 5-15P Power Cord with Yellow Connectors, 120V, 10A	4 ft.	C13 N	5-15P J
P006-006	C13 to 5-15P Power Cord, 120V, 10A	6 ft.	C13 N	5-15P J
P006-006-13LA	Left-Angle C13 to 5-15P Power Cord, 120V, 10A	6 ft.	C13 N	5-15P J
P006-006-13RA	Right-Angle C13 to 5-15P Power Cord, 120V, 10A	6 ft.	C13 N	5-15P J
P006-006-515MF	C13 to 5-15P/R Piggyback Power Cord, 120V, 10A	6 ft.	C13 N	5-15P/R J / O
P006-006-2	(x2) C13 to 5-15P Power Splitter Cord, 120V, 10A	6 ft.	(x2) C13 N	5-15P J
P007-006	C13 to 5-15P Heavy Duty Power Cord, 120V, 15A	6 ft.	C13 N	5-15P J
P006-010	C13 to 5-15P Power Cord, 120V, 10A	10 ft.	C13 N	5-15P J
P007-010	C13 to 5-15P Heavy Duty Power Cord, 120V, 15A	10 ft.	C13 N	5-15P J
P010-012	C13 to 5-15P Power Cord, 120V, 10A	12 ft.	C13 N	5-15P J
P011-006	C13 to L6-20P Power Cord, 250V, 15A	6 ft.	C13 N	L6-20P P
P005-12N	C13 to C14 Heavy Duty Power Extension Cord, 100-250V, 15A	12 in.	C13 N	C14 K
P005-18N	C13 to C14 Heavy Duty Power Extension Cord, 100-250V, 15A	18 in.	C13 N	C14 K
P004-002-5	5-Pack of C13 to C14 Power Extension Cords, 100-250V, 10A	2 ft.	C13 N	C14 K
P004-002-13LA	Left-Angle C13 to C14 Power Extension Cord, 100-250V, 10A	2 ft.	C13 N	C14 K
P004-002-13RA	Right-Angle C13 to C14 Power Extension Cord, 100-250V, 10A	2 ft.	C13 N	C14 K
P005-002	C13 to C14 Heavy Duty Power Extension Cord, 100-250V, 15A	2 ft.	C13 N	C14 K
P004-004	C13 to C14 Power Extension Cord, 100-250V, 10A	4 ft.	C13 N	C14 K
P004-004-GN	C13 to C14 Power Extension Cord with Green Connectors, 100-250V, 10A	4 ft.	C13 N	C14 K

A DB9
(Female)



 B DB25
(Male)



C DIN-5
(Female)



D Mini DIN-6
(Male)



E DIN-5
(Male)



F Mini DIN-6
(Female)



G DB9
(Male)



H DB25
(Female)



I C5
(Female)



J 5-15P
(Male)



K C14
(Male)



L C7
(Female)



M 1-15P
(Male)



N C13
(Female)



O 5-15R
(Female)



P L6-20P
(Male)



AC Power Cords (continued)

C13 Power Cords (continued)

Item #	Description	Length	Connector (Female)	Connector (Male)
P004-004-RD	C13 to C14 Power Extension Cord with Red Connectors, 100-250V, 10A	4 ft.	C13 A	C14 B
P004-004-YW	C13 to C14 Power Extension Cord with Yellow Connectors, 100-250V, 10A	4 ft.	C13 A	C14 B
P004-006	C13 to C14 Power Extension Cord, 100-250V, 10A	6 ft.	C13 A	C14 B
P004-006-2C13	(x2) C13 to C14 Power Splitter Cord, 100-250V, 10A	6 ft.	(x2) C13 A	C14 B
P005-006	C13 to C14 Heavy Duty Power Extension Cord, 100-250V, 15A	6 ft.	C13 A	C14 B
P005-006-GN	C13 to C14 Heavy Duty Power Extension Cord with Green Connectors, 100-250V, 15A	6 ft.	C13 A	C14 B
P005-006-RD	C13 to C14 Heavy Duty Power Extension Cord with Red Connectors, 100-250V, 15A	6 ft.	C13 A	C14 B
P005-006-YW	C13 to C14 Heavy Duty Power Extension Cord with Yellow Connectors, 100-250V, 15A	6 ft.	C13 A	C14 B
P005-010	C13 to C14 Heavy Duty Power Extension Cord, 100-250V, 15A	10 ft.	C13 A	C14 B
P032-002-2C13	(x2) C13 to C20 Power Splitter Cord, 100-250V, 15A	2 ft.	(x2) C13 A	C20 C
P032-007	C13 to C20 Power Adapter Cord, 100-250V, 15A	7 ft.	C13 A	C20 C

C14 Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P002-002	5-15R to C14 Power Adapter Cord, 120V, 13A	2 ft.	5-15R D	C14 B
P047-002	C19 to C14 Power Adapter Cord, 100-250V, 15A	2 ft.	C19 E	C14 B
P047-004	C19 to C14 Power Adapter Cord, 100-250V, 15A	4 ft.	C19 E	C14 B
P047-006	C19 to C14 Power Adapter Cord, 100-250V, 15A	6 ft.	C19 E	C14 B
P047-010	C19 to C14 Power Adapter Cord, 100-250V, 15A	10 ft.	C19 E	C14 B

C15 Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P018-003	C15 to C14 Power Adapter Cord, 100-250V, 15A	3 ft.	C15 F	C14 B
P018-006	C15 to C14 Power Adapter Cord, 100-250V, 15A	6 ft.	C15 F	C14 B

C19 Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P034-010	C19 to 5-15P Power Cord, 120V, 15A	10 ft.	C19 E	5-15P G
P049-010	C19 to 5-20P Power Cord, 120V, 20A	10 ft.	C19 E	5-20P H
P040-006	C19 to L6-20P Power Cord, 250V, 20A	6 ft.	C19 E	L6-20P I
P040-010	C19 to L6-20P Power Cord, 250V, 20A	10 ft.	C19 E	L6-20P I
P040-014	C19 to L6-20P Power Cord, 250V, 20A	14 ft.	C19 E	L6-20P I
P045-010	C19 to L5-20P Power Cord, 120V, 20A	10 ft.	C19 E	L6-20P I
P070-010	C19 to Blue IEC-309 16A 2P+E Power Cord, 250V, 16A	10 ft.	C19 E	Blue IEC-309 16A 2P+E J
P036-002	C19 to C20 Power Extension Cord, 100-250V, 20A	2 ft.	C19 E	C20 C
P036-002-19LA	Left-Angle C19 to C20 Power Extension Cord, 100-250V, 20A	2 ft.	C19 E	C20 C
P036-002-19RA	Right-Angle C19 to C20 Power Extension Cord, 100-250V, 20A	2 ft.	C19 E	C20 C
P036-002-20LA	C19 to Left-Angle C20 Power Extension Cord, 100-250V, 20A	2 ft.	C19 E	C20 C
P036-002-20RA	C19 to Right-Angle C20 Power Extension Cord, 100-250V, 20A	2 ft.	C19 E	C20 C
P036-006	C19 to C20 Power Extension Cord, 100-250V, 20A	6 ft.	C19 E	C20 C
P036-006-2C19	(x2) C19 to C20 Power Splitter Cord, 100-250V, 20A	6 ft.	(x2) C19 E	C20 C

5-15P Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P022-001	5-15R to 5-15P Power Extension Cord, 120V, 10A	1 ft.	5-15R D	5-15P G
P022-001-2	(x2) 5-15R to 5-15P Power Splitter Cord, 120V, 10A	1 ft.	(x2) 5-15R D	5-15P G
P022-015	5-15R to 5-15P Power Extension Cord, 120V, 10A	15 ft.	5-15R D	5-15P G
P022-025	5-15R to 5-15P Power Extension Cord, 120V, 10A	25 ft.	5-15R D	5-15P G
P023-001	L5-15R to 5-15P Power Adapter Cord, 120V, 15A	1 ft.	L5-15R K	5-15P G

A C13
(Female)



B C14
(Male)



C C20
(Male)



D 5-15R
(Female)



E C19
(Female)



F C15
(Female)



G 5-15P
(Male)



H 5-20P
(Male)



I L6-20P
(Male)



J Blue IEC-309
16A 2P+E (Male)



K L5-15R
(Female)



Computer Solutions (continued)

AC Power Cords (continued)

L5-20R Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P044-06I	L5-20R to 5-20P Power Adapter Cord, 120V, 20A	6 in.	L5-20R 	5-20P 
P046-06N	L5-20R to L5-20P Power Extension Cord, 120V, 20A	6 in.	L5-20R 	L5-20P 
P043-002	L5-20R to L5-30P Power Adapter with 20-Amp Breaker, 120V, 20A	2 ft.	L5-20R 	L5-30P 

L6-20P Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P039-001-2	(x2) L6-20R to L6-20P Power Splitter Cord, 250V, 20A	1 ft.	(x2) L6-20R 	L6-20P 

L6-30P Power Cords

Item #	Description	Length	Connector (Female)	Connector (Male)
P041-001-2	(x2) L6-30R to L6-30P Power Splitter Cord, 250V, 30A	1 ft.	(x2) L6-30R 	L6-30P 
P041-008	L6-30R to L6-30P Power Extension Cord, 250V, 30A	8 ft.	L6-30R 	L6-30P 

International Power Cords

Item #	Description	Length	Connector	Connector
P050-008	CEE 7/7 SHUKO to C19 Power Cord, 250V, 16A	8 ft.	CEE 7/7 SHUKO 	C19 
P052-008	BS1363 UK to C19 Power Cord, 250V, 13A	8 ft.	BS1363 UK 	C19 
P054-006	CEE 7/7 SHUKO to C13 Power Cord, 250V, 10A	6 ft.	CEE 7/7 SHUKO 	C13 
P056-006	BS1363 UK to C13 Power Cord, 250V, 5A	6 ft.	BS1363 UK 	C13 
P058-006	CEE 7/7 SHUKO to C5 Power Cord, 250V, 2.5A	6 ft.	CEE 7/7 SHUKO 	C5 
P060-006	BS1363 UK to C5 Power Cord, 250V, 2.5A	6 ft.	BS1363 UK 	C5 

VGA Display Solutions

VGA Solutions provide a wide range of cables and adapters that connect, split or extend a VGA signal. Ideal for connecting a local computer monitor or extending a display signal farther from the source, these cables extend signals up to 2,000 ft.

VGA Display Cables

- Directly connect a computer and display
- Standard and plenum-rated cables up to 100 ft.

Item #	Description	Length	Connector (Female)	Connector (Male)
P502-001	SVGA/VGA Gold Monitor Cable	1 ft.	HD15 (Male) 	HD15 (Male) 
P502-003	SVGA/VGA Gold Monitor Cable	3 ft.	HD15 (Male) 	HD15 (Male) 
P502-006	SVGA/VGA Gold Monitor Cable	6 ft.	HD15 (Male) 	HD15 (Male) 
P502-010	SVGA/VGA Gold Monitor Cable	10 ft.	HD15 (Male) 	HD15 (Male) 
P502-015	SVGA/VGA Gold Monitor Cable	15 ft.	HD15 (Male) 	HD15 (Male) 
P502-025	SVGA/VGA Gold Monitor Cable	25 ft.	HD15 (Male) 	HD15 (Male) 
P502-050	SVGA/VGA Gold Monitor Cable	50 ft.	HD15 (Male) 	HD15 (Male) 
P502-100	SVGA/VGA Gold Monitor Cable	100 ft.	HD15 (Male) 	HD15 (Male) 

VGA Display Cables with Right-Angle Connectors

Item #	Description	Length	Connector	Connector
P502-003-RA	SVGA/VGA Gold Monitor Cable, Right-Angle Connector	3 ft.	HD15 (Male) 	HD15 (Male) 
P502-006-RA	SVGA/VGA Gold Monitor Cable, Right-Angle Connector	6 ft.	HD15 (Male) 	HD15 (Male) 
P502-010-RA	SVGA/VGA Gold Monitor Cable, Right-Angle Connector	10 ft.	HD15 (Male) 	HD15 (Male) 
P502-025-RA	SVGA/VGA Gold Monitor Cable, Right-Angle Connector	25 ft.	HD15 (Male) 	HD15 (Male) 

VGA Cables with Low-Profile Connectors

Item #	Description	Length	Connector	Connector
P502-003-SM	SVGA/VGA Gold Monitor Cable, Low-Profile Connectors	3 ft.	HD15 (Male) 	HD15 (Male) 
P502-006-SM	SVGA/VGA Gold Monitor Cable, Low-Profile Connectors	6 ft.	HD15 (Male) 	HD15 (Male) 

Plenum-Rated VGA Display Cables

Item #	Description	Length	Connector	Connector
P502-025-P	Plenum-Rated SVGA/VGA Gold Monitor Cable	25 ft.	HD15 (Male) 	HD15 (Male) 
P502-050-P	Plenum-Rated SVGA/VGA Gold Monitor Cable	50 ft.	HD15 (Male) 	HD15 (Male) 

 L5-20R
(Female)

 CEE 7/7
SHUKO

 5-20P
(Male)

 C19
(Female)

 L5-20P
(Male)

 BS1363
UK

 L5-30P
(Male)

 C13
(Female)

 L6-20R
(Female)

 C5
(Female)

 L6-20P
(Male)

 HD15
(Male)

 L6-30R
(Female)

 L6-30P
(Male)

VGA Display Solutions (continued)

VGA Display Cables (continued)

VGA + Audio Cables

Item #	Description	Length	Connector	Connector
P504-006	SVGA/VGA Gold Monitor Cable with Audio	6 ft.	HD15 (Male) A 3.5 mm (Male) B	HD15 (Male) A 3.5 mm (Male) B
P504-010	SVGA/VGA Gold Monitor Cable with Audio	10 ft.	HD15 (Male) A 3.5 mm (Male) B	HD15 (Male) A 3.5 mm (Male) B
P504-015	SVGA/VGA Gold Monitor Cable with Audio	15 ft.	HD15 (Male) A 3.5 mm (Male) B	HD15 (Male) A 3.5 mm (Male) B
P504-025	SVGA/VGA Gold Monitor Cable with Audio	25 ft.	HD15 (Male) A 3.5 mm (Male) B	HD15 (Male) A 3.5 mm (Male) B
P504-050	SVGA/VGA Gold Monitor Cable with Audio	50 ft.	HD15 (Male) A 3.5 mm (Male) B	HD15 (Male) A 3.5 mm (Male) B

VGA + Audio Cables with Low-Profile Connectors

Item #	Description	Length	Connector	Connector
P504-003-SM	SVGA/VGA Gold Monitor Cable with Audio, Low-Profile Connectors	3 ft.	HD15 (Male) A 3.5 mm (Male) B	HD15 (Male) A 3.5 mm (Male) B
P504-006-SM	SVGA/VGA Gold Monitor Cable with Audio, Low-Profile Connectors	6 ft.	HD15 (Male) A 3.5 mm (Male) B	HD15 (Male) A 3.5 mm (Male) B

Plenum-Rated VGA + Audio Cable

Item #	Description	Length	Connector	Connector
P504-025-P	Plenum-Rated SVGA/VGA Gold Monitor Cable with Audio	25 ft.	HD15 (Male) A 3.5 mm (Male) B	HD15 (Male) A 3.5 mm (Male) B

VGA Extension Cables

- Extend the length of an existing display cable
- Standard and plenum-rated cables up to 100 ft.

Item #	Description	Length	Connector	Connector
P500-006	VGA Display Extension Cable	6 ft.	HD15 (Male) A	HD15 (Female) C
P500-010	VGA Display Extension Cable	10 ft.	HD15 (Male) A	HD15 (Female) C
P500-025	VGA Display Extension Cable	25 ft.	HD15 (Male) A	HD15 (Female) C
P500-050	VGA Display Extension Cable	50 ft.	HD15 (Male) A	HD15 (Female) C
P500-075	VGA Display Extension Cable	75 ft.	HD15 (Male) A	HD15 (Female) C
P500-100	VGA Display Extension Cable	100 ft.	HD15 (Male) A	HD15 (Female) C

Plenum-Rated VGA Extension Cable

Item #	Description	Length	Connector	Connector
P500-100-P	Plenum-Rated VGA Display Extension Cable	100 ft.	HD15 (Male) A	HD15 (Female) C

VGA Adapters


- Connect a VGA display or source to a dissimilar display or source

Item #	Description	Length	Connector	Connector
P120-000	DVI to VGA Adapter	—	DVI-A (Male) D	HD15 (Female) C
P120-001-2	DVI to VGA Cable Splitter	1 ft.	DVI-A (Male) D	(x2) HD15 (Female) C
P126-000	DVI to VGA Adapter	—	DVI-I (Female) E	HD15 (Male) A
P134-06N-VGA	DisplayPort to VGA Adapter	6 in.	DisplayPort (Male) F	HD15 (Female) C
P137-06N-VGA	Mini-DisplayPort to VGA Adapter	6 in.	Mini-DisplayPort (Male) G	HD15 (Female) C
P556-003	DVI Analog Source to VGA Display Cable	3 ft.	DVI-A (Male) D	HD15 (Male) A
P556-006	DVI Analog Source to VGA Display Cable	6 ft.	DVI-A (Male) D	HD15 (Male) A
P556-010	DVI Analog Source to VGA Display Cable	10 ft.	DVI-A (Male) D	HD15 (Male) A
P574-001	DMS59 to (2) VGA Splitter Cable	1 ft.	DMS59 (Male) H	(x2) HD15 (Female) C
U244-001-VGA-R	USB 2.0 to VGA Adapter	—	USB Mini-B 5-Pin (Female) I	HD15 (Female) C

A HD15
(Male)



 
B 3.5 mm
(Male)



C HD15
(Female)



 D DVI-A
(Male)



E DVI-I
(Female)



F DisplayPort
(Male)



G Mini-DisplayPort
(Male)



H DMS59
(Male)



I USB Mini-B
5-Pin (Female)



VGA Display Solutions (continued)

VGA Gender Changers

- Convert a female VGA connector to male, or vice-versa

Item #	Description	Connector	Connector
P158-000	Compact Gold Gender Changer	HD15 (Male) A	HD15 (Male) A
P160-000	Compact Gold Gender Changer	HD15 (Female) B	HD15 (Female) B

VGA Switches & Splitters

- Switch between two computers connected to one monitor
- Split a VGA signal for distribution to multiple monitors


Item #	Description	Ports	Connector	Connector
B112-002-R	Manual VGA Switch, 2-Port	—	HD15 (Female) B	HD15 (Female) B
B114-002-R	VGA Splitter, 2-Port	—	HD15 (Male) A	(x2) HD15 (Female) B
B114-004-R	VGA Splitter, 4-Port	—	HD15 (Male) A	(x4) HD15 (Female) B
B114-0H4	VGA/SVGA/SXGA/UXGA/QXGA Hi-Res Video Splitter	4	HD15 (Male) A	(x4) HD15 (Female) B

VGA Over Cat5 (UTP) Extenders

- Extend VGA signals to one or more remote displays over cost-effective Cat5 (UTP) cabling
- Support resolutions up to 1920 x 1440
- Also extend audio or serial signals

Item #	Description	Ports	Connector	Connector
B130-101	VGA over Cat5 Extender Kit	1	RJ45 (Female) C (x2) HD15 (Female) B	RJ45 (Female) C HD15 (Female) B
B130-101-WP-1	VGA over Cat5 Extender Wallplate Kit	1	RJ45 (Female) C (x2) HD15 (Female) B	RJ45 (Female) C HD15 (Female) B
B130-101-U	VGA over Cat5 Extender Kit, USB-Powered	1	RJ45 (Female) C USB A (Male) D HD15 (Male) A	RJ45 (Female) C HD15 (Male) A
B130-101A	VGA + Audio over Cat5 Extender Kit	1	RJ45 (Female) C (x2) HD15 (Female) B (x2) 3.5 mm (Female) E	RJ45 (Female) C HD15 (Female) B 3.5mm (Female) E
B130-101A-WP-1	VGA + Audio over Cat5 Extender Wallplate Kit	1	RJ45 (Female) C (x2) HD15 (Female) B (x2) 3.5 mm (Female) E	RJ45 (Female) C 3.5 mm (Female) E
B130-101S	VGA + RS232 Serial over Cat5 Extender Kit	1	RJ45 (Female) C (x2) HD15 (Female) B 3.5 mm (Female) E	RJ45 (Female) C HD15 (Female) B 3.5 mm (Female) E
B130-101S-WP	VGA + RS232 Serial over Cat5 Extender Wallplate Kit	1	RJ45 (Female) C (x2) HD15 (Female) B 3.5 mm (Female) E	RJ45 (Female) C HD15 (Female) B 3.5 mm (Female) E
B130-111	VGA over Cat5 Extender/Repeater Kit, 1 Remote Expansion Port	2	RJ45 (Female) C (x2) HD15 (Female) B	(x2) RJ45 (Female) C HD15 (Female) B
B130-111A	VGA + Audio over Cat5 Extender/Repeater Kit, 1 Remote Expansion Port	2	RJ45 (Female) C (x2) HD15 (Female) B (x2) 3.5 mm (Female) E	(x2) RJ45 (Female) C HD15 (Female) B 3.5 mm (Female) E
B132-002-1	VGA over Cat5 Extender Local Transmitter Unit	2	HD15 (Female) B	(x2) RJ45 (Female) C
B132-002A	VGA + Audio over Cat5 Extender Local Transmitter Unit	2	HD15 (Female) B 3.5 mm (Female) E	(x2) RJ45 (Female) C
B132-004-1	VGA over Cat5 Extender Local Transmitter Unit	4	(x2) HD15 (Female) B	(x4) RJ45 (Female) C
B132-004A	VGA + Audio over Cat5 Extender Local Transmitter Unit	4	(x2) HD15 (Female) B (x2) 3.5 mm (Female) E	(x4) RJ45 (Female) C
B132-004-RB	VGA over Cat5 Extender Rackmount Bracket	—	—	—
B132-100-1	VGA over Cat5 Extender Remote Receiver Unit	—	RJ45 (Female) C	HD15 (Female) B
B132-100-WP-1	VGA over Cat5 Extender Remote Receiver Wallplate	—	RJ45 (Female) C	HD15 (Female) B
B132-100A	VGA + Audio over Cat5 Extender Remote Receiver Unit	—	RJ45 (Female) C	HD15 (Female) B 3.5 mm (Female) E
B132-100A-WP-1	VGA + Audio over Cat5 Extender Remote Receiver Wallplate	—	RJ45 (Female) C	HD15 (Female) B 3.5 mm (Female) E
B132-110	VGA over Cat5 Extender Remote/Repeater Unit	1	RJ45 (Female) C	HD15 (Female) B RJ45 (Female) C
B132-110A	VGA + Audio over Cat5 Extender Remote/Repeater Unit	1	RJ45 (Female) C	HD15 (Female) B 3.5 mm (Female) E RJ45 (Female) C

 A HD15
(Male)



B HD15
(Female)



 
C RJ45
(Female)



D USB A
(Male)



E 3.5 mm.
(Female)



VGA Display Solutions (continued)

Easily pull a VGA cable through conduit or confined spaces with included pull-caps.

Easy Pull Base Cables (Type A)

- Require Easy Pull Type A connectors

Item #	Description	Length	Connector		Connector
EZA-035	Easy Pull Type A Base Cable	35 ft.	Easy Pull A (Female) A		Easy Pull A (Female) A
EZA-035-P	Easy Pull Type A Plenum Rated Base Cable	35 ft.	Easy Pull A (Female) A		Easy Pull A (Female) A
EZA-050	Easy Pull Type A Base Cable	50 ft.	Easy Pull A (Female) A		Easy Pull A (Female) A
EZA-050-P	Easy Pull Type A Plenum Rated Base Cable	50 ft.	Easy Pull A (Female) A		Easy Pull A (Female) A
EZA-100	Easy Pull Type A Base Cable	100 ft.	Easy Pull A (Female) A		Easy Pull A (Female) A
EZA-100-P	Easy Pull Type A Plenum Rated Base Cable	100 ft.	Easy Pull A (Female) A		Easy Pull A (Female) A

Easy Pull VGA Connector Kits (Type A)

- Include two connectors, with or without wall plates
- Require Easy Pull Type A base cable

Item #	Description	Connector		Connector
EZA-VGAM-2	2 Easy Pull VGA Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Male) C		HD15 (Male) C
EZA-VGAF-2	2 Easy Pull VGA Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Female)* D		HD15 (Female)* D
EZA-VGAX-2	2 Easy Pull VGA Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Female)* D		HD15 (Male) C
EZA-VGAAM-2	2 Easy Pull VGA + Audio Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Male) C		HD15 (Male) C
		3.5 mm. (Male) E		3.5 mm. (Male) E
EZA-VGA AF-2	2 Easy Pull VGA + Audio Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Female)* D		HD15 (Female)* D
		3.5 mm. (Female)* F		3.5 mm. (Female)* F
EZA-VGAAX-2	2 Easy Pull VGA + Audio Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Female)* D		HD15 (Male) C
		3.5 mm. (Female)* F		3.5 mm. (Male) E
EZA-VGACSAM-2	2 Easy Pull VGA + Audio + Composite Video Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Male) C		HD15 (Male) C
		3.5 mm. (Male) E		3.5 mm. (Male) E
		(x3) RCA (Male) G		(x3) RCA (Male) G
EZA-VGACSAF-2	2 Easy Pull VGA + Audio + Composite Video Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Female)* D		HD15 (Female)* D
		3.5 mm. (Female)* F		3.5 mm. (Female)* F
		(x3) RCA (Female)* H		(x3) RCA (Female)* H
EZA-VGACSAX-2	2 Easy Pull VGA + Audio + Composite Video Connectors	Easy Pull A (Male) B		Easy Pull A (Male) B
		HD15 (Female)* D		HD15 (Male) C
		3.5 mm. (Female)* F		3.5 mm. (Male) E
		(x3) RCA (Female)* F		(x3) RCA (Male) G

* Each Female connector includes a wallplate

Easy Pull VGA All-in-One Kits

- Cables up to 100 ft. with connectors included

Item #	Description	Length	Connector		Connector
P501-050	Easy Pull VGA Extension Cable	50 ft.	HD15 (Female) D		Easy Pull A (Male) B
			Easy Pull A (Female) A		HD15 (Male) C
P501-100	Easy Pull VGA Extension Cable	100 ft.	HD15 (Female) D		Easy Pull A (Male) B
			Easy Pull A (Female) A		HD15 (Male) C
P503-050	Easy Pull VGA Monitor Cable	50 ft.	HD15 (Male) C		Easy Pull A (Male) B
			Easy Pull A (Female) A		HD15 (Male) C
P503-100	Easy Pull VGA Monitor Cable	100 ft.	HD15 (Male) C		Easy Pull A (Male) B
			Easy Pull A (Female) A		HD15 (Male) C
P504-050-EZ	Easy Pull VGA Monitor Cable with Audio	50 ft.	HD15 (Male) C		Easy Pull A (Male) B
			3.5 mm. (Male) E		HD15 (Male) C
			Easy Pull A (Female) A		3.5 mm. (Male) E
P504-100-EZ	Easy Pull VGA Monitor Cable with Audio	100 ft.	HD15 (Male) C		Easy Pull A (Male) B
			3.5 mm. (Male) E		HD15 (Male) C
			Easy Pull A (Female) A		3.5 mm. (Male) E

A Easy Pull A (Female)



B Easy Pull A (Male)



 
C HD15 (Male)




D HD15 (Female)



E 3.5 mm. (Male)



F 3.5 mm. (Female)

 

G RCA (Male)



H RCA (Female)



DVI Display Solutions

Available in both Dual- and Single-Link DVI cables for use with both digital and analog sources, these cables provide high video resolutions and bandwidth rates, and are shielded from EMI/RFI interference for higher-quality video.

DVI Display Cables

- Connect a computer and display directly

Item #	Description	Length	Connector	Connector
P560-003	DVI Dual-Link Display Cable	3 ft.	DVI-D Dual-Link (Male) A	DVI-D Dual-Link (Male) A
P560-006	DVI Dual-Link Display Cable	6 ft.	DVI-D Dual-Link (Male) A	DVI-D Dual-Link (Male) A
P560-010	DVI Dual-Link Display Cable	10 ft.	DVI-D Dual-Link (Male) A	DVI-D Dual-Link (Male) A
P560-015	DVI Dual-Link Display Cable	15 ft.	DVI-D Dual-Link (Male) A	DVI-D Dual-Link (Male) A
P560-020	DVI Dual-Link Display Cable	20 ft.	DVI-D Dual-Link (Male) A	DVI-D Dual-Link (Male) A
P560-025	DVI Dual-Link Display Cable	25 ft.	DVI-D Dual-Link (Male) A	DVI-D Dual-Link (Male) A
P560-050	DVI Dual-Link Display Cable	50 ft.	DVI-D Dual-Link (Male) A	DVI-D Dual-Link (Male) A
P560-100	DVI Dual-Link Display Cable	100 ft.	DVI-D Dual-Link (Male) A	DVI-D Dual-Link (Male) A

DVI Dual-Link Display Cables with Audio

Item #	Description	Length	Connector	Connector
P560-006-A	DVI Dual-Link Display Cable with Audio	6 ft.	DVI-D Dual-Link (Male) A 3.5 mm. (Male) B	DVI-D Dual-Link (Male) A 3.5 mm. (Male) B
P560-010-A	DVI Dual-Link Display Cable with Audio	10 ft.	DVI-D Dual-Link (Male) A 3.5 mm. (Male) B	DVI-D Dual-Link (Male) A 3.5 mm. (Male) B

DVI Dual-Link Extension Cables

Item #	Description	Length	Connector	Connector
P562-001-45L	DVI Dual-Link Extension Cable with 45 Degree Left Male Connector	1 ft.	DVI-D (Female) C	DVI-D (Male) D
P562-006	DVI Dual-Link Extension Cable	6 ft.	DVI-D (Female) C	DVI-D (Male) D

DVI Single-Link Display Cables

Item #	Description	Length	Connector	Connector
P561-006	DVI Single-Link Display Cable	6 ft.	DVI-D Single-Link (Male) E	DVI-D Single-Link (Male) E
P561-010	DVI Single-Link Display Cable	10 ft.	DVI-D Single-Link (Male) E	DVI-D Single-Link (Male) E
P561-050	DVI Single-Link Display Cable	50 ft.	DVI-D Single-Link (Male) E	DVI-D Single-Link (Male) E
P561-075	DVI Single-Link Display Cable	75 ft.	DVI-D Single-Link (Male) E	DVI-D Single-Link (Male) E
P561-100	DVI Single-Link Display Cable	100 ft.	DVI-D Single-Link (Male) E	DVI-D Single-Link (Male) E

DVI Adapters

- Connect a DVI display or source to a dissimilar display or source

Item #	Description	Length	Connector	Connector
P118-000	DVI Cable Adapter	—	DVI-I (Female) F	DVI-D Dual-Link (Male) A
P120-000	DVI Analog Source to VGA Display Adapter	—	DVI-A (Male) G	HD15 (Female) H
P120-001-2	DVI Analog Source to VGA Display Splitter	1 ft.	DVI-A (Male) G	(x2) HD15 (Female) H
P122-000	DVI Source to DFP Cable Adapter	—	DVI-D Single-Link (Male) E	DFP (Female) I
P126-000	VGA Source to DVI Analog Display Adapter	—	HD15 (Male) J	DVI-I (Female) F
P130-000	DVI Source to HDMI Cable Adapter	—	DVI-D Single-Link (Male) E	HD15 (Female) H
P132-000	HDMI Source to DVI Cable Adapter	—	HDMI (Male) K	DVI-I (Female) F
P134-000	DisplayPort Source to DVI Cable Adapter	6 in.	DisplayPort (Male) L	DVI-I (Female) F
P137-06N-DVI	Mini-DisplayPort Source to DVI Cable Adapter	6 in.	Mini-DisplayPort (Male) M	DVI-I (Female) F
P138-000-DVI	Mini-DVI Source to DVI Cable Adapter	8 in.	Mini-DVI (Male) N	DVI-D (Female) C
P138-000-HDMI	Mini-DVI Source to HDMI Cable Adapter	8 in.	Mini-DVI (Male) N	HD15 (Female) H
P162-000	DVI Male-to-Female Gender Changer	—	DVI-I (Female) F	DVI-I (Female) F
P556-003	DVI Analog Source to VGA Display Cable	3 ft.	DVI-A (Male) G	HD15 (Male) J
P556-006	DVI Analog Source to VGA Display Cable	6 ft.	DVI-A (Male) G	HD15 (Male) J
P556-010	DVI Analog Source to VGA Display Cable	10 ft.	DVI-A (Male) G	HD15 (Male) J
P566-006	DVI to HDMI Display Cable	6 ft.	DVI-D Single-Link (Male) E	HDMI (Male) K
P566-010	DVI to HDMI Display Cable	10 ft.	DVI-D Single-Link (Male) E	HDMI (Male) K
P566-016	DVI to HDMI Display Cable	16 ft.	DVI-D Single-Link (Male) E	HDMI (Male) K
P576-001	DMS59 Source to DVI Display Splitter	1 ft.	DMS59 (Male) O	(x2) DVI-I (Female) F
P581-006	DisplayPort Source to DVI Single-Link Display Cable	6 ft.	DisplayPort (Male) L	DVI-D Single-Link (Male) E

A DVI-D Dual-Link (Male)



B 3.5 mm. (Male)



 
C DVI-D (Female)



D DVI-D (Male)




E DVI-D Single-Link (Male)



F DVI-I (Female)



 G DVI-A (Male)



H HD15 (Female)



 
I DFP (Female)




J HD15 (Male)



K HDMI (Male)



L DisplayPort (Male)

 

M Mini-DisplayPort (Male)



N Mini-DVI (Male)



O DMS59 (Male)



DVI Display Solutions (continued)

DVI Adapters (continued)

Item #	Description	Length	Connector	Connector
P581-010	DisplayPort Source to DVI Single-Link Display Cable	10 ft.	DisplayPort (Male) A	DVI-D Single-Link (Male) B
U244-001-R	USB 2.0 to DVI Adapter	—	USB Mini-B 5-Pin (Female) C	DVI-I (Female) D

DVI Splitters

- Split a DVI signal for distribution to multiple displays

Item #	Description	Ports	Connector	Connector
B116-002A	DVI Single-Link Splitter with Audio	2	DVI-I (Female) D 3.5 mm (Female) E	(x2) DVI-I (Female) D (x2) 3.5 mm (Female) E
B116-004A	DVI Single-Link Splitter with Audio	4	DVI-I (Female) D 3.5 mm (Female) E	(x4) DVI-I (Female) D (x4) 3.5 mm (Female) E
P564-001	DVI Splitter Cable - 1 ft.	2	DVI-D Dual-Link (Male) F	(x2) DVI-D Dual-Link (Female) G

DVI Signal Boosters

- Boost a DVI signal for cable runs up to 150 ft.

Item #	Description	Range	Connector	Connector
B120-000	DVI Dual-Link Signal Booster - Extend a 2560 x 1600 Signal up to 150 ft.	150 ft.	DVI-I (Female) D	DVI-I (Female) D
B120-000-SL	DVI Single-Link Signal Booster - Extend a 1920 x 1080 Signal up to 150 ft.	150 ft.	DVI-I (Female) D	DVI-I (Female) D

DVI Over Cat5 (UTP) Extenders


- Extend DVI signals to one or more remote displays over cost-effective Cat5 (UTP) cabling
- Active models extend a signal up to 200 ft. from the source
- Passive models extend a signal up to 100 ft. from the source

Item #	Description	Ports	Connector	Connector
B140-101	DVI over Cat5 Passive Extender Kit	1	DVI-D Single-Link (Male) B RJ45 (Female) H	RJ45 (Female) H DVI-D Single-Link (Male) B
B140-101-WP	DVI over Cat5 Passive Extender Wallplate Kit	1	DVI-I (Female) D 110-Type (Female) I	110-Type (Female) I DVI-I (Female) D
B140-101X	DVI over Cat5 Active Extender Kit	1	DVI-D Single-Link (Male) B RJ45 (Female) H	RJ45 (Female) H DVI-I (Female) D
B140-1A1-WP	DVI over Cat5 Active Extender Wallplate Kit	1	DVI-I (Female) D RJ45 (Female) H	RJ45 (Female) H DVI-I (Female) D
B140-002	DVI over Cat5 Extender Local Transmitter Unit	2	DVI-I (Female) D	(x2) RJ45 (Female) H
B140-004	DVI over Cat5 Extender Local Transmitter Unit	4	(x2) DVI-I (Female) D	(x4) RJ45 (Female) H
B140-1A0	DVI over Cat5 Active Extender Remote Receiver Unit	—	RJ45 (Female) H	DVI-I (Female) D
B140-1A0-WP	DVI over Cat5 Active Extender Remote Receiver Wallplate	—	110-Type (Female) I	DVI-I (Female) D
B140-1P0	DVI over Cat5 Passive Extender Remote Receiver Unit	—	RJ45 (Female) H	DVI-D Single-Link (Male) B
B140-1P0-WP	DVI over Cat5 Passive Extender Remote Receiver Wallplate	—	110-Type (Female) I	DVI-I (Female) D
B140-110	DVI over Cat5 Extender Remote/Repeater Unit	1	RJ45 (Female) H	DVI-I (Female) D RJ45 (Female) H

A DisplayPort
(Male)



 B DVI-D Single-
Link (Male)




C USB Mini-B
5-Pin (Female)



D DVI-I
(Female)



 E 3.5 mm
(Female)



F DVI-D Dual-Link
(Male)



G DVI-D Dual-Link
(Female)



H RJ45
(Female)



I 110-Type
(Female)



DVI Display Solutions (continued)

Easily pull a DVI cable through conduit or confined spaces with included pull-caps.

Easy Pull Base Cables (Type B)

- Require Easy Pull Type B connectors

Item #	Description	Length	Connector	Connector
EZB-050	Easy Pull Type B Base Cable	50 ft.	Easy Pull B (Female) A	Easy Pull B (Female) A
EZB-100	Easy Pull Type B Base Cable	100 ft.	Easy Pull B (Female) A	Easy Pull B (Female) A

Easy Pull DVI Connector Kits (Type B)

- Include two connectors, with or without wall plates
- Require Easy Pull Type B base cable

Item #	Description	Connector	Connector
EZB-DVIM-2	2 Easy Pull DVI Connectors	Easy Pull B (Male) B DVI-D Single-Link (Male) C	Easy Pull B (Female) A DVI-D Single-Link (Male) C
EZB-DVIF-2	2 Easy Pull DVI Connectors	Easy Pull B (Male) B DVI-D Dual-Link (Female)* D	Easy Pull B (Male) B DVI-D Dual-Link (Female)* D
EZB-DVIX-2	2 Easy Pull DVI Connectors	Easy Pull B (Male) B DVI-D Dual-Link (Female)* D	Easy Pull B (Male) B DVI-D Single-Link (Male) C

* Each Female connector includes a wallplate

Easy Pull DVI All-in-One Kits

- Cables up to 100 ft. with connectors included

Item #	Description	Length	Connector	Connector
P561-050-EZ	Easy Pull DVI Single-Link Display Cable	50 ft.	DVI-D Single-Link (Male) C Easy Pull B (Female) A	Easy Pull B (Female) A DVI-D Single-Link (Male) C
P561-100-EZ	Easy Pull DVI Single-Link Display Cable	100 ft.	DVI-D Single-Link (Male) C Easy Pull B (Female) A	Easy Pull B (Female) A DVI-D Single-Link (Male) C

* Each Female connector includes a wallplate

HDMI Display Solutions

High-definition A/V equipment demands the highest quality signal, so use a reliable HDMI cable or extender to connect an HDMI source video to an HDTV or display.

High-Speed HDMI Cables

Item #	Description	Length	Connector	Connector
P568-003	High-Speed HDMI Cable	3 ft.	HDMI (Male) E	HDMI (Male) E
P568-006	High-Speed HDMI Cable	6 ft.	HDMI (Male) E	HDMI (Male) E
P568-010	High-Speed HDMI Cable	10 ft.	HDMI (Male) E	HDMI (Male) E
P568-016	High-Speed HDMI Cable	16 ft.	HDMI (Male) E	HDMI (Male) E
P568-025	High-Speed HDMI Cable	25 ft.	HDMI (Male) E	HDMI (Male) E
P568-050	High-Speed HDMI Cable	50 ft.	HDMI (Male) E	HDMI (Male) E
P568-050-P	Plenum Rated High-Speed HDMI Cable	50 ft.	HDMI (Male) E	HDMI (Male) E
P568-100	High-Speed HDMI Cable	100 ft.	HDMI (Male) E	HDMI (Male) E
P568-100-HD	High-Definition, High-Speed HDMI Cable	100 ft.	HDMI (Male) E	HDMI (Male) E
P572-006	High-Speed Mini-HDMI Cable	6 ft.	Mini-HDMI (Male) F	Mini-HDMI (Male) F

Flat High-Speed HDMI Cables

Item #	Description	Length	Connector	Connector
P568-003-FL	Flat High-Speed HDMI Cable	3 ft.	HDMI (Male) E	HDMI (Male) E
P568-006-FL	Flat High-Speed HDMI Cable	6 ft.	HDMI (Male) E	HDMI (Male) E
P568-010-FL	Flat High-Speed HDMI Cable	10 ft.	HDMI (Male) E	HDMI (Male) E
P568-016-FL	Flat High-Speed HDMI Cable	16 ft.	HDMI (Male) E	HDMI (Male) E

 
A Easy Pull B
(Female)



B Easy Pull B
(Male)



C DVI-D Single-
Link (Male)



D DVI-D Dual-Link
(Female)



E HDMI
(Male)



F Mini-HDMI
(Male)



HDMI Display Solutions (continued)

High-Speed HDMI Cables (continued)

High-Speed HDMI Cables with 180 Degree Swivel Connectors

Item #	Description	Length	Connector	Connector
P568-003-SW	High-Speed HDMI Cable with 180 Degree Swivel Connectors	3 ft.	HDMI (Male) A	HDMI (Male) A
P568-006-SW	High-Speed HDMI Cable with 180 Degree Swivel Connectors	6 ft.	HDMI (Male) A	HDMI (Male) A
P568-010-SW	High-Speed HDMI Cable with 180 Degree Swivel Connectors	10 ft.	HDMI (Male) A	HDMI (Male) A

High-Speed HDMI Cables with Right-Angle Connectors

Item #	Description	Length	Connector	Connector
P568-006-RA	High-Speed HDMI Cable with a Single Right-Angle Connector	6 ft.	HDMI (Male) A	HDMI (Male) A
P568-006-RA2	High-Speed HDMI Cable with Dual Right-Angle Connectors	6 ft.	HDMI (Male) A	HDMI (Male) A

High-Speed HDMI Cables with Ethernet

Item #	Description	Length	Connector	Connector
P569-003	High-Speed HDMI Cable with Ethernet	3 ft.	HDMI (Male) A	HDMI (Male) A
P569-006	High-Speed HDMI Cable with Ethernet	6 ft.	HDMI (Male) A	HDMI (Male) A
P569-010	High-Speed HDMI Cable with Ethernet	10 ft.	HDMI (Male) A	HDMI (Male) A
P569-016	High-Speed HDMI Cable with Ethernet	16 ft.	HDMI (Male) A	HDMI (Male) A
P569-025	High-Speed HDMI Cable with Ethernet	25 ft.	HDMI (Male) A	HDMI (Male) A

HDMI Adapters

Item #	Description	Length	Connector	Connector
P130-000	DVI Source to HDMI Cable Adapter	—	DVI-D Single-Link (Male) B	HDMI (Female) C
P132-000	HDMI Source to DVI Cable Adapter	—	HDMI (Male) A	DVI-I (Female) D
P136-000	DisplayPort Source to HDMI Cable Adapter	6 in.	DisplayPort (Male) E	HDMI (Female) C
P137-06N-HDMI	Mini-DisplayPort Source to HDMI Cable Adapter	6 in.	Mini-DisplayPort (Male) F	HDMI (Female) C
P138-000-HDMI	Mini-DVI Source to HDMI Cable Adapter	8 in.	Mini-DVI (Male) G	HDMI (Female) C
P142-000-UD	Adjustable-Angle HDMI Adapter	—	HDMI (Female) C	HDMI (Male) A
P142-000-UP	Right-Angle HDMI Adapter	—	HDMI (Female) C	HDMI (Male) A
P566-006	DVI to HDMI Display Cable	6 ft.	DVI-D Single-Link (Male) B	HDMI (Male) A
P566-010	DVI to HDMI Display Cable	10 ft.	DVI-D Single-Link (Male) B	HDMI (Male) A
P566-016	DVI to HDMI Display Cable	16 ft.	DVI-D Single-Link (Male) B	HDMI (Male) A
P570-006	Mini-HDMI to HDMI Adapter Cable	6 ft.	Mini-HDMI (Male) H	HDMI (Male) A
P570-003-MICRO	Micro-HDMI to HDMI Adapter Cable	3 ft.	Micro-HDMI (Male) I	HDMI (Male) A
P570-006-MICRO	Micro-HDMI to HDMI Adapter Cable	6 ft.	Micro-HDMI (Male) I	HDMI (Male) A
U244-001-HDMI-R	USB 2.0 to HDMI Adapter	—	USB Mini-B 5-Pin (Female) J	HDMI (Female) C

HDMI Gender Changers

- Connect a male HDMI connector to female

Item #	Description	Connector	Connector
P164-000	HDMI Male-to-Female Gender Changer	HDMI (Female) C	HDMI (Female) C
P164-000-UP	Right-Angle HDMI Male-to-Female Gender Changer	HDMI (Female) C	HDMI (Female) C
P166-001-P	HDMI Male-to-Female Pass-Through Wall Plate	HDMI (Female) C	HDMI (Female) C

HDMI Splitters








- Split an HDMI signal for distribution to multiple displays

Item #	Description	Ports	Connector	Connector
B118-302-R	HDMI Splitter	2	HDMI (Female) C	(x2) HDMI (Female) C
B118-304-R	HDMI Splitter	4	HDMI (Female) C	(x4) HDMI (Female) C

HDMI Switches

- Switch between multiple HDMI sources connected to a single HDMI port

Item #	Description	Ports	Connector	Connector
B119-302-R	HDMI Switch	2	(x2) HDMI (Female) C	HDMI (Female) C
B119-303-R	HDMI Switch, with Remote	3	(x4) HDMI (Female) C	HDMI (Female) C

       

HDMI Display Solutions (continued)

HDMI Over Cat5 (UTP) Extenders

- Extend HDMI signals to one or more remote displays over cost-effective Cat5 (UTP) cabling
- Active models extend a signal up to 200 ft. from the source
- Passive models extend a signal up to 100 ft. from the source

Item #	Description	Ports	Connector	Connector
B125-150	HDMI over Dual Cat5 Extender Kit, 1080p/24Hz	1	HDMI (Female) A (x2) RJ45 (Female) B	(x2) RJ45 (Female) B HDMI (Female) A
B125-101-60	HDMI over Dual Cat5 Extender Kit, 1080p/60Hz	1	HDMI (Female) A (x2) RJ45 (Female) B	(x2) RJ45 (Female) B HDMI (Female) A
P167-000	HDMI over Dual Cat5 Extender Wallplate Kit, 1080p/24Hz	1	HDMI (Female) A (x2) 110-Type (Female) C	(x2) 110-Type (Female) C HDMI (Female) A
B125-101-60-WP	HDMI over Dual Cat5 Extender Wallplate Kit, 1080p/60Hz	1	HDMI (Female) A (x2) RJ45 (Female) B	(x2) RJ45 (Female) B HDMI (Female) A
B126-1A1	HDMI over Single Cat5 Active Extender Kit, 1080p/60Hz	1	(x2) HDMI (Female) A RJ45 (Female) B	RJ45 (Female) B HDMI (Female) A
B126-1A1-WP	HDMI over Single Cat5 Active Extender Wallplate Kit, 1080p/60Hz	1	HDMI (Female) A RJ45 (Female) B	RJ45 (Female) B HDMI (Female) A
B126-1A1SR	HDMI + RS232 Serial and IR Control over Single Cat5 Active Extender Kit, 1080p/60Hz	1	HDMI (Female) A (x3) 3.5 mm. (Female) D RJ45 (Female) B	RJ45 (Female) B (x3) 3.5 mm. (Female) D HDMI (Female) A
B126-002	HDMI over Single Cat5 Extender Local Transmitter Unit, 1080p/60Hz	2	HDMI (Female) A	(x2) RJ45 (Female) B
B126-004	HDMI over Single Cat5 Extender Local Transmitter Unit, 1080p/60Hz	4	(x2) HDMI (Female) A	(x4) RJ45 (Female) B
B126-1A0	HDMI over Single Cat5 Active Extender Remote Receiver Unit, 1080p/60Hz	—	RJ45 (Female) B	HDMI (Female) A
B126-1A0-WP-1	HDMI over Single Cat5 Active Extender Remote Receiver Wallplate, 1080p/60Hz	—	RJ45 (Female) B	HDMI (Female) A
B126-1P0	HDMI over Single Cat5 Passive Extender Remote Receiver Unit, 1080p/60Hz	—	RJ45 (Female) B	HDMI (Male) E
B126-1P0-WP	HDMI over Single Cat5 Passive Extender Remote Receiver Wallplate, 1080p/60Hz	—	110-Type (Female) C	HDMI (Female) A
B126-110	HDMI over Single Cat5 Extender Remote/Repeater Unit, 1080p/60Hz	1	RJ45 (Female) B	RJ45 (Female) B HDMI (Female) A

Audio/Video Solutions

Premium-quality A/V solutions offer superior video image and audio quality, resulting in brighter, more saturated colors and deeper, richer audio.

Composite Video Cables (Yellow RCA Connector)

Item #	Description	Length	Connector	Connector
A004-006	Composite Video Cable	6 ft.	RCA (Male) F	RCA (Male) F
A004-012	Composite Video Cable	12 ft.	RCA (Male) F	RCA (Male) F

Component Video Cables (Red/Green/Blue RCA Connectors)

Item #	Description	Length	Connector	Connector
A008-006	Component Video Cable	6 ft.	(x3) RCA (Male) F	(x3) RCA (Male) F
A008-012	Component Video Cable	12 ft.	(x3) RCA (Male) F	(x3) RCA (Male) F

S-Video Cables

Item #	Description	Length	Connector	Connector
A012-006	S-Video Cable	6 ft.	MD4 (Male) G	MD4 (Male) G
A012-012	S-Video Cable	12 ft.	MD4 (Male) G	MD4 (Male) G

A HDMI
(Female)



 
B RJ45
(Female)



C 110-Type
(Female)



D 3.5 mm.
(Female)



E HDMI
(Male)



F RCA
(Male)



G MD4
(Male)



RG59 Coaxial Cables ("F" Type Connector)

Item #	Description	Length	Connector	Connector
A200-006	RG59 Coaxial Cable	6 ft.	F-Type Threaded Coax (Male) A	F-Type Threaded Coax (Male) A
A200-012	RG59 Coaxial Cable	12 ft.	F-Type Threaded Coax (Male) A	F-Type Threaded Coax (Male) A
A200-025	RG59 Coaxial Cable	25 ft.	F-Type Threaded Coax (Male) A	F-Type Threaded Coax (Male) A

Stereo Audio Cables (Red/White RCA Connectors)

Item #	Description	Length	Connector	Connector
A050-006	Stereo Audio Cable	6 ft.	(x2) RCA (Male) B	(x2) RCA (Male) B
A050-012	Stereo Audio Cable	12 ft.	(x2) RCA (Male) B	(x2) RCA (Male) B

Mini-Stereo Audio Cables

Item #	Description	Length	Connector	Connector
P310-004-R	Retractable Mini-Stereo Audio Cable	4 ft.	3.5 mm. (Male) C	3.5 mm. (Male) C
P312-006	Mini-Stereo Audio Cable	6 ft.	3.5 mm. (Male) C	3.5 mm. (Male) C
P312-010	Mini-Stereo Audio Cable	10 ft.	3.5 mm. (Male) C	3.5 mm. (Male) C
P312-025	Mini-Stereo Audio Cable	25 ft.	3.5 mm. (Male) C	3.5 mm. (Male) C
P312-050	Mini-Stereo Audio Cable	50 ft.	3.5 mm. (Male) C	3.5 mm. (Male) C

Digital Coax Audio Cables

Item #	Description	Length	Connector	Connector
A060-006	Digital Coax Audio Cable	6 ft.	RCA (Male) B	RCA (Male) B
A060-012	Digital Coax Audio Cable	12 ft.	RCA (Male) B	RCA (Male) B

Toslink Digital Optical Audio Cables

Item #	Description	Length	Connector	Connector
A102-01M	Toslink Digital Optical Audio Cable	1 m. (3 ft.)	Toslink D	Toslink D
A102-02M	Toslink Digital Optical Audio Cable	2 m. (6 ft.)	Toslink D	Toslink D
A102-03M	Toslink Digital Optical Audio Cable	3 m. (10 ft.)	Toslink D	Toslink D
A102-04M	Toslink Digital Optical Audio Cable	4 m. (13 ft.)	Toslink D	Toslink D

Audio Adapters and Cable Ties

Item #	Description	Length	Connector	Connector
P313-001	Mini-Stereo Audio Splitter Cable	1 ft.	3.5 mm. (Male) C	(x2) 3.5 mm. (Female) E
P314-006	Mini-Stereo to Stereo Audio Adapter/Splitter Cable	6 ft.	3.5 mm. (Male) C	(x2) RCA (Male) B
P314-012	Mini-Stereo to Stereo Audio Adapter/Splitter Cable	12 ft.	3.5 mm. (Male) C	(x2) RCA (Male) B
P315-006	Mini-Stereo to Stereo Audio Adapter/Splitter Cable	6 ft.	3.5 mm. (Male) C	3.5 mm. (Female) E
P350-10N-10	Hook-and-Loop Velcro Cable Ties - 10/pk	10 in.	—	—

Component Video and S-Video Splitters & Extenders


- Extend Component or S-Video signals with Audio over cost-effective Cat5 (UTP) cabling

Item #	Description	Ports	Connector	Connector
B136-101	Component Video + Stereo Audio over Cat5 Extender Kit	1	(x5) RCA (Male) B RJ45 (Female) F	(x5) RCA (Male) B RJ45 (Female) F
B136-101-WP-1	Component Video + Stereo Audio over Cat5 Extender Wallplate Kit	1	(x5) RCA (Female) G RJ45 (Female) F	(x5) RCA (Female) G RJ45 (Female) F
B137-101	S-Video + Stereo Audio over Cat5 Extender Kit	1	MD4 (Male) H (x2) RCA (Male) B RJ45 (Female) F	MD4 (Male) H (x2) RCA (Male) B RJ45 (Female) F
B136-004	Component Video + Stereo Audio over Cat5 Extender Local Transmitter Unit	4	(x10) RCA (Female) G	(x4) RJ45 (Female) F
B136-100	Component Video + Stereo Audio over Cat5 Extender Remote Receiver Unit	1	RJ45 (Female) F	(x5) RCA (Male) B
B136-100-WP	Component Video + Stereo Audio over Cat5 Extender Remote Receiver Wallplate	1	110-Type (Female) I	(x5) RCA (Female) G


A F-Type Threaded Coax (Male)



 
B RCA (Male)



C 3.5 mm. (Male)

 

D Toslink

 

E 3.5 mm. (Female)



F RJ45 (Female)



G RCA (Female)



H MD4 (Male)



I 110-Type (Female)



DisplayPort Cables & Adapters

Display video on an HDTV directly from your laptop or desktop computer with a DisplayPort video cable.

DisplayPort Cables

- Connect a DisplayPort source and display directly

Item #	Description	Length	Connector	Connector
P580-003	DisplayPort Monitor Cable	3 ft.	DisplayPort (Male) A	DisplayPort (Male) A
P580-006	DisplayPort Monitor Cable	6 ft.	DisplayPort (Male) A	DisplayPort (Male) A
P580-010	DisplayPort Monitor Cable	10 ft.	DisplayPort (Male) A	DisplayPort (Male) A
P580-015	DisplayPort Monitor Cable	15 ft.	DisplayPort (Male) A	DisplayPort (Male) A

DisplayPort Adapters & Gender Changer

Item #	Description	Length	Connector	Connector
P134-000	DisplayPort Source to DVI Cable Adapter	6 in.	DisplayPort (Male) A	DVI-I (Female) B
P134-06N-VGA	DisplayPort Source to VGA Cable Adapter	6 in.	DisplayPort (Male) A	HD15 (Female) C
P136-000	DisplayPort Source to HDMI Cable Adapter	6 in.	DisplayPort (Male) A	HDMI (Female) D
P137-06N-DVI	Mini-DisplayPort Source to DVI Cable Adapter	6 in.	Mini-DisplayPort (Male) E	DVI-I (Female) B
P137-06N-HDMI	Mini-DisplayPort Source to HDMI Cable Adapter	6 in.	Mini-DisplayPort (Male) E	HDMI (Female) D
P137-06N-VGA	Mini-DisplayPort Source to VGA Cable Adapter	6 in.	Mini-DisplayPort (Male) E	HD15 (Female) C
P139-06N-DP	Mini-DisplayPort Source to DisplayPort Cable Adapter	6 in.	Mini-DisplayPort (Male) E	DisplayPort (Female) F
P168-000	DisplayPort Male-to-Female Gender Changer	—	DisplayPort (Female) F	DisplayPort (Female) F
P581-006	DisplayPort to DVI Single-Link Adapter Cable	6 ft.	DisplayPort (Male) A	DVI-D Single-Link (Male) G
P581-010	DisplayPort to DVI Single-Link Adapter Cable	10 ft.	DisplayPort (Male) A	DVI-D Single-Link (Male) G

Category 6/5e Network Solutions

Category 6 and Category 5e cabling provides faster network transmission speeds (up to 1 Gigabit per second) and supports a wide variety of applications: 1000BASE-T (1 Gbps Ethernet); 100BASE-T (100 Mbps Ethernet); 10BASE-T (10 Mbps Ethernet); 100 Mbps TPDDI; 155 Mbps ATM; ISDN; and Voice.

Cat6 Shielded (STP) Patch Cables

- Protect network data from EMI/RFI interference
- Manufactured from PVC, 4-pair, stranded shielded twisted pair, and rated for 550MHz/1Gbps communication

Item #	Description	Length	Connector	Connector
N125-007-GY	Cat6 Gigabit Gray Shielded Patch Cable	7 ft.	RJ45 (Male) H	RJ45 (Male) H
N125-010-GY	Cat6 Gigabit Gray Shielded Patch Cable	10 ft.	RJ45 (Male) H	RJ45 (Male) H
N125-025-GY	Cat6 Gigabit Gray Shielded Patch Cable	25 ft.	RJ45 (Male) H	RJ45 (Male) H
N125-050-GY	Cat6 Gigabit Gray Shielded Patch Cable	50 ft.	RJ45 (Male) H	RJ45 (Male) H

Cat6 Snagless (UTP) Patch Cables

- High-speed (up to 550 Mhz) Cat6 snagless patch cables to distribute data, voice and video
- Designed for use in Category 6, Category 5e and Category 5 applications

Item #	Description	Length	Connector	Connector
N201-001-BK	Cat6 Gigabit Black Snagless Patch Cable	1 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-001-BL	Cat6 Gigabit Blue Snagless Patch Cable	1 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-001-GY	Cat6 Gigabit Gray Snagless Patch Cable	1 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-001-RD	Cat6 Gigabit Red Snagless Patch Cable	1 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-001-YW	Cat6 Gigabit Yellow Snagless Patch Cable	1 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-001-WH	Cat6 Gigabit White Snagless Patch Cable	1 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-002-BK	Cat6 Gigabit Black Snagless Patch Cable	2 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-002-BL	Cat6 Gigabit Blue Snagless Patch Cable	2 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-002-GY	Cat6 Gigabit Gray Snagless Patch Cable	2 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-002-YW	Cat6 Gigabit Yellow Snagless Patch Cable	2 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-002-RD	Cat6 Gigabit Red Snagless Patch Cable	2 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-002-WH	Cat6 Gigabit White Snagless Patch Cable	2 ft.	RJ45 (Male) H	RJ45 (Male) H
N201-003-BK	Cat6 Gigabit Black Snagless Patch Cable	3 ft.	RJ45 (Male) H	RJ45 (Male) H

A DisplayPort
(Male)



B DVI-I
(Female)



C HD15
(Female)



D HDMI
(Female)



 
E Mini-DisplayPort
(Male)



F DisplayPort
(Female)



G DVI-D Single-Link
(Male)




H RJ45
(Male)



Category 6/5e Network Solutions (continued)

Cat6 Snagless (UTP) Patch Cables (continued)

Item #	Description	Length	Connector	Connector
N201-003-BL	Cat6 Gigabit Blue Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-003-GN	Cat6 Gigabit Green Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-003-GY	Cat6 Gigabit Gray Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-003-OR	Cat6 Gigabit Orange Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-003-YW	Cat6 Gigabit Yellow Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-003-RD	Cat6 Gigabit Red Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-003-WH	Cat6 Gigabit White Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-004-BL	Cat6 Gigabit Blue Snagless Patch Cable	4 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-004-YW	Cat6 Gigabit Yellow Snagless Patch Cable	4 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-005-BK	Cat6 Gigabit Black Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-005-BL	Cat6 Gigabit Blue Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-005-GN	Cat6 Gigabit Green Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-005-GY	Cat6 Gigabit Gray Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-005-OR	Cat6 Gigabit Orange Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-005-YW	Cat6 Gigabit Yellow Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-005-RD	Cat6 Gigabit Red Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-005-WH	Cat6 Gigabit White Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-006-GY	Cat6 Gigabit Gray Snagless Patch Cable	6 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-007-BK	Cat6 Gigabit Black Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-007-BL	Cat6 Gigabit Blue Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-007-GN	Cat6 Gigabit Green Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-007-GY	Cat6 Gigabit Gray Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-007-OR	Cat6 Gigabit Orange Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-007-YW	Cat6 Gigabit Yellow Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-007-RD	Cat6 Gigabit Red Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-007-WH	Cat6 Gigabit White Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-010-BK	Cat6 Gigabit Black Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-010-BL	Cat6 Gigabit Blue Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-010-GN	Cat6 Gigabit Green Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-010-GY	Cat6 Gigabit Gray Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-010-OR	Cat6 Gigabit Orange Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-010-YW	Cat6 Gigabit Yellow Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-010-RD	Cat6 Gigabit Red Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-010-WH	Cat6 Gigabit White Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-014-BK	Cat6 Gigabit Black Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-014-BL	Cat6 Gigabit Blue Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-014-GN	Cat6 Gigabit Green Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-014-GY	Cat6 Gigabit Gray Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-014-OR	Cat6 Gigabit Orange Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-014-YW	Cat6 Gigabit Yellow Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-014-RD	Cat6 Gigabit Red Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-014-WH	Cat6 Gigabit White Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-015-GY	Cat6 Gigabit Gray Snagless Patch Cable	15 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-020-BK	Cat6 Gigabit Black Snagless Patch Cable	20 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-020-BL	Cat6 Gigabit Blue Snagless Patch Cable	20 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-020-GN	Cat6 Gigabit Green Snagless Patch Cable	20 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-020-GY	Cat6 Gigabit Gray Snagless Patch Cable	20 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-020-OR	Cat6 Gigabit Orange Snagless Patch Cable	20 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-020-YW	Cat6 Gigabit Yellow Snagless Patch Cable	20 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-020-RD	Cat6 Gigabit Red Snagless Patch Cable	20 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-020-WH	Cat6 Gigabit White Snagless Patch Cable	20 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-025-BK	Cat6 Gigabit Black Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-025-BL	Cat6 Gigabit Blue Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-025-GN	Cat6 Gigabit Green Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-025-GY	Cat6 Gigabit Gray Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-025-OR	Cat6 Gigabit Orange Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 

 

Category 6/5e Network Solutions (continued)

Cat6 Snagless (UTP) Patch Cables (continued)

Item #	Description	Length	Connector	Connector
N201-025-YW	Cat6 Gigabit Yellow Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-025-RD	Cat6 Gigabit Red Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-025-WH	Cat6 Gigabit White Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-025-BL-FL	Cat5 Gigabit Blue Flat Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-050-GY	Cat6 Gigabit Gray Snagless Patch Cable	50 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-050-GY-P	Cat6 Gigabit Gray Snagless Patch Cable (Plenum)	50 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-050-RD	Cat6 Gigabit Red Snagless Patch Cable	50 ft.	RJ45 (Male) 	RJ45 (Male) 
N201-100-GY-P	Cat6 Gigabit Gray Snagless Patch Cable (Plenum)	100 ft.	RJ45 (Male) 	RJ45 (Male) 

Cat6 Snagless (UTP) 24Awg, Solid Conductor Patch Cables

- High-speed (up to 550 Mhz) Cat6 snagless patch cables to distribute data, voice and video
- Designed for use in Category 6, Category 5e and Category 5 applications
- Also used in Tripp Lite Cat5 Extender installations

Item #	Description	Length	Connector	Connector
N202-025-BL	Cat6 Gigabit Blue 24Awg, Solid Conductor Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N202-050-BL	Cat6 Gigabit Blue 24Awg, Solid Conductor Snagless Patch Cable	50 ft.	RJ45 (Male) 	RJ45 (Male) 
N202-075-BL	Cat6 Gigabit Blue 24Awg, Solid Conductor Snagless Patch Cable	75 ft.	RJ45 (Male) 	RJ45 (Male) 
N202-100-BL	Cat6 Gigabit Blue 24Awg, Solid Conductor Snagless Patch Cable	100 ft.	RJ45 (Male) 	RJ45 (Male) 
N202-125-BL	Cat6 Gigabit Blue 24Awg, Solid Conductor Snagless Patch Cable	125 ft.	RJ45 (Male) 	RJ45 (Male) 
N202-150-BL	Cat6 Gigabit Blue 24Awg, Solid Conductor Snagless Patch Cable	150 ft.	RJ45 (Male) 	RJ45 (Male) 
N202-200-BL	Cat6 Gigabit Blue 24Awg, Solid Conductor Snagless Patch Cable	200 ft.	RJ45 (Male) 	RJ45 (Male) 

Cat6 (UTP) Patch Cables

- High-speed (up to 550 Mhz) Cat6 snagless patch cables to distribute data, voice and video
- Designed for use in Category 6, Category 5e and Category 5 applications
- Angled connectors are ideal for use in tight spaces

Item #	Description	Length	Connector	Connector
N204-003-BL-DN	Cat6 Gigabit Blue Down-Angle Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-003-BL-LA	Cat6 Gigabit Blue Left-Angle Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-003-BL-RA	Cat6 Gigabit Blue Right-Angle Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-003-BL-UP	Cat6 Gigabit Blue Up-Angle Snagless Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-005-BL-DN	Cat6 Gigabit Blue Down-Angle Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-005-BL-LA	Cat6 Gigabit Blue Left-Angle Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-005-BL-RA	Cat6 Gigabit Blue Right-Angle Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-005-BL-UP	Cat6 Gigabit Blue Up-Angle Snagless Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-010-BL-DN	Cat6 Gigabit Blue Down-Angle Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-010-BL-LA	Cat6 Gigabit Blue Left-Angle Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-010-BL-RA	Cat6 Gigabit Blue Right-Angle Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N204-010-BL-UP	Cat6 Gigabit Blue Up-Angle Snagless Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 

Cat6 Snagless (UTP) Cross-Over Cables


- High-speed (up to 550 Mhz) Cat6 snagless cross-over patch cables to distribute data, voice and video
- Designed for use in Category 6, Category 5e and Category 5 applications
- Designed to connect hub-to-hub, PC-to-PC or Mac-to-Mac and perfect in conjunction with 10/100/1000BASE-T networks

Item #	Description	Length	Connector	Connector
N210-007-GY	Cat6 Gigabit Gray Cross-Over Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N210-010-GY	Cat6 Gigabit Gray Cross-Over Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 

Cat6a (Augmented Cat6) Snagless 10Gb Certified Patch Cables

- Next-generation Cat6 patch cables—10Gbps communication
- NEXT performance beyond 650 Mhz

Item #	Description	Length	Connector	Connector
N261-007-AQ	Cat6a 10Gb Aqua Certified Snagless Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N261-014-AQ	Cat6a 10Gb Aqua Certified Snagless Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N261-025-AQ	Cat6a 10Gb Aqua Certified Snagless Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 

 

Category 6/5e Network Solutions (continued)

Cat5/5e Retractable Patch Cable

- Ideal for connecting the RJ45 network port on a notebook to a network

Item #	Description	Length	Connector	Connector
N009-004-R	Retractable RJ45 Ethernet Patch Cable	4 ft.	RJ45 (Male) 	RJ45 (Male) 

Cat5e Shielded (STP) Patch Cables


- These cables are manufactured from PVC, 4-pair, stranded shielded twisted pair, and are rated for 350MHz/1Gbps communication

Item #	Description	Length	Connector	Connector
N105-007-GY	Cat5e 350MHz Gray Molded Shielded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N105-010-GY	Cat5e 350MHz Gray Molded Shielded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N105-025-GY	Cat5e 350MHz Gray Molded Shielded Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N105-050-GY	Cat5e 350MHz Gray Molded Shielded Patch Cable	50 ft.	RJ45 (Male) 	RJ45 (Male) 
N105-100-GY	Cat5e 350MHz Gray Molded Shielded Patch Cable	100 ft.	RJ45 (Male) 	RJ45 (Male) 

Cat5e Snagless Patch Cables

- Premium cabling for Category 5 and Category 5e applications—rated for 350MHz/1Gbps communications

Item #	Description	Length	Connector	Connector
N001-003-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-003-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-003-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-003-YW	Cat5e 350MHz Yellow Snagless Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-005-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-005-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-005-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-005-YW	Cat5e 350MHz Yellow Snagless Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-006-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	6 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-006-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	6 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-007-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-007-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-007-BL-R	Cat5e 350MHz Blue Snagless Molded Patch Cable (Retail Package)	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-007-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-007-GY-R	Cat5e 350MHz Gray Snagless Molded Patch Cable (Retail Package)	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-007-YW	Cat5e 350MHz Yellow Snagless Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-010-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-010-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-010-BL-R	Cat5e 350MHz Blue Snagless Molded Patch Cable (Retail Package)	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-010-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-010-YW	Cat5e 350MHz Yellow Snagless Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-014-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-014-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-014-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-014-GY-R	Cat5e 350MHz Gray Snagless Molded Patch Cable (Retail Package)	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-014-YW	Cat5e 350MHz Yellow Snagless Molded Patch Cable	14 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-015-BK	Cat5e 250MHz Black Snagless Molded Patch Cable	15 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-015-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	15 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-025-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-015-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	15 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-025-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-025-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-025-YW	Cat5e 350MHz Yellow Snagless Molded Patch Cable	25 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-030-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	30 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-050-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	50 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-050-BL	Cat5e 350MHz Blue Snagless Molded Patch Cable	50 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-050-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	50 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-075-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	75 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-100-BK	Cat5e 350MHz Black Snagless Molded Patch Cable	100 ft.	RJ45 (Male) 	RJ45 (Male) 

 

Category 6/5e Network Solutions (continued)


Cat5e Snagless Patch Cables (continued)

Item #	Description	Length	Connector	Connector
N001-100-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	100 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-125-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	125 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-150-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	150 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-200-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	200 ft.	RJ45 (Male) 	RJ45 (Male) 
N001-250-GY	Cat5e 350MHz Gray Snagless Molded Patch Cable	250 ft.	RJ45 (Male) 	RJ45 (Male) 

Cat5e Patch Cables

- Premium cabling for Category 5 and Category 5e applications—rated for 350MHz/1Gbps communications

Item #	Description	Length	Connector	Connector
N002-001-BK	Cat5e 350MHz Black Molded Patch Cable	1 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-001-BL	Cat5e 350MHz Blue Molded Patch Cable	1 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-001-GN	Cat5e 350MHz Green Molded Patch Cable	1 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-001-GY	Cat5e 350MHz Gray Molded Patch Cable	1 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-001-RD	Cat5e 350MHz Red Molded Patch Cable	1 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-001-WH	Cat5e 350MHz White Molded Patch Cable	1 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-001-YW	Cat5e 350MHz Yellow Molded Patch Cable	1 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-002-BK	Cat5e 350MHz Black Molded Patch Cable	2 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-002-BL	Cat5e 350MHz Blue Molded Patch Cable	2 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-002-GY	Cat5e 350MHz Gray Molded Patch Cable	2 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-003-BL-MC	Cat5e 350MHz Blue Molded Micro Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-003-BK	Cat5e 350MHz Black Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-003-BL	Cat5e 350MHz Blue Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-003-GN	Cat5e 350MHz Green Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-003-GY	Cat5e 350MHz Gray Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-003-RD	Cat5e 350MHz Red Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-003-WH	Cat5e 350MHz White Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-003-YW	Cat5e 350MHz Yellow Molded Patch Cable	3 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-004-BK	Cat5e 350MHz Black Molded Patch Cable	4 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-004-BL	Cat5e 350MHz Blue Molded Patch Cable	4 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-004-GY	Cat5e 350MHz Gray Molded Patch Cable	4 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-005-BK	Cat5e 350MHz Black Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-005-BL	Cat5e 350MHz Blue Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-005-BL-MC	Cat5e 350MHz Blue Molded Micro Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-005-GN	Cat5e 350MHz Green Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-005-GY	Cat5e 350MHz Gray Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-005-RD	Cat5e 350MHz Red Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-005-WH	Cat5e 350MHz White Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-005-YW	Cat5e 350MHz Yellow Molded Patch Cable	5 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-006-BK	Cat5e 350MHz Black Molded Micro Patch Cable	6 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-006-BL	Cat5e 350MHz Blue Molded Micro Patch Cable	6 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-006-GY	Cat5e 350MHz Gray Molded Micro Patch Cable	6 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-006-RD	Cat5e 350MHz Red Molded Micro Patch Cable	6 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-006-YW	Cat5e 350MHz Yellow Molded Micro Patch Cable	6 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-007-BK	Cat5e 350MHz Black Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-007-BL	Cat5e 350MHz Blue Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-007-GN	Cat5e 350MHz Green Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-007-GY	Cat5e 350MHz Gray Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-007-RD	Cat5e 350MHz Red Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-007-WH	Cat5e 350MHz White Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-007-YW	Cat5e 350MHz Yellow Molded Patch Cable	7 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-010-BK	Cat5e 350MHz Black Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-010-BL	Cat5e 350MHz Blue Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-010-GN	Cat5e 350MHz Green Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-010-GY	Cat5e 350MHz Gray Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-010-RD	Cat5e 350MHz Red Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 
N002-010-WH	Cat5e 350MHz White Molded Patch Cable	10 ft.	RJ45 (Male) 	RJ45 (Male) 

 

Category 6/5e Network Solutions (continued)

Cat5e Patch Cables (continued)

Item #	Description	Length	Connector	Connector
N002-010-YW	Cat5e 350MHz Yellow Molded Patch Cable	10 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-014-BK	Cat5e 350MHz Black Molded Patch Cable	14 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-014-BL	Cat5e 350MHz Blue Molded Patch Cable	14 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-014-GN	Cat5e 350MHz Green Molded Patch Cable	14 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-014-GY	Cat5e 350MHz Gray Molded Patch Cable	14 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-014-OR	Cat5e 350MHz Orange Molded Patch Cable	14 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-014-RD	Cat5e 350MHz Red Molded Patch Cable	14 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-014-WH	Cat5e 350MHz White Molded Patch Cable	14 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-014-YW	Cat5e 350MHz Yellow Molded Patch Cable	14 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-015-BL	Cat5e 350MHz Blue Molded Micro Patch Cable	15 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-015-GY	Cat5e 350MHz Gray Molded Patch Cable	15 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-020-GY	Cat5e 350MHz Gray Molded Patch Cable	20 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-025-BK	Cat5e 350MHz Black Molded Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-025-BL	Cat5e 350MHz Blue Molded Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-025-GN	Cat5e 350MHz Green Molded Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-025-GY	Cat5e 350MHz Gray Molded Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-025-RD	Cat5e 350MHz Red Molded Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-025-WH	Cat5e 350MHz White Molded Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-025-YW	Cat5e 350MHz Yellow Molded Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-050-BK	Cat5e 350MHz Black Molded Patch Cable	50 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-050-GY	Cat5e 350MHz Gray Molded Patch Cable	50 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-075-GY	Cat5e 350MHz Gray Molded Patch Cable	75 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-100-BL	Cat5e 350MHz Blue Molded Patch Cable	100 ft.	RJ45 (Male) A	RJ45 (Male) A
N002-100-GY	Cat5e 350MHz Gray Molded Patch Cable	100 ft.	RJ45 (Male) A	RJ45 (Male) A
N017-025-GY	Cat5e 350MHz Gray Cable, RJ45 to 110 Patch	25 ft.	RJ45 (Male) A	110-Type (Male) B

Cat5e Outdoor-Rated Snagless Patch Cables

- Manufactured with high-quality UV-resistant PVC cable for use in outdoor installations

Item #	Description	Length	Connector	Connector
N007-025-GY	Cat5e 350MHz Gray Molded Outdoor Rated Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A
N007-050-GY	Cat5e 350MHz Gray Molded Outdoor Rated Patch Cable	50 ft.	RJ45 (Male) A	RJ45 (Male) A
N007-100-GY	Cat5e 350MHz Gray Molded Outdoor Rated Patch Cable	100 ft.	RJ45 (Male) A	RJ45 (Male) A
N007-150-GY	Cat5e 350MHz Gray Molded Outdoor Rated Patch Cable	150 ft.	RJ45 (Male) A	RJ45 (Male) A
N007-200-GY	Cat5e 350MHz Gray Molded Outdoor Rated Patch Cable	200 ft.	RJ45 (Male) A	RJ45 (Male) A



Cat5e Cross-Over Patch Cables

- Designed to connect hub-to-hub, PC-to-PC or Mac-to-Mac, and perfect for use in 10BASE-T and 100BASE-T networks

Item #	Description	Length	Connector	Connector
N010-007-GY	Cat5e 350MHz Gray Cross-Over Snagless Molded Patch Cable	7 ft.	RJ45 (Male) A	RJ45 (Male) A
N010-010-GY	Cat5e 350MHz Gray Cross-Over Snagless Molded Patch Cable	10 ft.	RJ45 (Male) A	RJ45 (Male) A
N010-010-YW	Cat5e 350MHz Yellow Cross-Over Snagless Molded Patch Cable	10 ft.	RJ45 (Male) A	RJ45 (Male) A
N010-025-YW	Cat5e 350MHz Yellow Cross-Over Snagless Molded Patch Cable	25 ft.	RJ45 (Male) A	RJ45 (Male) A

T1 Patch Cables

Item #	Description	Length	Connector	Connector
N265-003	T1 RJ48C Patch Cable - Straight Through	3 ft.	RJ45 (Male) A	RJ45 (Male) A
N265-005	T1 RJ48C Patch Cable - Straight Through	5 ft.	RJ45 (Male) A	RJ45 (Male) A
N265-007	T1 RJ48C Patch Cable - Straight Through	7 ft.	RJ45 (Male) A	RJ45 (Male) A
N265-010	T1 RJ48C Patch Cable - Straight Through	10 ft.	RJ45 (Male) A	RJ45 (Male) A
N266-003	T1 RJ48C Patch Cable - Cross-Over	3 ft.	RJ45 (Male) A	RJ45 (Male) A
N266-005	T1 RJ48C Patch Cable - Cross-Over	5 ft.	RJ45 (Male) A	RJ45 (Male) A
N266-007	T1 RJ48C Patch Cable - Cross-Over	7 ft.	RJ45 (Male) A	RJ45 (Male) A
N266-010	T1 RJ48C Patch Cable - Cross-Over	10 ft.	RJ45 (Male) A	RJ45 (Male) A

  

Category 6/5e Network Solutions (continued)

Cat5e Bulk Cables, Connectors & In-Line Couplers

- Solid PVC high-speed (up to 350 Mhz) bulk cabling to distribute data, voice and video

Item #	Description	Length	Connector	Connector
N020-01K-GY	Cat5e 350MHz Gray Bulk Stranded PVC Cable	1000 ft.	—	—
N022-01K-GY	Cat5e 350MHz Gray Bulk Solid PVC Cable	1000 ft.	—	—
N024-01K	Cat5e 350MHz Gray Bulk Solid Plenum Cable	1000 ft.	—	—
N028-01K-GY	Cat5e Outdoor Rated PVC Bulk Cable	1000 ft.	—	—
N030-010	Cat5e RJ45 Modular Connector, Solid - 10-Pack	—	RJ45 (Male) A	—
N031-050	Cat5e RJ45 Modular Connector, Stranded - 50-Pack	—	RJ45 (Male) A	—
N032-001	Cat5e Modular Coupler - Straight Through	—	RJ45 (Female) B	RJ45 (Female) B
N033-001	Modular Coupler - Straight Through	—	RJ45 (Female) B	RJ45 (Female) B
N042-001-WH	White Keystone Faceplate - 2 Socket	—	—	—
N044-000-R	Network Cable Tester (Cat5e/Cat6/Coax/Phone)	—	RJ45 (Female) B	RJ11 (Female) C
N046-000	110/66 Punchdown Cable Installation Tool	—	—	—
N048-000	Cable Stripping Tool	—	—	—

Cat5e Patch Panels

- Include 110-type termination while meeting and exceeding EIA/TIA TSB-40 Cat5e connecting hardware specifications
- Color coded for both EIA/TIA 568A & 568B installations—19 in. rackmount ready
- Up to 48 ports with high-speed (up to 350 Mhz) communications

Item #	Description	Ports	Connector
N050-012	Cat5e Wall-Mount Patch Panel 568B	12	(x12) RJ45 (Female) B
N052-012	Cat5e Patch Panel 568B - 1U	12	(x12) RJ45 (Female) B
N052-024	Cat5e Patch Panel 568B - 1U	24	(x24) RJ45 (Female) B
N052-048	Cat5e Patch Panel 568B - 2U	48	(x48) RJ45 (Female) B
N054-024	Cat5e Feed-Through Patch Panel - 1U	24	(x24) RJ45 (Female) B

Cat6 Bulk Cables & In-Line Coupler





- Solid PVC high-speed (up to 550 Mhz) bulk cabling to distribute data, voice and video

Item #	Description	Length	Connector	Connector
N222-01K-BL	Cat6 Gigabit Blue Bulk Solid PVC Cable	1000 ft.	—	—
N222-01K-GY	Cat6 Gigabit Gray Bulk Solid PVC Cable	1000 ft.	—	—
N224-01K-GY	Cat6 Gigabit Gray Bulk Solid Plenum Cable	1000 ft.	—	—
N235-001	Cat6/5e Black Straight-Through Snap-In Coupler	—	RJ45 (Female) B	RJ45 (Female) B
N235-001-SH	Shielded Cat6/5e Black Straight-Through Snap-In Coupler	—	RJ45 (Female) B	RJ45 (Female) B
N238-001-BL	Cat6/5e Blue 110-Style Punchdown Keystone Jack	—	110-Type (Female) D	RJ45 (Female) B
N238-001-GN	Cat6/5e Green 110-Style Punchdown Keystone Jack	—	110-Type (Female) D	RJ45 (Female) B
N238-001-RD	Cat6/5e Red 110-Style Punchdown Keystone Jack	—	110-Type (Female) D	RJ45 (Female) B
N238-001-WH	Cat6/5e White 110-Style Punchdown Keystone Jack	—	110-Type (Female) D	RJ45 (Female) B
N238-001-WH-TF	Cat6/5e White Toolless Keystone Jack	—	110-Type (Female) D	RJ45 (Female) B
N238-001-YW	Cat6/5e Yellow 110-Style Punchdown Keystone Jack	—	110-Type (Female) D	RJ45 (Female) B

Cat6 Patch Panels

- Include 110-type termination while meeting and exceeding EIA/TIA TSB-40 Cat6 connecting hardware specifications
- Color coded for both EIA/TIA 568A & 568B installations—19 in. rackmount ready
- Up to 48 ports with high-speed (up to 550 Mhz) communications

Item #	Description	Ports	Connector	Connector
N250-012	Cat6 Wallmount 110-Type Patch Panel	12	(x12) 110-Type (Female) D	(x12) RJ45 (Female) B
N250-024-LP	Cat6 Low-Profile Feed-Through Wallmount/Rackmount Patch Panel - 1U	24	(x24) RJ45 (Female) B	(x24) RJ45 (Female) B
N252-012	Cat6 Rackmount 110-Type Patch Panel - 1U	12	(x12) 110-Type (Female) D	(x12) RJ45 (Female) B
N252-024	Cat6 Rackmount 110-Type Patch Panel - 1U	24	(x24) 110-Type (Female) D	(x24) RJ45 (Female) B
N252-024-HU	Cat6 Rackmount 110-Type Patch Panel - 0.5U	24	(x24) 110-Type (Female) D	(x24) RJ45 (Female) B
N252-024-V	Cat6 V-Shaped Rackmount 110-Type Patch Panel - 1U	24	(x24) 110-Type (Female) D	(x24) RJ45 (Female) B
N252-048-1U	Cat6 Rackmount 110-Type Patch Panel - 1U	48	(x48) 110-Type (Female) D	(x48) RJ45 (Female) B
N252-048	Cat6 Rackmount 110-Type Patch Panel - 2U	48	(x48) 110-Type (Female) D	(x48) RJ45 (Female) B
N254-024	Cat6 Rackmount Feed-Through Patch Panel - 1U	24	(x24) RJ45 (Female) B	(x24) RJ45 (Female) B
N254-024-SH	Shielded Cat6 Rackmount Feed-Through Patch Panel - 1U	24	(x24) RJ45 (Female) B	(x24) RJ45 (Female) B

    

Category 6/5e Network Solutions (continued)

Patch Panel Brackets

Item #	Description
N060-002	Hinged Wall-Mount Patch Panel Bracket - 2U
N060-004	Hinged Wall-Mount Patch Panel Bracket - 4U

CX4 Cables

- Flexible 28AWG Madison TurboTwin™ cable with ejector-style latch mechanism — full 802.3ak compliance

Item #	Description	Length	Connector	Connector
N263-20I	10Gbps CX4 Cable	20 in.	CX4 (Male) A	CX4 (Male) A
N263-01M	10Gbps CX4 Cable	1 m (3 ft.)	CX4 (Male) A	CX4 (Male) A
N263-02M	10Gbps CX4 Cable	2 m (6 ft.)	CX4 (Male) A	CX4 (Male) A
N263-03M	10Gbps CX4 Cable	3 m (10 ft.)	CX4 (Male) A	CX4 (Male) A
N263-05M	10Gbps CX4 Cable	5 m (15 ft.)	CX4 (Male) A	CX4 (Male) A

Fiber Optic Solutions


Tripp Lite fiber optic patch cables offer unparalleled quality and a wide range of options. Each cable assembly comes with its test data affixed to the package, displaying compliance to ANSI specifications. Choose from singlemode, multimode and mode conditioning cables.

62.5/125 Multimode Fiber Optic Patch Cables

- Premium PVC 62.5/125µm multimode patch cables
- Attenuation loss better than the latest industry standards

Item #	Description	Length	Connector	Connector
N302-003	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	ST B	ST B
N302-006	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	ST B	ST B
N302-010	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	ST B	ST B
N302-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	ST B	ST B
N302-06M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	6 m (20 ft.)	ST B	ST B
N302-08M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	8 m (26 ft.)	ST B	ST B
N302-10M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	10 m (33 ft.)	ST B	ST B
N302-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	ST B	ST B
N302-18M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	18 m (60 ft.)	ST B	ST B
N302-23M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	23 m (75 ft.)	ST B	ST B
N302-30M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	30 m (98 ft.)	ST B	ST B
N304-003	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	SC C	ST B
N304-004	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1.2 m (4 ft.)	SC C	ST B
N304-006	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	SC C	ST B
N304-008	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2.5 m (8 ft.)	SC C	ST B
N304-010	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	SC C	ST B
N304-025	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	7.5 m (25 ft.)	SC C	ST B
N304-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	SC C	ST B
N304-06M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	6 m (20 ft.)	SC C	ST B
N304-09M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	9 m (30 ft.)	SC C	ST B
N304-10M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	10 m (33 ft.)	SC C	ST B
N304-11M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	11 m (36 ft.)	SC C	ST B
N304-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	SC C	ST B
N304-23M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	23 m (75 ft.)	SC C	ST B
N304-30M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	30 m (98 ft.)	SC C	ST B
N306-001	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	0.35 m (1 ft.)	SC C	SC C
N306-002	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	0.70 m (2 ft.)	SC C	SC C
N306-003	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	SC C	SC C
N306-004	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1.2 m (4 ft.)	SC C	SC C
N306-006	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	SC C	SC C
N306-010	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	SC C	SC C

 A CX4
(Male)



B ST



C SC



Fiber Optic Solutions (continued)

62.5/125 Multimode Fiber Optic Patch Cables (continued)

Item #	Description	Length	Connector	Connector
N306-04M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	4 m (13 ft.)	SC A	SC A
N306-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	SC A	SC A
N306-07M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	7 m (23 ft.)	SC A	SC A
N306-08M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	8 m (26 ft.)	SC A	SC A
N306-09M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	9 m (30 ft.)	SC A	SC A
N306-12M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	12 m (40 ft.)	SC A	SC A
N306-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	SC A	SC A
N306-23M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	23 m (75 ft.)	SC A	SC A
N306-25M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	25 m (82 ft.)	SC A	SC A
N306-30M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	30 m (98 ft.)	SC A	SC A
N306-46M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	46 m (151 ft.)	SC A	SC A
N306-60M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	60 m (197 ft.)	SC A	SC A
N308-003	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	MTRJ B	ST C
N308-006	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	MTRJ B	ST C
N308-010	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	MTRJ B	ST C
N308-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	MTRJ B	ST C
N308-08M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	8 m (26 ft.)	MTRJ B	ST C
N308-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	MTRJ B	ST C
N310-003	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	MTRJ B	SC B
N310-006	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	MTRJ B	SC B
N310-010	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	MTRJ B	SC B
N310-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	MTRJ B	SC B
N310-08M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	8 m (26 ft.)	MTRJ B	SC B
N310-11M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	11 m (36 ft.)	MTRJ B	SC B
N310-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	MTRJ B	SC B
N310-30M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	30 m (98 ft.)	MTRJ B	SC B
N312-01M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	MTRJ B	MTRJ B
N312-02M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	MTRJ B	MTRJ B
N312-03M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	MTRJ B	MTRJ B
N312-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	MTRJ B	MTRJ B
N314-01M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	MTRJ B	LC D
N314-02M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	MTRJ B	LC D
N314-03M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	MTRJ B	LC D
N314-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	MTRJ B	LC D
N314-09M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	9 m (30 ft.)	MTRJ B	LC D
N314-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	MTRJ B	LC D
N316-01M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC D	SC A
N316-02M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC D	SC A
N316-03M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	LC D	SC A
N316-04M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	4 m (13 ft.)	LC D	SC A
N316-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC D	SC A
N316-06M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	6 m (20 ft.)	LC D	SC A
N316-07M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	7 m (23 ft.)	LC D	SC A
N316-10M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	10 m (33 ft.)	LC D	SC A
N316-13M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	13 m (43 ft.)	LC D	SC A
N316-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	LC D	SC A
N316-20M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	20 m (65 ft.)	LC D	SC A
N316-21M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	21 m (69 ft.)	LC D	SC A
N316-25M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	25 m (82 ft.)	LC D	SC A
N316-30M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	30 m (98 ft.)	LC D	SC A
N316-76M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	76 m (250 ft.)	LC D	SC A
N318-01M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC D	ST C
N318-02M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC D	ST C
N318-03M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	LC D	ST C
N318-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC D	ST C
N318-06M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	6 m (20 ft.)	LC D	ST C

A SC

B MTRJ

C ST

D LC



62.5/125 Multimode Fiber Optic Patch Cables (continued)

Item #	Description	Length	Connector	Connector
N318-07M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	7 m (23 ft.)	LC A	ST B
N318-08M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	8 m (26 ft.)	LC A	ST B
N318-09M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	9 m (30 ft.)	ST B	LC A
N318-10M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	10 m (33 ft.)	ST B	LC A
N318-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	ST B	LC A
N318-20M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	20 m (65 ft.)	ST B	LC A
N318-30M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	30 m (98 ft.)	ST B	LC A
N320-001	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 ft.	LC A	LC A
N320-01M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC A	LC A
N320-01M-RD	Duplex Multimode 62.5/125 Fiber Optic Patch Cable (Red)	1 m (3 ft.)	LC A	LC A
N320-02M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC A	LC A
N320-02M-RD	Duplex Multimode 62.5/125 Fiber Optic Patch Cable (Red)	2 m (6 ft.)	LC A	LC A
N320-03M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	3 m (10 ft.)	LC A	LC A
N320-03M-RD	Duplex Multimode 62.5/125 Fiber Optic Patch Cable (Red)	3 m (10 ft.)	LC A	LC A
N320-04M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	4 m (13 ft.)	LC A	LC A
N320-05M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC A	LC A
N320-05M-RD	Duplex Multimode 62.5/125 Fiber Optic Patch Cable (Red)	5 m (16 ft.)	LC A	LC A
N320-06M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	6 m (20 ft.)	LC A	LC A
N320-07M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	7 m (23 ft.)	LC A	LC A
N320-10M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	10 m (33 ft.)	LC A	LC A
N320-10M-RD	Duplex Multimode 62.5/125 Fiber Optic Patch Cable (Red)	10 m (33 ft.)	LC A	LC A
N320-15M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	15 m (50 ft.)	LC A	LC A
N320-15M-RD	Duplex Multimode 62.5/125 Fiber Optic Patch Cable (Red)	15 m (50 ft.)	LC A	LC A
N320-20M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	20 m (65 ft.)	LC A	LC A
N320-20M-RD	Duplex Multimode 62.5/125 Fiber Optic Patch Cable (Red)	20 m (65 ft.)	LC A	LC A
N320-21M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	21 m (69 ft.)	LC A	LC A
N320-30M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	30 m (98 ft.)	LC A	LC A
N320-25M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	25 m (82 ft.)	LC A	LC A
N320-46M	Duplex Multimode 62.5/125 Fiber Optic Patch Cable	46 m (151 ft.)	LC A	LC A

50/125 Multimode Fiber Optic Patch Cables

- Premium PVC 50/125µm multimode patch cables
- Attenuation loss better than the latest industry standards

Item #	Description	Length	Connector	Connector
N504-02M	Duplex Multimode 50/125 Fiber Optic Patch Cable	2 m (6 ft.)	SC C	ST B
N504-05M	Duplex Multimode 50/125 Fiber Optic Patch Cable	5 m (16 ft.)	SC C	ST B
N506-01M	Duplex Multimode 50/125 Fiber Optic Patch Cable	1 m (3 ft.)	SC C	SC C
N506-02M	Duplex Multimode 50/125 Fiber Optic Patch Cable	2 m (6 ft.)	SC C	SC C
N506-03M	Duplex Multimode 50/125 Fiber Optic Patch Cable	3 m (10 ft.)	SC C	SC C
N506-05M	Duplex Multimode 50/125 Fiber Optic Patch Cable	5 m (16 ft.)	SC C	SC C
N506-09M	Duplex Multimode 50/125 Fiber Optic Patch Cable	9 m (30 ft.)	SC C	SC C
N506-10M	Duplex Multimode 50/125 Fiber Optic Patch Cable	10 m (33 ft.)	SC C	SC C
N506-15M	Duplex Multimode 50/125 Fiber Optic Patch Cable	15 m (50 ft.)	SC C	SC C
N506-30M	Duplex Multimode 50/125 Fiber Optic Patch Cable	30 m (98 ft.)	SC C	SC C
N506-50M	Duplex Multimode 50/125 Fiber Optic Patch Cable	50 m (164 ft.)	SC C	SC C
N514-03M	Duplex Multimode 50/125 Fiber Optic Patch Cable	3 m (10 ft.)	MTRJ D	LC A
N516-01M	Duplex Multimode 50/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC A	SC C
N516-02M	Duplex Multimode 50/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC A	SC C
N516-03M	Duplex Multimode 50/125 Fiber Optic Patch Cable	3 m (10 ft.)	LC A	SC C
N516-05M	Duplex Multimode 50/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC A	SC C
N516-07M	Duplex Multimode 50/125 Fiber Optic Patch Cable	7 m (23 ft.)	LC A	SC C
N516-10M	Duplex Multimode 50/125 Fiber Optic Patch Cable	10 m (33 ft.)	LC A	SC C
N516-15M	Duplex Multimode 50/125 Fiber Optic Patch Cable	15 m (50 ft.)	LC A	SC C
N516-20M	Duplex Multimode 50/125 Fiber Optic Patch Cable	20 m (65 ft.)	LC A	SC C
N516-30M	Duplex Multimode 50/125 Fiber Optic Patch Cable	30 m (98 ft.)	LC A	SC C

A LC

B ST

C SC

D MTRJ



50/125 Multimode Fiber Optic Patch Cables (continued)

Item #	Description	Length	Connector	Connector
N516-50M	Duplex Multimode 50/125 Fiber Optic Patch Cable	50 m (164 ft.)	LC A	SC B
N518-01M	Duplex Multimode 50/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC A	ST C
N518-02M	Duplex Multimode 50/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC A	ST C
N518-03M	Duplex Multimode 50/125 Fiber Optic Patch Cable	3 m (10 ft.)	LC A	ST C
N518-05M	Duplex Multimode 50/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC A	ST C
N518-10M	Duplex Multimode 50/125 Fiber Optic Patch Cable	10 m (33 ft.)	LC A	ST C
N518-15M	Duplex Multimode 50/125 Fiber Optic Patch Cable	15 m (50 ft.)	LC A	ST C
N518-20M	Duplex Multimode 50/125 Fiber Optic Patch Cable	20 m (65 ft.)	LC A	ST C
N520-01M	Duplex Multimode 50/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC A	LC A
N520-02M	Duplex Multimode 50/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC A	LC A
N520-03M	Duplex Multimode 50/125 Fiber Optic Patch Cable	3 m (10 ft.)	LC A	LC A
N520-04M	Duplex Multimode 50/125 Fiber Optic Patch Cable	4 m (13 ft.)	LC A	LC A
N520-05M	Duplex Multimode 50/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC A	LC A
N520-07M	Duplex Multimode 50/125 Fiber Optic Patch Cable	7 m (23 ft.)	LC A	LC A
N520-10M	Duplex Multimode 50/125 Fiber Optic Patch Cable	10 m (33 ft.)	LC A	LC A
N520-12M	Duplex Multimode 50/125 Fiber Optic Patch Cable	12 m (39 ft.)	LC A	LC A
N520-15M	Duplex Multimode 50/125 Fiber Optic Patch Cable	15 m (50 ft.)	LC A	LC A
N520-20M	Duplex Multimode 50/125 Fiber Optic Patch Cable	20 m (65 ft.)	LC A	LC A
N520-25M	Duplex Multimode 50/125 Fiber Optic Patch Cable	25 m (82 ft.)	LC A	LC A
N520-30M	Duplex Multimode 50/125 Fiber Optic Patch Cable	30 m (98 ft.)	LC A	LC A
N520-30M-P	Duplex Multimode 50/125 Fiber Optic Patch Cable, Pleum Rated	30 m (98 ft.)	LC A	LC A
N520-35M	Duplex Multimode 50/125 Fiber Optic Patch Cable	35 m (115 ft.)	LC A	LC A
N520-50M	Duplex Multimode 50/125 Fiber Optic Patch Cable	50 m (164 ft.)	LC A	LC A
N520-100M	Duplex Multimode 50/125 Fiber Optic Patch Cable	100 m (328 ft.)	LC A	LC A
N520-152M	Duplex Multimode 50/125 Fiber Optic Patch Cable	152 m (500 ft.)	LC A	LC A
N546-05M	Duplex Multimode 50/125 Fiber Optic Patch Cable	5 m (16 ft.)	MTP D	MTP D
N546-10M	Duplex Multimode 50/125 12-Fiber Fiber Optic Patch Cable	10 m (33 ft.)	MTP D	MTP D
N546-15M	Duplex Multimode 50/125 12-Fiber Fiber Optic Patch Cable	15 m (50 ft.)	MTP D	MTP D
N546-20M	Duplex Multimode 50/125 12-Fiber Fiber Optic Patch Cable	20 m (65 ft.)	MTP D	MTP D
N546-30M	Duplex Multimode 50/125 12-Fiber Fiber Optic Patch Cable	30 m (100 ft.)	MTP D	MTP D
N546-50M	Duplex Multimode 50/125 12-Fiber Fiber Optic Patch Cable	50 m (165 ft.)	MTP D	MTP D

8.3/125 Singlemode Fiber Optic Patch Cables

- Premium PVC 8.3/125µm singlemode patch cables
- Attenuation loss better than the latest industry standards

Item #	Description	Length	Connector	Connector
N352-01M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	1 m (3 ft.)	ST C	ST C
N352-02M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	2 m (6 ft.)	ST C	ST C
N352-03M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	3 m (10 ft.)	ST C	ST C
N352-05M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	5 m (16 ft.)	ST C	ST C
N352-09M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	9 m (30 ft.)	ST C	ST C
N352-15M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	15 m (50 ft.)	ST C	ST C
N354-01M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	1 m (3 ft.)	SC B	ST C
N354-02M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	2 m (6 ft.)	SC B	ST C
N354-03M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	3 m (10 ft.)	SC B	ST C
N354-05M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	5 m (16 ft.)	SC B	ST C
N354-09M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	9 m (30 ft.)	SC B	ST C
N354-15M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	15 m (50 ft.)	SC B	ST C
N356-01M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	1 m (3 ft.)	SC B	SC B
N356-02M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	2 m (6 ft.)	SC B	SC B
N356-03M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	3 m (10 ft.)	SC B	SC B
N356-05M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	5 m (16 ft.)	SC B	SC B
N356-06M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	6 m (20 ft.)	SC B	SC B
N356-09M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	9 m (30 ft.)	SC B	SC B
N356-10M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	10 m (33 ft.)	SC B	SC B

A LC

B SC

C ST

D MTP



8.3/125 Singlemode Fiber Optic Patch Cables (continued)

Item #	Description	Length	Connector	Connector
N356-15M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	15 m (50 ft.)	SC A	SC A
N356-30M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	30 m (98 ft.)	SC A	SC A
N366-01M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC B	SC A
N366-01M-AP	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable (Angle Physical Contact)	1 m (3 ft.)	LC B	SC A
N366-02M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC B	SC A
N366-03M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	3 m (9 ft.)	LC B	SC A
N366-03M-AP	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable (Angle Physical Contact)	3 m (9 ft.)	LC B	SC A
N366-05M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC B	SC A
N366-10M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	10 m (33 ft.)	LC B	SC A
N366-15M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	15 m (50 ft.)	LC B	SC A
N366-25M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	25 m (82 ft.)	LC B	SC A
N368-01M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC B	ST C
N368-02M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC B	ST C
N368-03M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	3 m (9 ft.)	LC B	ST C
N368-05M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC B	ST C
N368-05M-P	Duplex Singlemode 8.3/125 Plenum Rated Fiber Optic Patch Cable	5 m (16 ft.)	LC B	ST C
N368-07M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	7 m (23 ft.)	LC B	ST C
N368-10M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	10 m (33 ft.)	LC B	ST C
N368-15M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	15 m (50 ft.)	LC B	ST C
N368-20M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	20 m (60 ft.)	LC B	ST C
N368-30M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	30 m (98 ft.)	LC B	ST C
N370-01M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	1 m (3 ft.)	LC B	LC B
N370-02M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC B	LC B
N370-03M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	3 m (10 ft.)	LC B	LC B
N370-05M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	5 m (16 ft.)	LC B	LC B
N370-10M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	10 m (33 ft.)	LC B	LC B
N378-02M	Duplex Singlemode 8.3/125 Fiber Optic Patch Cable	2 m (6 ft.)	LC B	FC D

Mode Conditioning Fiber Optic Patch Cables

- For Gigabit Ethernet applications when Gigabit 1000Base-LX routers and switches are installed into existing multimode cable plants

Item#	Description	Length	Connector	Connector
N420-03M	Fiber Optic Mode Conditioning Patch Cable	3 m (10 ft.)	ST C	SC A
N422-01M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	1 m (3 ft.)	ST C	LC B
N422-02M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	2 m (6 ft.)	ST C	LC B
N422-03M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	3 m (10 ft.)	ST C	LC B
N422-10M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	10 m (33 ft.)	ST C	LC B
N424-01M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	1 m (3 ft.)	SC A	LC B
N424-04M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	4 m (13 ft.)	SC A	LC B
N424-05M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	5 m (16 ft.)	SC A	LC B
N426-02M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	2 m (6 ft.)	SC A	SC A
N426-03M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	3 m (10 ft.)	SC A	SC A
N426-05M	Gigabit Ethernet Mode Conditioning Fiber Optic Patch Cable	5 m (16 ft.)	SC A	SC A

10Gbps 50/125 Multimode Aqua Fiber Optic Patch Cables

- Premium 10Gbps PVC 50/125µm multimode aqua patch cables
- LSZH—Low Smoke Zero Halogen cable

Item#	Description	Length	Connector	Connector
N806-01M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	1 m (3 ft.)	SC A	SC A
N806-02M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	2 m (6 ft.)	SC A	SC A
N806-03M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	3 m (10 ft.)	SC A	SC A
N806-05M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	5 m (16 ft.)	SC A	SC A
N806-10M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	10 m (33 ft.)	SC A	SC A
N806-15M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	15 m (50 ft.)	SC A	SC A
N816-01M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	1 m (3 ft.)	LC B	SC A
N816-02M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	2 m (6 ft.)	LC B	SC A

A SC

B LC

C ST

D FC



10Gbps 50/125 Multimode Aqua Fiber Optic Patch Cables (cont)

Item#	Description	Length	Connector	Connector
N816-03M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	3 m (10 ft.)	LC A	SC B
N816-05M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	5 m (16 ft.)	LC A	SC B
N816-10M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	10 m (33 ft.)	LC A	SC B
N816-15M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	15 m (50 ft.)	LC A	SC B
N818-01M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	1 m (3 ft.)	LC A	ST C
N818-02M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	2 m (6 ft.)	LC A	ST C
N818-03M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	3 m (10 ft.)	LC A	ST C
N818-05M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	5 m (16 ft.)	LC A	ST C
N818-10M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	10 m (33 ft.)	LC A	ST C
N820-01M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	1 m (3 ft.)	LC A	LC A
N820-02M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	2 m (6 ft.)	LC A	LC A
N820-03M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	3 m (10 ft.)	LC A	LC A
N820-05M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	5 m (16 ft.)	LC A	LC A
N820-06M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	6 m (20 ft.)	LC A	LC A
N820-07M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	7 m (23 ft.)	LC A	LC A
N820-10M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	10 m (33 ft.)	LC A	LC A
N820-15M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	15 m (50 ft.)	LC A	LC A
N820-20M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	20 m (65 ft.)	LC A	LC A
N820-25M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	25 m (80 ft.)	LC A	LC A
N820-30M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	30 m (100 ft.)	LC A	LC A
N820-50M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	50 m (165 ft.)	LC A	LC A
N836-01M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	1 m (3 ft.)	LC A	Mini-LC D
N836-02M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	2 m (6 ft.)	LC A	Mini-LC D
N836-03M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	3 m (10 ft.)	LC A	Mini-LC D
N836-05M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	5 m (16 ft.)	LC A	Mini-LC D
N836-10M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	10 m (33 ft.)	LC A	Mini-LC D
N838-01M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	1 m (3 ft.)	Mini-LC D	Mini-LC D
N838-02M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	2 m (6 ft.)	Mini-LC D	Mini-LC D
N838-03M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	3 m (10 ft.)	Mini-LC D	Mini-LC D
N838-05M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	5 m (16 ft.)	Mini-LC D	Mini-LC D
N838-10M	10Gb Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	10 m (33 ft.)	Mini-LC D	Mini-LC D

40/100 Gbps 50/125 Multimedia Aqua OM4 Fiber Optic Patch Cables


- Designed for 40/100Gb Ethernet applications, OM4 Rated
- LSZH—Low Smoke Zero Halogen cable

Item#	Description	Length	Connector	Connector
N820-01M-OM4	40/100Gb OM4 Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	1 m (3 ft.)	LC A	LC A
N820-02M-OM4	40/100Gb OM4 Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	2 m (6 ft.)	LC A	LC A
N820-03M-OM4	40/100Gb OM4 Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	3 m (10 ft.)	LC A	LC A
N820-05M-OM4	40/100Gb OM4 Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	5 m (16 ft.)	LC A	LC A
N820-10M-OM4	40/100Gb OM4 Duplex Multimode 50/125 LSZH Aqua Fiber Patch Cable	10 m (33 ft.)	LC A	LC A

Couplers

- Provide a simple way to link two fiber optic cables

Item #	Description	Connector	Connector
N452-000	Duplex Multimode Fiber Coupler - 10/100	SC (Female) E	SC (Female) E
N455-000	Duplex Multimode Fiber Coupler - 10/100	LC (Female) F	LC (Female) F
N455-000-S	Duplex Singlemode Fiber Coupler	LC (Female) F	LC (Female) F
N456-000	Duplex Multimode Fiber Coupler - 10/100/1000	SC (Female) E	ST (Female) G

 

Fiber Optic Solutions (continued)

Media Converters

- Convert Cat6/Cat5e to fiber optic
- UTP port senses network speed (10/100)

Item #	Description	Connector	Connector
N784-001-SC	External Multimode Media Converter	SC (Female) A	RJ45 (Female) B
N784-001-ST	External Multimode Media Converter	ST (Female) C	RJ45 (Female) B
N785-001-SC	External Multimode Media Converter	SC (Female) A	RJ45 (Female) B

Adapters

- Utilize Existing SC or ST cabling with new LC type switches

Item #	Description	Length	Connector	Connector
N457-001-50	LC/ST M/F 50/125 Duplex Multimode Adapter Cable	1 ft.	LC D	ST (Female) C
N457-001-62	LC/ST M/F 62.5/125 Duplex Multimode Adapter Cable	1 ft.	LC D	ST (Female) C
N458-001-9	LC/SC M/F 8.3/125 Duplex Singlemode Adapter	1 ft.	LC D	SC (Female) A
N458-001-50	LC/SC M/F 50/125 Duplex Multimode Adapter Cable	1 ft.	LC D	SC (Female) A
N458-001-62	LC/SC M/F 62.5/125 Duplex Multimode Adapter Cable	1 ft.	LC D	SC (Female) A

Patch Panels

- Provide efficient and easy management of fiber optic cables in a rack or cabinet

Item #	Description	Ports	Connector	Connector
N480-012-SC	MTP 50/125 Fiber Breakout 1U Patch Panel	12	MTP E	SC (Female) A
N480-024-LC	MTP 50/125 Fiber Breakout 1U Patch Panel	24	MTP E	LC (Female) F
N490-016-LCLC	1U Rackmount Fiber Optic Patch Panel	16	LC (Female) D	LC (Female) F
N490-016-MTRJ	1U Rackmount Fiber Optic Patch Panel	16	MTRJ (Female) G	MTRJ (Female) G
N490-016-SCSC	1U Rackmount Fiber Optic Patch Panel	16	SC (Female) A	SC (Female) A
N490-016-STSC	1U Rackmount Fiber Optic Patch Panel	16	ST (Female) C	SC (Female) A
N490-016-STST	1U Rackmount Fiber Optic Patch Panel	16	ST (Female) C	ST (Female) C

SCSI/SAS/Fibre Channel Solutions

All Tripp Lite SCSI cabling is double-shielded (braid and foil) to provide the most reliable, error-free data communications available. Tripp Lite offers a complete line of internal and external solutions for SCSI/RAID and Fibre Channel ranging from the very latest Ultra 320 to legacy SCSI-1 and every combination in between. Since all SCSI generations are backward-compatible, they ensure your cabling investment will always keep pace with technology.

SCSI Adapters


- Convert SCSI devices to work with SCSI installations—perfect for upgrading mixed installations

Item #	Description	Connector	Connector
S212-000	Internal SCSI Adapter	HD68 (Female) I	50 Socket IDC (Female) L
S236-000	External SCSI II Adapter	HD50 (Male) J	DB25 (Female) K

SCSI Terminators

- Provide reliable termination for high-speed single-ended drive chains

Item #	Description	Connector
S122-000	External Active SCSI II Single-End Terminator	HD50 (Male) J
S140-000	External SCSI Ultra320 LVD Active Terminator	HD68 (Male) I
S142-000	External SCSI Ultra320 LVD Active Terminator	VHDCI68 (Male) M

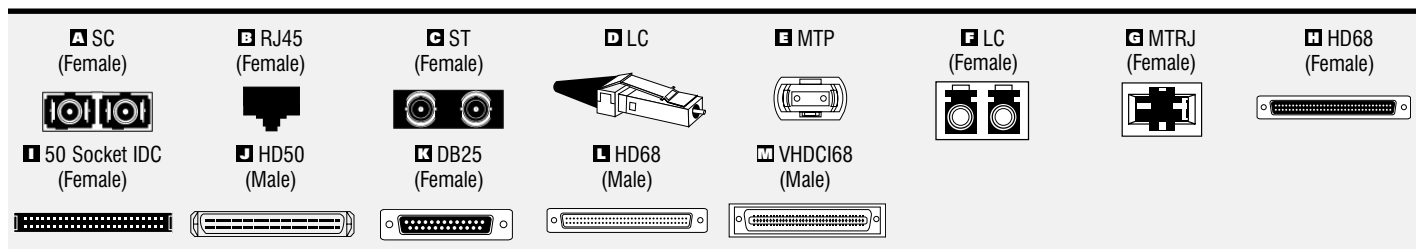

SCSI Ribbon Cables

- Complete offering of Ultra320/Ultra160/Ultra2 LVD/SE solutions with active terminator

Item #	Description	Length	Connector
S051-21I	Internal/External SCSI U160 LVD Ribbon Cable	21 in.	(x2) HD68 (Male) A
S052-21I	Internal SCSI U160 2-Drive LVD/SE Ribbon Cable with Terminator	21 in.	(x3) HD68 (Male) A
S053-36I	Internal SCSI U160 3-Drive Ribbon Cable with Terminator	36 in.	(x4) HD68 (Male) A
S054-45I	Internal SCSI U160 4-Drive Ribbon Cable with Terminator	45 in.	(x5) HD68 (Male) A
S055-38I	Internal SCSI U160 5-Drive LVD/SE Ribbon Cable with Terminator	38 in.	(x6) HD68 (Male) A
S063-31I	Internal SCSI U320 3-Drive Ribbon LVD Cable with Terminator	31 in.	(x4) HD68 (Male) A
S065-42I	Internal SCSI U320 5-Drive Ribbon LVD Cable with Terminator	42 in.	(x6) HD68 (Male) A

SCSI External Cables


- Premium double-shielded cables connect two SCSI devices together

Item #	Description	Length	Connector	Connector
S362-006	SCSI II Cable	6 ft.	HD50 (Male) B	DB25 (Male) C
S366-006	SCSI II Cable	6 ft.	HD50 (Male) B	HD50 (Male) B
S404-006	SCSI III Cable	6 ft.	HD68 (Male) A	HD68 (Male) A
S410-006	SCSI III to II Cable	6 ft.	HD50 (Male) B	HD68 (Male) A
S442-006	SCSI III to II Cable	6 ft.	VHDCI68 (Male) D	HD50 (Male) B
S444-006	SCSI III Cable	6 ft.	VHDCI68 (Male) D	HD68 (Male) A
S446-006	SCSI III Cable	6 ft.	VHDCI68 (Male) D	VHDCI68 (Male) D
S450-006	SCSI Ultra2/U160/U320 LVD/SE Cable	6 ft.	HD68 (Male) A	HD68 (Male) A
S450-010	SCSI Ultra2/U160/U320 LVD/SE Cable	10 ft.	HD68 (Male) A	HD68 (Male) A
S454-006	SCSI Ultra2/U160/U320 LVD/SE Cable Offset	6 ft.	VHDCI68 (Male) D	HD68 (Male) A
S455-003	SCSI U160/U320 LVD/SE Cable	3 ft.	VHDCI68 (Male) D	HD68 (Male) A
S455-006	SCSI U160/U320 LVD/SE Cable	6 ft.	VHDCI68 (Male) D	HD68 (Male) A
S455-010	SCSI U160/U320 LVD/SE Cable	10 ft.	VHDCI68 (Male) D	HD68 (Male) A
S456-003	SCSI U160/U320 LVD/SE Cable Offset	3 ft.	VHDCI68 (Male) D	VHDCI68 (Male) D
S456-006	SCSI U160/U320 LVD/SE Cable Offset	6 ft.	VHDCI68 (Male) D	VHDCI68 (Male) D
S457-006	SCSI U160/U320 LVD/SE Cable	6 ft.	VHDCI68 (Male) D	VHDCI68 (Male) D
S457-010	SCSI U160/U320 LVD/SE Cable	10 ft.	VHDCI68 (Male) D	VHDCI68 (Male) D

SAS (Serial Attached SCSI) Cables

- Data rates up to 3.0 Gbps

Item #	Description	Length	Connector	Connector
S500-01M	Internal SAS Cable	1 m (3 ft.)	SFF-8484 E	SFF-8484 E
S501-24N	Internal SAS Cable	24 in.	SFF-8484 E	SFF-8482 F
S502-01M	Internal SAS Cable	1 m (3 ft.)	SFF-8484 E	(x4) 7-Pin Straight (Female) G
S502-20N	Internal SAS 4-in-1 to 4x1 Cable, 32P to 4x7P	20 in.	SFF-8484 E	(x4) 7-Pin Straight (Female) G
S504-24N	Internal SAS Cable	24 in.	SFF-8087 G	(x4) SFF-8482 F
S506-003	Internal SAS mSAS to mSAS 36P/36P Cable	1 m (3 ft.)	SFF-8087 G	SFF-8087 G
S506-18N	Internal SAS mSAS to mSAS 36P/36P Cable	18 in.	SFF-8087 G	SFF-8087 G
S508-003	Internal SAS mSAS to (4) SATA 36P/(4) 7P Cable	1 m (3 ft.)	SFF-8087 G	(x4) 7-Pin Straight (Female) G
S508-18N	Internal SAS mSAS to (4) SATA 36P/(4) 7P Cable	18 in.	SFF-8087 G	(x4) 7-Pin Straight (Female) G
S510-003	Internal SAS mSAS to 4-in-1 36P/32P Cable	1 m (3 ft.)	SFF-8087 G	SFF-8484 E
S510-18N	Internal SAS mSAS to 4-in-1 36P/32P Cable	18 in.	SFF-8087 G	SFF-8484 E
S520-01M	External SAS Cable	1 m (3 ft.)	SFF-8088 H	SFF-8470 I
S520-02M	External SAS Cable	2 m (6 ft.)	SFF-8088 H	SFF-8470 I
S520-03M	External SAS Cable	3 m (10 ft.)	SFF-8088 H	SFF-8470 I
S522-01M	External SAS Cable	1 m (3 ft.)	SFF-8470 I	SFF-8470 I
S522-02M	External SAS Cable	2 m (6 ft.)	SFF-8470 I	SFF-8470 I
S522-03M	External SAS Cable	3 m (10 ft.)	SFF-8470 I	SFF-8470 I
S524-01M	External SAS Cable	1 m (3 ft.)	SFF-8088 A	SFF-8088 A
S524-02M	External SAS Cable	2 m (6 ft.)	SFF-8088 A	SFF-8088 A
S524-03M	External SAS Cable	3 m (10 ft.)	SFF-8088 A	SFF-8088 A

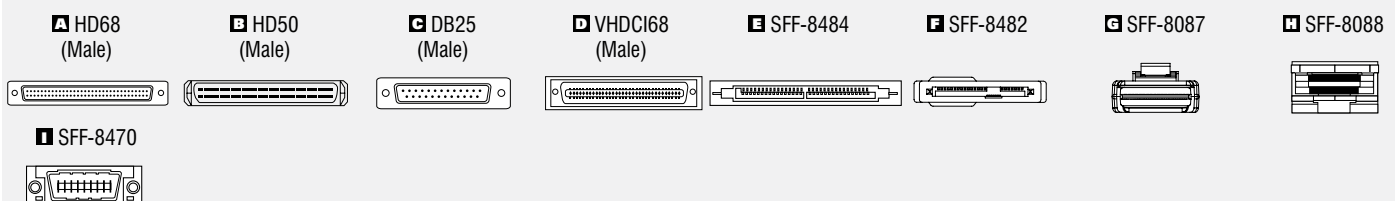

KVM Switch Solutions

A Keyboard, Video, Mouse (KVM) switch allows a user to control multiple computers from a single console. Space-saving, convenient and economical, a KVM switch is flexible enough to meet the needs of any home office, small/mid-size or enterprise application. Plus, a KVM switch is easy to install, configure and manage.

KVM Switches

- Rackmount, rackmount console and desktop solutions available with up to 48 ports; can control over 4,000 PCs or servers through daisy-chaining additional units

Secure KVM Switches

Item #	Description	Ports
B002-DUA2	Secure KVM Switch - DVI/USB, Audio, NIAP-Certified (EAL 2+), TAA Compliant	2
B002-DUA4	Secure KVM Switch - DVI/USB, Audio, NIAP-Certified (EAL 2+), TAA Compliant	4

Desktop KVM Switches

Item #	Description	Ports
B004-DUA2-K-R	Compact Desktop KVM Switch - DVI/USB, Audio	2
B004-DUA4-K-R	Desktop KVM Switch - DVI/USB, Audio, USB Hub	4
B004-VPA2-K-R	Compact Desktop KVM Switch - VGA/PS2, Audio	2
B004-VUA2-K-R	Compact Desktop KVM Switch - VGA/USB, Audio	2
B004-008	Standard Rackmount KVM Switch - VGA/PS2, 1U	8
B006-VU4-R	Desktop KVM Switch - VGA/USB	4
B006-VUA4-K-R	Desktop/Rackmount KVM Switch - VGA/USB, Audio, (x2) USB Hub Ports, OSD, 1U	4
B022-002-KT-R	Slim Desktop KVM Switch - VGA/PS2/USB, (x2) PS/2 Cable Kits	2
B022-004-R	Slim Desktop KVM Switch - VGA/PS2/USB	4

Rackmount KVM Switches - Standard KVM Cable Kits

Item #	Description	Ports
B004-008	Standard Rackmount KVM Switch - VGA/PS2, 1U	8
B006-VUA4-K-R	Desktop/Rackmount KVM Switch - VGA/USB, Audio, (x2) USB Hub Ports, OSD, 1U	4
B007-008	Rackmount KVM Switch - VGA/PS2, OSD, 1U	8
B020-008-17	NetDirector Console KVM Switch - 17 in. Monitor, USB/PS2, OSD, 1U	8
B020-016-17	NetDirector Console KVM Switch - 17 in. Monitor, USB/PS2, OSD, 1U	16
B020-U08-19KTAA	NetDirector Console KVM Switch - 19 in. Monitor, USB/PS2, (x8) Cable Kits, OSD, 1U, TAA Compliant	8
B020-U08-19-K	NetDirector Console KVM Switch - 19 in. Monitor, USB/PS2, (x8) Cable Kits, OSD, 1U	8
B020-U16-19-K	NetDirector Console KVM Switch - 19 in. Monitor, USB/PS2, (x8) Cable Kits, OSD, 1U	16
B022-U16	NetDirector Rackmount KVM Switch - VGA/PS2/USB, OSD, 1U	16
B040-008-19	NetController Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U	8
B040-016-19	NetController Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U	16
B042-004	NetController Rackmount KVM Switch - USB/PS2, OSD, 1U	4
B042-008	NetController Rackmount KVM Switch - USB/PS2, OSD, 1U	8
B042-016	NetController Rackmount KVM Switch - USB/PS2, OSD, 1U	16

Rackmount KVM Switches - Cat5 Cabling

Item #	Description	Ports
B060-016-2	NetDirector Cat5 Rackmount KVM Switch - USB/PS2, OSD, 2-User, 1U, TAA Compliant	16
B064-016	NetDirector Cat5 Rackmount KVM Switch - USB/PS2, OSD, 1U, TAA Compliant	16
B070-008-19	NetCommander Cat5 Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U	8
B070-016-19	NetCommander Cat5 Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U	16
B070-016-19TAA	NetCommander Cat5 Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U, TAA Compliant	16
B072-008-1	NetCommander Cat5 Rackmount KVM Switch - USB/PS2, OSD, 1U, TAA Compliant	8
B072-016-1	NetCommander Cat5 Rackmount KVM Switch - USB/PS2, OSD, 1U, TAA Compliant	16

Rackmount KVM Switches - IP KVM's and IP Remote Access Units

Item #	Description	Ports
B020-016-17-IP	NetDirector Console KVM Switch - 17 in. Monitor, USB/PS2, OSD, IP Remote Access, 1U, TAA Compliant	16
B020-U08-19-IP	NetDirector Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, IP Remote Access, 1U	8
B051-000	IP Remote Access Unit	
B064-016-02-IPG	NetDirector Cat5 IP Rackmount KVM Switch - USB/PS2, OSD, IP Remote Access, 3-User, Virtual Media, 1U, TAA Compliant	16
B064-016-04-IPG	NetDirector Cat5 IP Rackmount KVM Switch - USB/PS2, OSD, IP Remote Access, 5-User, Virtual Media, 1U, TAA Compliant	16
B064-032-02-IPG	NetDirector Cat5 IP Rackmount KVM Switch - USB/PS2, OSD, IP Remote Access, 3-User, Virtual Media, 1U, TAA Compliant	32
B064-032-04-IPG	NetDirector Cat5 IP Rackmount KVM Switch - USB/PS2, OSD, IP Remote Access, 5-User, Virtual Media, 1U, TAA Compliant	32
B070-016-19-IP	NetCommander Cat5 IP Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, IP Remote Access, 1U	16
B072-016-1-IP	NetCommander Cat5 IP Rackmount KVM Switch - USB/PS2, OSD, IP Remote Access, 1U, TAA Compliant	16

Consoles

Item #	Description	Ports
B021-000-17	Rackmount Console - 17 in. Monitor, 1U	—
B021-000-17TAA	Rackmount Console - 17 in. Monitor, 1U, TAA Compliant	—
B021-02R-17	Rackmount Console - 17 in. Monitor, Dual-Rail Technology, 1U	—
B021-000-19	Rackmount Console - 19 in. Monitor, 1U	—
B021-000-19-SH	Rackmount Console - 19 in. Monitor, Short-Depth for use in racks with a minimum depth of 19 in., 1U	—

KVM Switch Solutions

KVM Switches (continued)

Console KVM Switches

Item #	Description	Ports
B020-008-17	NetDirector Console KVM Switch - 17 in. Monitor, USB/PS2, OSD , 1U	8
B020-016-17	NetDirector Console KVM Switch - 17 in. Monitor, USB/PS2, OSD , 1U	16
B020-016-17-IP	NetDirector Console KVM Switch - 17 in. Monitor, USB/PS2, OSD, IP Remote Access, 1U, TAA Compliant	16
B020-U08-19KTAA	NetDirector Console KVM Switch - 19 in. Monitor, USB/PS2, (x8) Cable Kits, OSD, 1U, TAA Compliant	8
B020-U08-19-IP	NetDirector Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, IP Remote Access, 1U	8
B020-U08-19-K	NetDirector Console KVM Switch - 19 in. Monitor, USB/PS2, (x8) Cable Kits, OSD, 1U	8
B020-U16-19-K	NetDirector Console KVM Switch - 19 in. Monitor, USB/PS2, (x8) Cable Kits, OSD, 1U	16
B040-008-19	NetController Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U	8
B040-016-19	NetController Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U	16
B070-008-19	NetCommander Cat5 Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U	8
B070-016-19	NetCommander Cat5 Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U	16
B070-016-19TAA	NetCommander Cat5 Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, 1U, TAA Compliant	16
B070-016-19-IP	NetCommander Cat5 IP Console KVM Switch - 19 in. Monitor, USB/PS2, OSD, IP Remote Access, 1U	16

Console Servers

Item #	Description	Ports
B092-016	Console Server - KVM Access and PowerAlert	16
B094-008-2E-M-F	Console Server - Dual NIC, Built-In Modem, Built-In USB Flash, 1U	8
B096-016	Console Server - Dual NIC, Built-In Modem, Built-In USB Flash, 1U, TAA Compliant	16
B096-048	Console Server - Dual NIC, Built-In Modem, Built-In USB Flash, 1U, TAA Compliant	48
B095-003-1E-M	Console Server - Single NIC, Built-In Modem, TAA Compliant	3
B095-004-1E	Console Server - Single NIC, TAA Compliant	4

KVM Cable Kits

- Premium cable kits provide superior performance and cable management and include all the necessary cabling to connect a KVM switch to a computer

Item #	Description	Length
P750-006	PS/2 KVM Cable Kit for B004-008	6 ft.
P750-010	PS/2 KVM Cable Kit for B004-008	10 ft.
P750-015	PS/2 KVM Cable Kit for B004-008	15 ft.
P753-006	PS/2 KVM Cable Kit for B007-008	6 ft.
P753-010	PS/2 KVM Cable Kit for B007-008	10 ft.
P753-015	PS/2 KVM Cable Kit for B007-008	15 ft.
P756-010	USB with Audio KVM Cable Kit for B006-VUA4-K-R	10 ft.
P757-010	PS/2 with Audio KVM Cable Kit for B006-VUA4-K-R	10 ft.
P758-006	USB KVM Cable Kit for B006-VU4-R	6 ft.
P758-010	USB KVM Cable Kit for B006-VU4-R	10 ft.
P759-006	USB with Audio KVM Cable Kit for B002-DUAX KVM Switches	6 ft.
P759-010	USB with Audio KVM Cable Kit for B002-DUAX KVM Switches	10 ft.
P759-015	USB with Audio KVM Cable Kit for B002-DUAX KVM Switches	15 ft.
P774-006	PS/2 KVM Cable Kit for B020-0/B022-0 Series KVM Switches	6 ft.
P774-010	PS/2 KVM Cable Kit for B020-0/B022-0 Series KVM Switches	10 ft.
P774-015	PS/2 KVM Cable Kit for B020-0/B022-0 Series KVM Switches	15 ft.
P774-025	PS/2 KVM Cable Kit for B020-0/B022-0 Series KVM Switches	25 ft.
P776-006	USB KVM Cable Kit for B020-0/B022-0 Series KVM Switches	6 ft.
P776-010	USB KVM Cable Kit for B020-0/B022-0 Series KVM Switches	10 ft.
P776-019	USB KVM Cable Kit for B020-0/B022-0 Series KVM Switches	19 ft.
P778-006	USB/PS2 Combo KVM Cable Kit for B020-U/B022-U KVM Switches	6 ft.
P778-010	USB/PS2 Combo KVM Cable Kit for B020-U/B022-U KVM Switches	10 ft.
P778-015	USB/PS2 Combo KVM Cable Kit for B020-U/B022-U KVM Switches	15 ft.
P780-006	USB/PS2 Combo KVM Cable Kit for B040/B042 KVM Switches	6 ft.
P780-010	USB/PS2 Combo KVM Cable Kit for B040/B042 KVM Switches	10 ft.
P780-015	USB/PS2 Combo KVM Cable Kit for B040/B042 KVM Switches	15 ft.

KVM Switch Solutions

KVM Accessories

- A full line of accessories including adapters, interface modules, cables, extender kit, IP remote access unit and more

Item #	Description	Length
B012-000	PS/2 Keyboard and Mouse Emulator	—
B013-330	Cat5e Console (PS/2 or USB) Extender - 330-ft. Range	—
B015-000	USB to PS/2 Adapter	—
B019-000	Two-Post Rackmount Bracket for Consoles and Console KVMs	—
B051-000	IP Remote Access Unit (KVM over IP)	—
B054-001-PS2	NetDirector Server Interface Module for B060 Series KVM - PS/2	—
B054-001-USB	NetDirector Server Interface Module for B060 Series KVM - USB	—
B055-001-PS2	NetDirector Server Interface for B064 Series KVM - PS/2	—
B055-001-SER	NetDirector Server Interface for B064 Series KVM - Serial	—
B055-001-USB	NetDirector Server Interface for B064 Series KVM - USB	—
B055-001-USB-V2	NetDirector Server Interface with Virtual Media Support for B064 Series KVM - USB	—
B062-002-PS2	NetDirector Console Interface Module for B060 Series KVM - PS/2	—
B062-002-USB	NetDirector Console Interface Module for B060 Series KVMs - USB	—
B078-101-PS2	NetCommander Server Interface Unit for B070/72 KVM - PS/2	—
B078-101-USB	NetCommander Server Interface Unit for B070/72 KVM - USB	—
B090-A9F	Console Server Adapter - Cisco RJ45 F to DB9 F - Straight	—
B090-A9F-X	Console Server Adapter - Cisco RJ45 F to DB9 F - Cross-Over	—
B090-A9M	Console Server Adapter - Cisco RJ45 F to DB9 M - Straight	—
P770-013	KVM Daisy-Chain Cable for the B060 Series KVM Switches	13 ft.
P770-10M	KVM Daisy-Chain Cable for the B060 Series KVM Switches	10 m (33 ft.)
P772-002	KVM Daisy-Chain Cable for B020-016, B020-016-17, B020-008, B020-008-17 & B022-016	2 ft.
P772-006	KVM Daisy-Chain Cable for B020-016, B020-016-17, B020-008, B020-008-17 & B022-016	6 ft.
P781-003	KVM Daisy-Chain Cable for the B040/42 Series KVM Switches	3 ft.
P781-006	KVM Daisy-Chain Cable for the B040/42 Series KVM Switches	6 ft.
P781-010	KVM Daisy-Chain Cable for the B040/42 Series KVM Switches	10 ft.
P781-016	KVM Daisy-Chain Cable for the B040/42 Series KVM Switches	16 ft.

Live Cable Chat

Reach out to a Tripp Lite expert for real-time information and support for all connectivity questions and assistance!

www.tripplite.com/cablefinder

Available Monday–Friday, 9am–5pm CST



1111 W. 35th Street, Chicago, IL 60609

www.tripplite.com

The policy of Tripp Lite is one of continuous improvement. Specifications are subject to change without notice. All trademarks are the property of their respective owners.