

TABLET/CHROMEBOOK CHARGING STATIONS



Mobile Device Charging Stations

Charge, sync, secure and organize up to 48 tablets or 32 Chromebooks in a locking steel cabinet.

Perfect for:

- iPad® • Android™ • Kindle Fire™ • Surface™
- Chromebook™ • MacBook Air® • UltraBook™



TRIPP-LITE TABLET/CHROMEBOOK CHARGING STATIONS



From education to business, in settings as diverse as the hospital room and the factory floor, mobile devices have transformed every organization. As tablet and Chromebook use increases, charging and storing dozens of high-value devices in limited space becomes a big headache and an even bigger security risk. Tripp Lite's iPad/tablet charging stations (USB) and Chromebook charging stations (AC) put an end to cable sprawl and missing assets. Each station organizes up to 48 tablets or 32 Chromebooks while providing high-speed charging, convenient syncing, secure storage and flexible deployment in a variety of settings.

HIGH-SPEED CHARGING

USB charging automatically matches each tablet's top charging speed, ensuring faster turnaround times and maximum availability of in-demand devices. AC charging works through standard outlets that allow you to plug in and charge all your Chromebooks at once. All the outlets and AC adapters are hidden from view during use, and cabling is neatly organized.



USB charging provides up to 2.4 amps (12 watts) per port, automatically matched to each tablet's top charging speed.




AC charging provides up to 12 amps (1,440 watts) total through standard household power outlets.

CONVENIENT SYNCING (iPad/Tablet Charging Stations Only)

Connect the USB uplink port to a host computer to sync connected devices. The sync function is perfect for updating software, backing up important data and returning tablets to standardized/authorized configurations after use. Wired syncing complements wireless functionality by providing high-speed, high-bandwidth device access and reducing congestion of busy Wi-Fi networks.



Connect the included USB cable to the sync uplink port and your computer. Cable access allows syncing while the cabinet is locked.

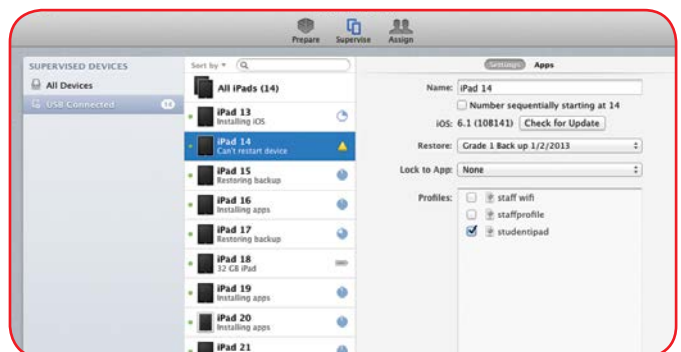

The sync uplink port allows you to configure, back up and restore tablets using software installed on your computer.

SECURE STORAGE




Tablets and Chromebooks represent a substantial investment, both in hardware and valuable data. A classroom equipped with iPads can easily represent more than \$10,000 in hardware costs alone. Inside the charging stations, your devices are surrounded by steel. The door and side panels lock securely for controlled access without interfering with charging. Flow-through ventilation ensures that devices will not overheat, even while charging simultaneously.

FLEXIBLE DEPLOYMENT

Charging stations support a variety of mounting and placement options, including wall, desk, table, counter or floor. They also support stacking configurations. Optional kits add rolling casters, with or without a reversible handle. Available in black or white, charging stations blend into a variety of classroom and office environments.

MOUNTS TO:

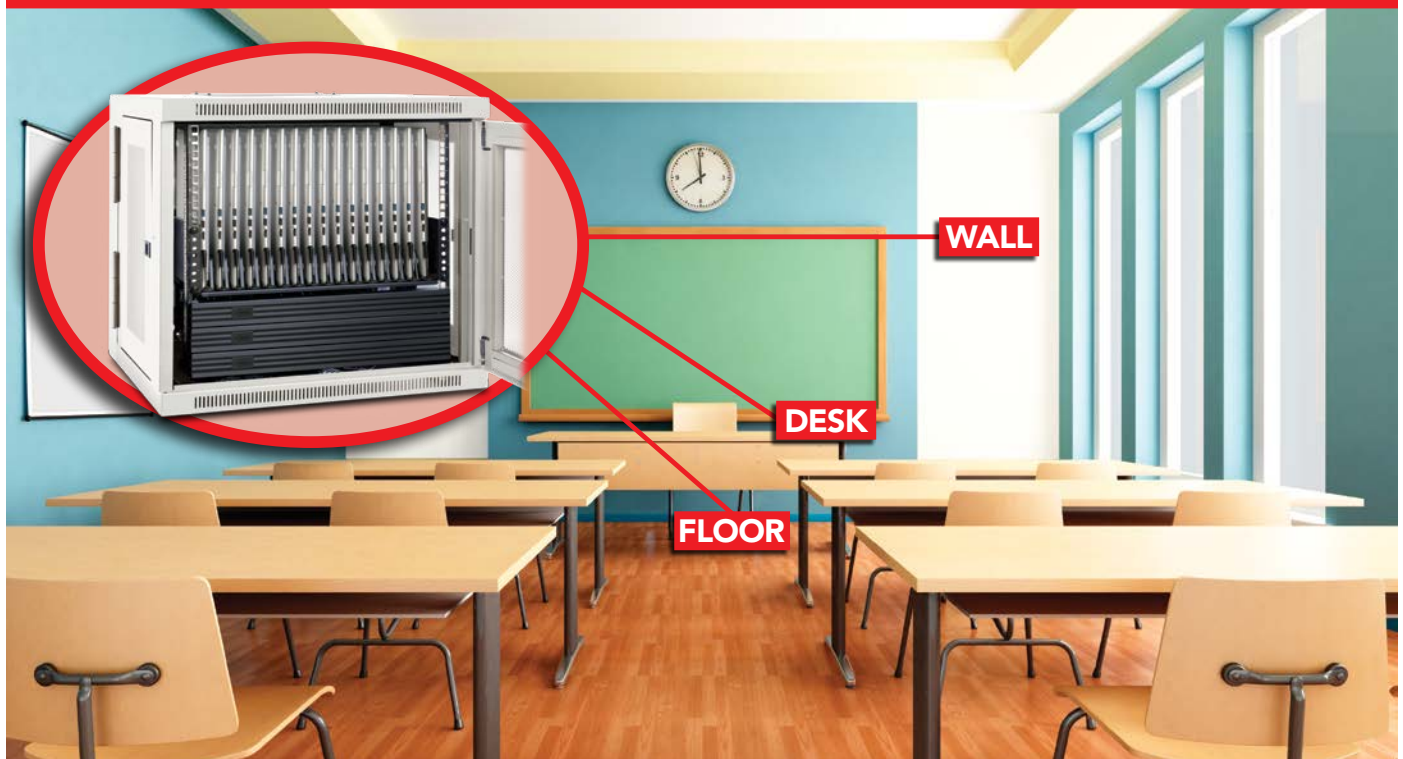


IPAD/TABLET CHARGING STATIONS (USB)



- Secure and organize 16, 32 or 48 tablets, including iPad and Android models
- Provide syncing and high-speed USB charging (up to 2.4 amps per port)
- Mount to wall, desk, table, counter or floor, with support for optional casters and a reversible handle
- Prevent theft and tampering with locking steel door and side panels
- Provide flow-through ventilation to prevent devices from overheating while charging

All models available in black or white


FEATURE FOCUS

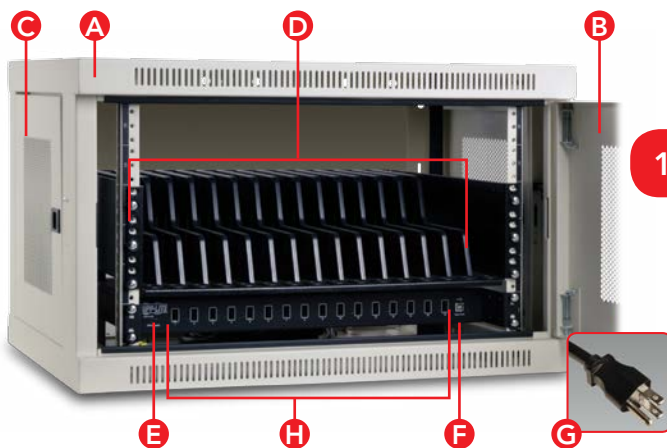

Model: CS16USBW

16 Tablets

- A** Steel Cabinet
- B** Locking Door
- C** Locking Side Panels
- D** Adjustable Shelf Dividers
- E** Firmware Upgrade Port
- F** USB Sync Uplink Port
- G** AC Power Cord with NEMA 5-15P Plug
- H** USB Device-Charging Ports with Activity LEDs

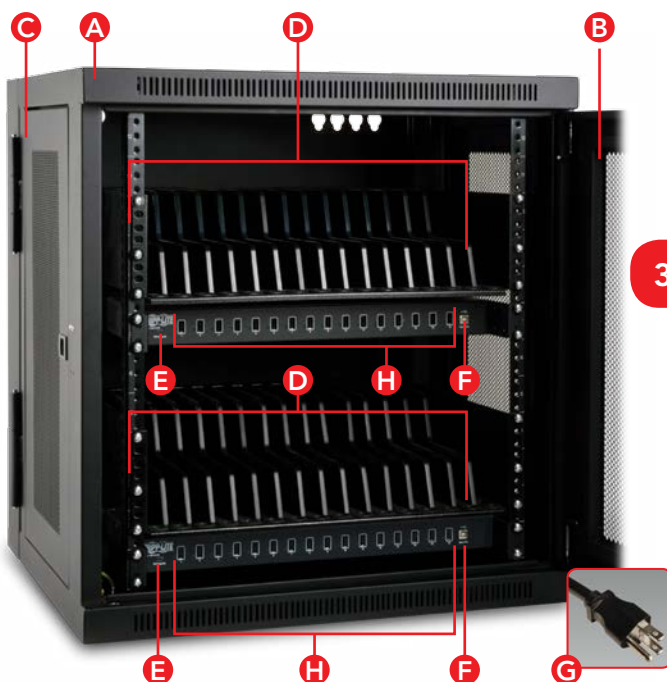

Model: CS32USB

32 Tablets



All charging stations can be equipped with a rolling caster kit (SRCASTER, shown installed above) or a kit that includes casters and a reversible handle (CSHANDLEKIT).



- A** Steel Cabinet
- B** Locking Door
- C** Locking Side Panels
- D** Adjustable Shelf Dividers
- E** Firmware Upgrade Port
- F** USB Sync Uplink Port
- G** AC Power Cord with NEMA 5-15P Plug
- H** USB Device-Charging Ports with Activity LEDs

Model: CS48USB

SPECIFICATIONS



iPAD/TABLET CHARGING STATIONS (USB)

Black Model	White Model	Description	Dimensions (HxWxD)	Weight	Load Rating	Cabinet Material
CS16USB	CS16USBW	16-iPad/Tablet Charging Station	14.6 x 23.6 x 17.7 in.	55 lb	200 lb	Steel
CS32USB	CS32USBW	32-iPad/Tablet Charging Station	25.1 x 23.6 x 21.6 in.	96 lb	200 lb	Steel
CS48USB	CS48USBW	48-iPad/Tablet Charging Station	35.6 x 23.6 x 21.6 in.	150 lb	250 lb	Steel

All models: 100-240 VAC, 50/60 Hz input. Up to 2.4 A output per USB port. 2-year limited warranty. Standards: Tested to UL 60950 (TUV), CE, FCC Class B, NOM.

ACCESSORIES

Model	Description
M110-10N-BK	10 in. USB to Apple® 30-Pin Connector Cable (Black)
M110-10N-BK-10	10 in. USB to Apple 30-Pin Connector Cable (Black, 10-pack)
M100-10N-BK	10 in. USB to Apple Lightning™ Connector Cable (Black)
M100-10N-BK-10	10 in. USB to Apple Lightning Connector Cable (Black, 10-pack)
SRCASTER	Rolling Caster Kit (Includes four casters and mounting hardware.)
CSHANDLEKIT	Handle and Rolling Caster Kit (Includes reversible handle, four casters and mounting hardware.)
U326-001-BK	1 ft. USB 3.0 A to 5-Pin Micro-B Cable (Black)
U326-001-BK-10	1 ft. USB 3.0 A to 5-Pin Micro-B Cable (Black, 10-pack)
UR050-001-24G	1 ft. USB 2.0 Reversible A to 5-Pin Micro-B Cable (Black)
UR050-001-24-10	1 ft. USB 2.0 Reversible A to 5-Pin Micro-B Cable (Black, 10-pack)



773.869.1773 • saleshelp@tripplite.com • www.tripplite.com/cs


CHROMEBOOK CHARGING STATIONS (AC)



- Secure and organize 16 or 32 Chromebooks
- Provide high-speed charging with built-in AC outlets for every device
- Mount to wall, desk, table, counter or floor, with support for optional casters and a reversible handle
- Prevent theft and tampering with locking steel door and side panels
- Provide flow-through ventilation to prevent devices from overheating while charging

All models available in black or white

FEATURE FOCUS

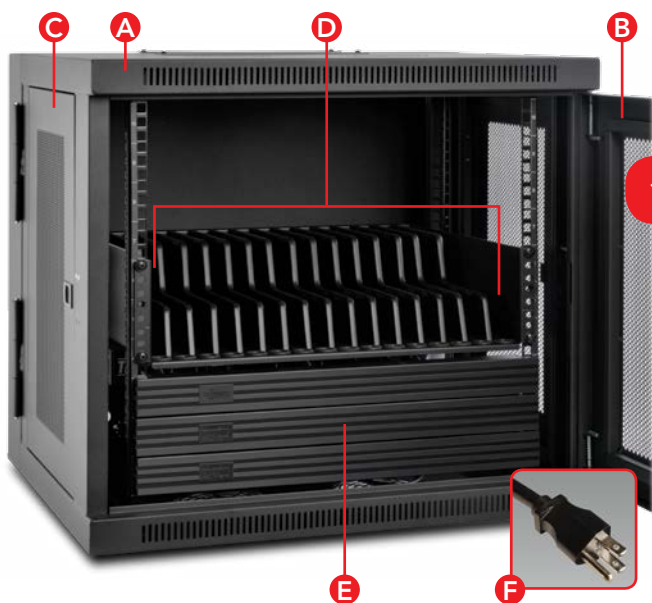


Model: CS16AC

16 Chromebooks

- A** Steel Cabinet
- B** Locking Door
- C** Locking Side Panels
- D** Adjustable Shelf Dividers
- E** Trim Panels (Conceal AC Adapters and Cords)
- F** AC Power Cord with NEMA 5-15P Plug
- G** AC Device-Charging Outlets (NEMA 5-15R)



G

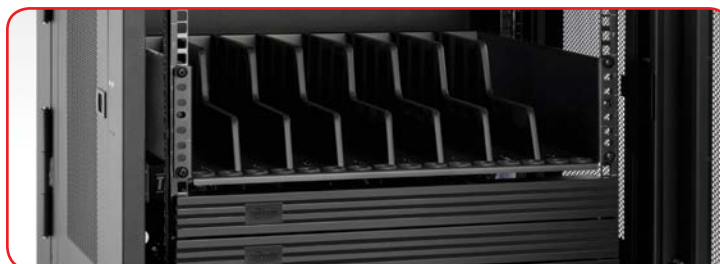

If you need to accommodate thicker devices, simply adjust the dividers to provide more space.



Model: CS32AC

- A** Steel Cabinet
- B** Locking Door
- C** Locking Side Panels
- D** Adjustable Shelf Dividers
- E** Trim Panels (Conceal AC Adapters and Cords)
- F** AC Power Cord with NEMA 5-15P Plug
- G** AC Device-Charging Outlets (NEMA 5-15R)



All charging stations can be equipped with a rolling caster kit (SRCASTER, shown installed above) or a kit that includes casters and a reversible handle (CSHANDLEKIT).

SPECIFICATIONS



CHROMEBOOK CHARGING STATIONS (AC)

Black Model	White Model	Description	Dimensions (HxWxD)	Weight	Load Rating	Cabinet Material
CS16AC	CS16ACW	16-Chromebook Charging Station	21.6 x 23.6 x 21.6 in.	72 lb	200 lb	Steel
CS32AC	CS32ACW	32-Chromebook Charging Station	35.6 x 23.6 x 21.6 in.	134 lb	250 lb	Steel

All models: 120 VAC, 50/60 Hz input. Up to 12 A (1,440 W) total output. 2-year limited warranty. Standards: Tested to UL 60950, TUV, NOM.

ACCESSORIES

Model	Description
SRCASTER	Rolling Caster Kit (Includes four casters and mounting hardware.)
CSHANDLEKIT	Handle and Rolling Caster Kit (Includes reversible handle, four casters and mounting hardware.)



Charge and Sync 16 Mobile Devices Simultaneously



Model: U280-016-RM

Tripp Lite's compact, rack-mountable charger is perfect for stand-alone charging applications. It can also upgrade existing device carts and storage with high-speed USB charging – up to 2.4 amps per port!

SPECIFICATIONS



Model	Description	Dimensions (H x W x D)	Weight	Cord/Plug	Housing
U280-016-RM	16-Port USB Charger with Syncing Function	1.7 x 17.3 x 9.5 in. (1U)	7.2 lb	10 ft. with 5-15P Plug	Steel

100-240 VAC, 50/60 Hz input. Up to 2.4 A output per USB port. 2-year limited warranty. Standards: Tested to UL 60950 (TUV), CE, FCC Class B, NOM.

TRIPP LITE MANUFACTURES OVER 3,000 IT INFRASTRUCTURE SOLUTIONS!

UPS Systems

250+ models of highly efficient UPS systems and battery packs.



Rack and Cooling Solutions

100+ models of EIA-compliant rack enclosures, open frame racks, cooling solutions and accessories.

Power Distribution Units (PDUs)

200+ models of basic, metered, monitored and switched rack PDUs.



KVM/Console Solutions

50+ models of KVMs, rack consoles and IP console servers, with or without remote access and built-in LCDs.



Cables and Connectivity

1,000+ cables, adapters, extenders, splitters, switches and patch panels.

Surge Protectors and Power Strips

200+ models of surge protectors and power strips.



Distributed By:



Tripp Lite World Headquarters
1111 West 35th St., Chicago, IL 60609 USA
773.869.1773 • saleshelp@tripplite.com
www.tripplite.com/cs